

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [10-01-3066](#)
Status: **Active**
Overview: SPOX™ Wire-to-Board Connectors
Description: 5.08mm Pitch SPOX™ Crimp Terminal Housing, 6 Circuits

Documents:

3D Model	Product Specification PS-5197-005 (PDF)
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
Product Specification PS-5197-001 (PDF)	

Agency Certification

CSA	LR19980
TUV	R72090224
UL	E29179

General

Product Family	Crimp Housings
Series	5197
Application	Signal, Wire-to-Board
Overview	SPOX™ Wire-to-Board Connectors
Product Name	SPOX™
UPC	800754209533

Physical

Circuits (maximum)	6
Color - Resin	Natural
Flammability	94V-2
Gender	Female
Glow-Wire Compliant	No
Material - Resin	Nylon
Net Weight	2305.100/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	5.08mm
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Material Info

Old Part Number	5197-06
-----------------	---------

Reference - Drawing Numbers

Product Specification	PS-5197-001, PS-5197-005, RPS-5281-001
Sales Drawing	SD-5197-N

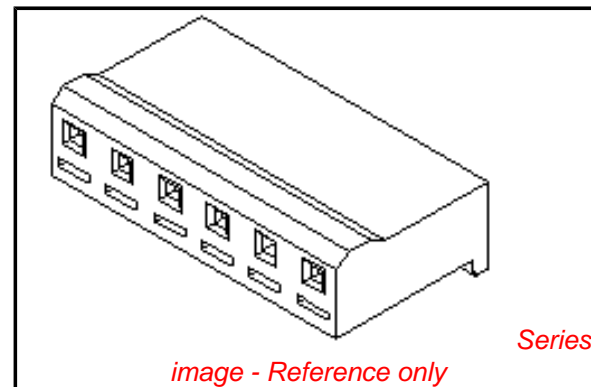


image - Reference only

EU RoHS

**ELV and RoHS
Compliant**
**REACH SVHC
Contains SVHC: No**
**Low-Halogen Status
Low-Halogen**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

5197Series

Mates With

5279 , 5280 , 5281 , 5282

Use With

5194 , 5225