


# 2AG Equivalent – 4.5 x 15mm Miniature Glass

 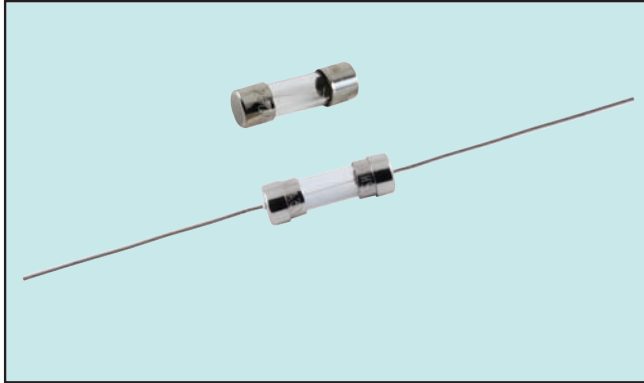


## Features


- Available in Fast Acting and Slow Blow Types
- Available in Cartridge and Axial Lead (Pigtail) Types
- RoHS Compliant



## F-08



## F-11

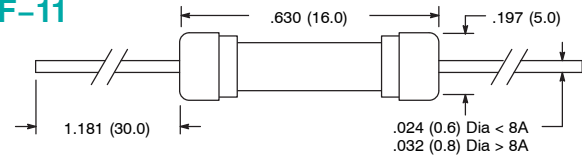

## Specifications

**Rated Voltage:** 125V / 250V

**Breaking Capacity:**

**Fast Acting:**

250V, 50A (375mA – 2A); 250V, 100A (2.5A – 5A);  
125V, 500A (6A – 10A)

**Slow Blow:**

250V, 35A (200mA – 1A); 250V, 100A (1.25A – 3.5A);  
125V, 100A (4A – 7A)

**Time Current Characteristics:**

| % of Ampere Rating | Opening Time   |                  |
|--------------------|----------------|------------------|
|                    | Fast Acting    | Slow Blow        |
| 100%               | 4 hours min.   | 4 hours min.     |
| 135%               | 1 hour max.    | 1 hour max.      |
| 200%               | 5 seconds max. | 120 seconds max. |

## Ordering Information:

| NTE Type No.    |             |          |                            |              |          | Rated Current |
|-----------------|-------------|----------|----------------------------|--------------|----------|---------------|
| Cartridge Types |             |          | Axial Lead (Pigtail) Types |              |          |               |
| Fast Acting     | Slow Blow   | Diag No. | Fast Acting                | Slow Blow    | Diag No. |               |
|                 | 74-4SG250MA | F-08     |                            | 74-4SGL250MA | F-11     | 250mA         |
|                 | 74-4SG350MA | F-08     |                            | 74-4SGL350MA | F-11     | 350mA         |
| 74-4FG375MA     | 74-4SG375MA | F-08     | 74-4FGL375MA               | 74-4SGL375MA | F-11     | 375mA         |
| 74-4FG500MA     | 74-4SG500MA | F-08     | 74-4FGL500MA               | 74-4SGL500MA | F-11     | 500mA         |
|                 | 74-4SG600MA | F-08     |                            | 74-4SGL600MA | F-11     | 600mA         |
| 74-4FG750MA     | 74-4SG750MA | F-08     | 74-4FGL750MA               | 74-4SGL750MA | F-11     | 750mA         |
|                 | 74-4SG800MA | F-08     |                            | 74-4SGL800MA | F-11     | 800mA         |
| 74-4FG1A        | 74-4SG1A    | F-08     | 74-4FGL1A                  | 74-4SGL1A    | F-11     | 1.0A          |
|                 | 74-4SG1.25A | F-08     |                            | 74-4SGL1.25A | F-11     | 1.25A         |
| 74-4FG1.5A      | 74-4SG1.5A  | F-08     | 74-4FGL1.5A                | 74-4SGL1.5A  | F-11     | 1.5A          |
|                 | 74-4SG1.6A  | F-08     |                            | 74-4SGL1.6A  | F-11     | 1.6A          |
| 74-4FG2A        | 74-4SG2A    | F-08     | 74-4FGL2A                  | 74-4SGL2A    | F-11     | 2.0A          |
| 74-4FG2.5A      | 74-4SG2.5A  | F-08     | 74-4FGL2.5A                | 74-4SGL2.5A  | F-11     | 2.5A          |
| 74-4FG3A        | 74-4SG3A    | F-08     | 74-4FGL3A                  | 74-4SGL3A    | F-11     | 3.0A          |
| 74-4FG3.5A      | 74-4SG3.5A  | F-08     | 74-4FGL3.5A                | 74-4SGL3.5A  | F-11     | 3.5A          |
| 74-4FG4A        | 74-4SG4A    | F-08     | 74-4FGL4A                  | 74-4SGL4A    | F-11     | 4.0A          |
| 74-4FG5A        | 74-4SG5A    | F-08     | 74-4FGL5A                  | 74-4SGL5A    | F-11     | 5.0A          |
| 74-4FG6A        | 74-4SG6A    | F-08     | 74-4FGL6A                  | 74-4SGL6A    | F-11     | 6.0A          |
| 74-4FG7A        | 74-4SG7A    | F-08     | 74-4FGL7A                  | 74-4SGL7A    | F-11     | 7.0A          |
| 74-4FG8A        |             | F-08     | 74-4FGL8A                  |              | F-11     | 8.0A          |
| 74-4FG10A       |             | F-08     | 74-4FGL10A                 |              | F-11     | 10A           |

**NOTE:** Fast Acting fuse are UL recognized up to 5A. Slow Blow fuses are UL listed up to 3.5A and UL recognized from 4A to 10A