


MNX PC 175/75 HT

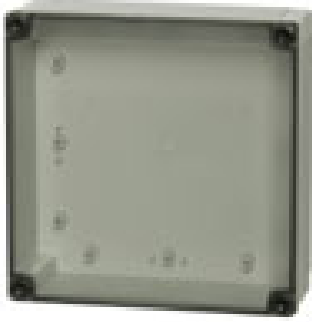

Sample photo

Order symbol: PC 175/75 HT
Product nbr: 6011920
Description: Enclosure, PC
Remarks: Smoked transparent cover

EAN: 6418074024435
EI. number:
 Finland: 3422254
 Electric No. Denmark: 8212022690
 Electric No. Italy: 7352113
 Electric No. Sweden: 2535664

Including: Base with TPE gasket, screws for mounting plate/DIN-rail and cover with polyamide cover screws.

Dimensions:			Accessories:	
Length	Width	Height		
mm:	180	180	MIN 15	DIN-15 Mounting rail
inch:	7.1	7.1	MIV 15	DIN-35 Mounting rail
			FP A 175/180	Front plate (Aluminium)
			HFP 180	Front plate hinge series
			FP 22046	Wall fastening lug (4 pcs)
Materials:			Rating:	
Material:	Polycarbonate		Ingress Protection (EN 60529): IP66/67	
Base colour:	RAL 7035 -light grey		Impact Resistance (EN 62262): IK08	
Cover screws material:	Polyamide		Electrical insulation: Totally insulated	
Cover colour:	Smoked grey		Halogen free (DIN/VDE 0472, Part 815): 1	
Cover screws colour:	Black		UV resistance: UL 508	
Gasket material:	TPE		Flammability Rating: UL 746C 5V	
			Glow Wire Test (IEC 695-2-1) °C: 960	
			NEMA Class: NEMA 1, 4, 4X, 6, 12, 13	
Temperatures:			Certificates:	
Temperature °C (short term):	-40 ... 120 °C		Germanischer Lloyd (GL)	
Temperature °C (continuous):	-40 ... 80 °C		SGS Fimko	
Temperature °F (short term):	-40 ... 250 °F		Gost R	
Temperature °F (continuous):	-40 ... 175 °F			
Accessories:				
MIV 175	Mounting plate (Galvanized steel)			

