

MTCA-085-02-S-DV-SMT-K-TR

**MTCA SERIES**

(0,75 mm) .030"

# MICRO TCA CONNECTOR

## SPECIFICATIONS

For complete specifications see [www.samtec.com?MTCA](http://www.samtec.com?MTCA)

**Insulator Material:**

LCP  
Terminal Material:  
Brass Alloy

**Plating:**

Au or Sn over  
50µ" (1,27 µm) Ni  
**Operating Temp Range:**  
-55°C to +125°C


## RECOGNITIONS

For complete scope of recognitions see [www.samtec.com/quality](http://www.samtec.com/quality)




**Mates with:**  
(1,60 mm) .062" thick cards

## APPLICATION

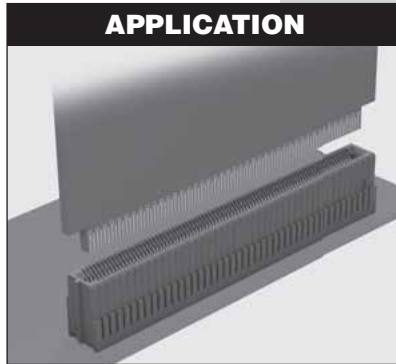

Contacts on  
(0,75 mm)  
.030" pitch



Supports  
hot plugging  
and high  
speed serial  
connections

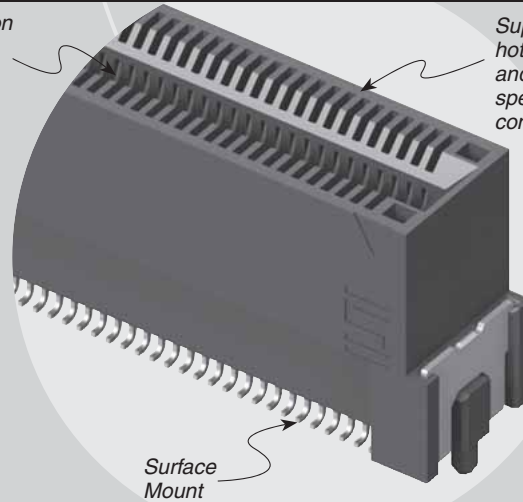

Surface  
Mount

## ALSO AVAILABLE (MOQ Required)

- Additional positions  
Contact Samtec.

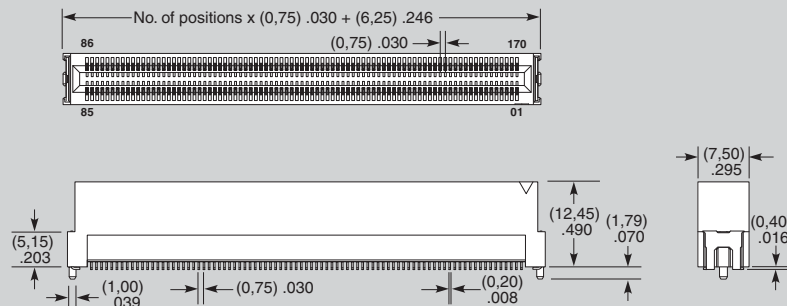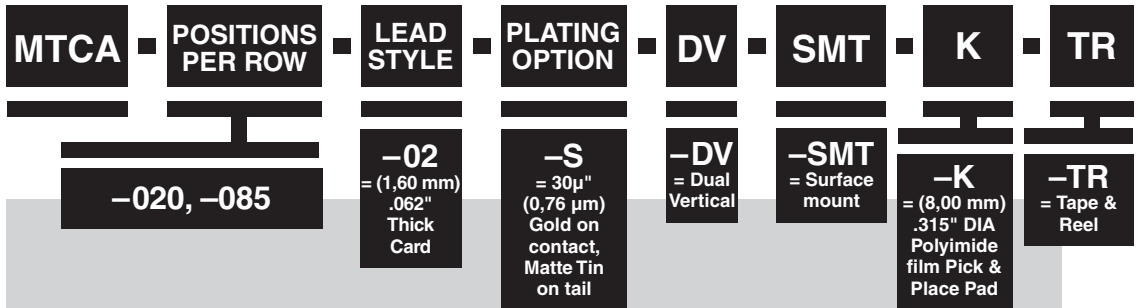

**Note:** Some lengths, styles and options are non-standard, non-returnable.

Due to technical progress, all designs, specifications and components are subject to change without notice.

[WWW.SAMTEC.COM](http://WWW.SAMTEC.COM)