

# EAO – Your Expert Partner for Human Machine Interfaces

## 82-5151.1214 - Illuminated pushbutton 19 mm stainless-steel, momentary

### 82-5151.1214 - Illuminated pushbutton 19 mm stainless-steel, momentary



*Attention: The preview is based on a sample product. This can differ from your current configuration.*

#### Mounting

Mounting cut-out Ø 19 mm  
Design flush

#### Front

Front dimension Ø 22 mm  
Front shape round  
Front ring shape flush

#### Other Attributes

Operating voltage 24 V AC/DC  
Weight 0.021 kg  
Operation current 10 mA

#### Operating-/Indication part

Lens optics opaque  
Lens material Stainless steel  
Lens profile flat  
Lens illumination illuminative  
Lens colour Stainless steel

#### IP-Rating

Front protection IP 67

#### Connection Method

Terminal Solder 2.8 x 0.5 mm

#### Actuator

Switching action Momentary

#### Switching element

Switching current 5 A  
Contact material Silver  
Contacts 1 C  
Switching system Snap-action switching element  
Switching voltage 250 V AC

#### Illumination

Illumination Dot with red LED


#### Function

Illuminated pushbutton


# EAO – Your Expert Partner for Human Machine Interfaces

82-5151.1214 - Illuminated pushbutton 19 mm stainless-steel, momentary


## Dimensions

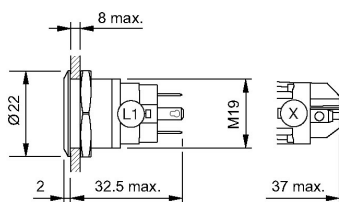


## Mounting cut-outs

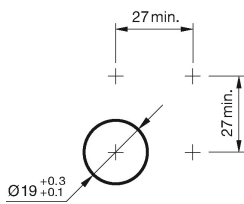

## Wiring diagram

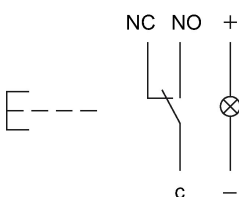

## Component layout

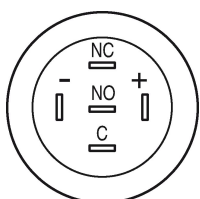

## Legend

Switching action: B = Momentary

Contacts: C = Changeover