



#### RE015-LF

- DIL-Labcard
- Epoxy fibre-glass 1.50 mm
- Single-sided 35 µm Cu
- Hot air leveling (HAL-Leadfree)
- Solder stop mask
- 14 x 14 soldering pads 2.00 x 2.00 mm
- Hole spacing 2.54 x 2.54 mm
- Hole diameter 1.00 mm
- Size 40.00 x 40.50 mm

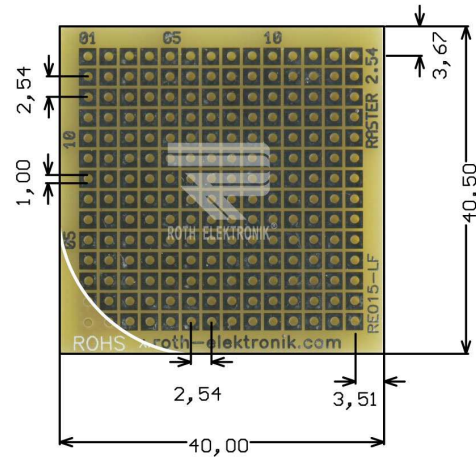

#### RE015-LF

- DIL-Laborkarte
- Epoxydglashartgewebe FR4 1,50 mm
- Einseitig 35 µm Cu
- Oberfläche HAL bleifrei
- Lötstopplack
- 14 x 14 Lötinseln 2,00 x 2,00 mm
- Raster 2,54 mm
- Lochdurchmesser 1,00 mm
- Größe 40,00 x 40,50 mm

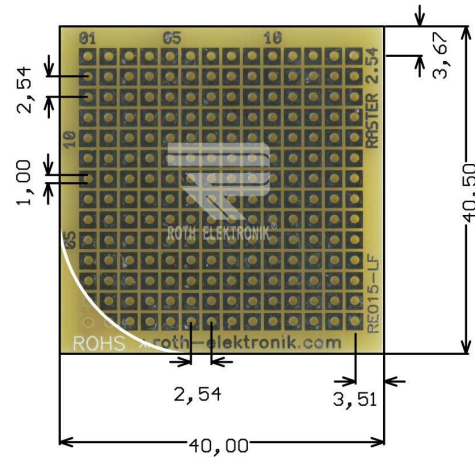

#### RE015-LF

- Carte d'expérimentation DIL
- Fibre de verre époxyde 1.50 mm
- Simple face 35 µm Cu
- Étamée à chaud (HAL-sans plomb)
- Masque de soudure
- 14 x 14 îlots de brasage 2.00 x 2.00 mm
- Pas 2.54 x 2.54 mm
- Perforation 1.00 mm
- Dimensions 40.00 x 40.50 mm

