

# UNIVERSAL ENCLOSURES

## 1100 Series Stylish ABS Cases

### 1101 ABS Lid

Aesthetic electronic enclosures with solid ABS lid, designed for a broad range of applications.

- Lid and base moulded in ABS- UL94-V0
- Lid mounted by four M3 machine screws
- Bevelled edges and curved side walls
- 1.2mm membrane keypad recesses in lid and base
- Polished finish for ease of cleaning and stylish appearance
- Deep profile for maximum internal volume
- Plastic standoffs in base for mounting of PCBs
- Excellent properties for machining



#### SPECIFICATION

Materials *Lid & base high impact ABS-UL94-V0*


Operating temperature *Resistant to temperatures up to 85°C*

Protection class *IP54*

Standard colours *Light grey similar to RAL 7035*

Standard unit includes: *Lid and Base  
4 x M3 machine screws*

LIGHT GREY	LENGTH	WIDTH	HEIGHT
CSACST001	90mm	50mm	35mm
CSACST002	110mm	60mm	40mm
CSACST003	125mm	75mm	50mm
CSACST004	155mm	95mm	60mm
CSACST005	190mm	115mm	75mm
CSACST006	220mm	140mm	90mm

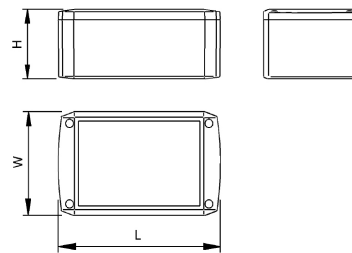

### 1102 Transparent Lid

Electronic enclosures featuring a transparent lid, designed for applications that require visible electronics. High impact polycarbonate smoked effect lid.

- Box moulded in ABS, UL94-V0
- Lid moulded in transparent, Polycarbonate, UL94-V0
- Lid mounted by four M3 machines screws
- Bevelled edges and curved side walls
- 1.2mm membrane keypad recesses in lid and base
- Polished finish for ease of cleaning and stylish appearance
- Deep profile for maximum internal volume
- Pillars in base for mounting of PCBs
- Excellent properties for machining



#### SPECIFICATION

Materials *Lid High Impact PC, UL94-V0  
Base High Impact ABS, UL94-V0*

Operating temperature *Base resistant to temperatures up to 85°C  
Lid resistant to temperatures up to 120°C*

Protection class *IP54*

Standard colours *Light grey similar to RAL 7035*

Standard unit includes: *Lid and Base  
4 x M3 machine screws*

LIGHT GREY	LENGTH	WIDTH	HEIGHT
CSACTT001	90mm	50mm	35mm
CSACTT002	110mm	60mm	40mm
CSACTT003	125mm	75mm	50mm
CSACTT004	155mm	95mm	60mm
CSACTT005	190mm	115mm	75mm
CSACTT006	220mm	140mm	90mm

