


Hex-Key Wrenches

Klein hex-keys are the tools professionals cannot afford to be without. Heat-treated and tempered for superior strength and durability, Klein hex-keys are designed for a precise fit in sockets, preventing slippage and stripping of the socket.

F O R P R O F E S S I O N A L S . . . S I N C E 1 8 5 7 ®

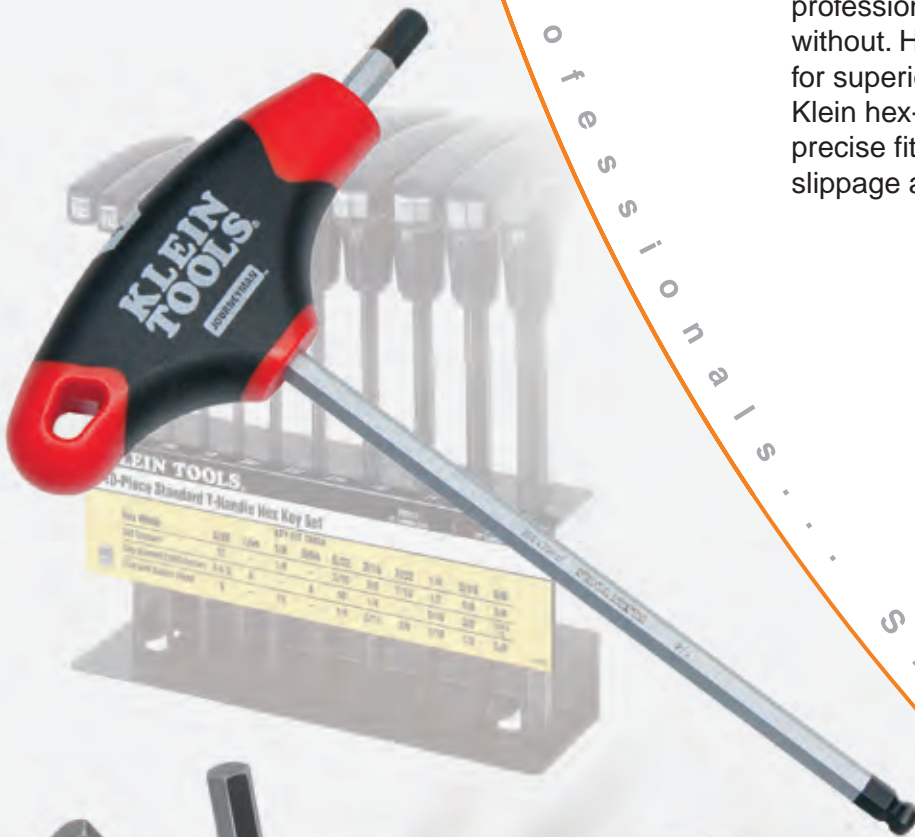

Hex-Key Wrenches



Folding Hex-Key Sets

Hex-Key Sets

- Two key positions (straight-out or right angle) for extra leverage.
- Hex ends are square-cut for a secure full-depth fit and maximum contact with the hex socket to prevent slippage and stripping of the socket.
- Handy sets fit your pocket or tool box easily and help eliminate the lost key problem.



70579

Cat. No.	Description	Handle Length	Key Lengths	Weight (lbs.)
Hex-Key Sets – Inch				
70591	nine-key inch set: 5/64", 3/32", 7/64", 1/8", 9/64", 5/32", 3/16", 7/32", 1/4"	4-1/4" (108 mm)	1-3/4" – 3-1/2" (44 mm – 89 mm)	.50
70581	eight-key inch set: .050", 1/16", 5/64", 3/32", 7/64", 1/8", 9/64", 5/32"	3-1/16" (78 mm)	1-1/2" – 2-3/8" (38 mm – 60 mm)	.20
70583	eight-key inch set: 3/32", 7/64", 1/8", 9/64", 5/32", 3/16", 7/32", 1/4"	5-1/4" (133 mm)	3-3/8" – 4-5/8" (86 mm – 117 mm)	.65
70579	five-key inch set: 3/16", 7/32", 1/4", 5/16", 3/8"	5-1/4" (133 mm)	3" – 4-5/8" (76 mm – 117 mm)	.85
Hex-Key Sets – Metric				
70582	seven-key metric set: 1.5 mm, 2 mm, 2.5 mm, 3 mm, 4 mm, 5 mm, 6 mm	92 mm (3-5/8")	41 mm – 76 mm (1-5/8" – 3")	.35
70580	five-key metric set: 4 mm, 5 mm, 6 mm, 8 mm, 10 mm	133 mm (5-1/4")	82 mm – 117 mm (3-1/4" – 4-5/8")	.85

Grip-It® Hex-Key Sets

- Blades rotate independently up to 270°.
- Precision fit so hex tool end reduces stripping problems. Keys are industrial strength, impact-resistant and tested for performance to below freezing.
- Glass-reinforced nylon handle.
- Hex ends are square-cut for a secure full-depth fit and maximum contact with the hex socket to prevent slippage and stripping of the socket (Cat. Nos. 70570, 70573, 70574, and 70575).
- Ball design allows for a thicker neck diameter increasing torque capacity, while maintaining operational angles to 25% (Cat. Nos. 70571 and 70572).



70570

Cat. No.	Description	Sizes	Color	Weight (lbs.)
70570	Grip-It® hex sets – 5 inch sizes	3/16", 7/32", 1/4", 5/16", 3/8"	yellow	.58
70571	Grip-It® ball hex set – 5 inch sizes	3/16", 7/32", 1/4", 5/16", 3/8"	yellow	.58
70572	Grip-It® ball hex set – 5 metric sizes	5 mm, 6 mm, 7 mm, 8 mm, 10 mm	red	.58
70573	Grip-It® hex sets – 6 inch sizes and 6 metric sizes	5/64", 3/32", 7/64", 1/8", 9/64", 5/32", 1.5 mm, 2 mm, 2.5 mm, 3 mm, 4 mm, 5 mm	blue	.30
70574	Grip-It® hex sets – 9 inch sizes	5/64", 3/32", 7/64", 1/8", 9/64", 5/32", 3/16", 7/32", 1/4"	yellow	.33
70575	Grip-It® hex sets – 9 inch sizes	.050", 1/16", 5/64", 3/32", 7/64", 1/8", 9/64", 5/32", 3/16"	yellow	.20

TORX® Set

Folding TORX® Set

- TORX® drive cuts slippage, saves fasteners, efficiently transmits more torque to the work.
- Keys are tough, heat-treated chrome-nickel alloy steel for strength and durability.
- Keys fold flat into handle.
- Can be used straight out or at an angle for extra leverage.



70586

Cat. No.	Handle Length	Blade Lengths	Contains	Weight (lbs.)
70586	4-1/4" (108 mm)	2-1/8" to 3" (54 mm to 76 mm)	T10, T15, T20, T25, T27, T30, T40	.30

TORX® is a trademark of Acument Intellectual Properties, LLC.

▲WARNING: Do NOT use a pipe or similar extension to increase leverage.


▲WARNING: Always wear approved eye protection.

▲WARNING: NOT insulated. Will NOT protect against electrical shock.



L-Style Hex-Key Sets

Features:

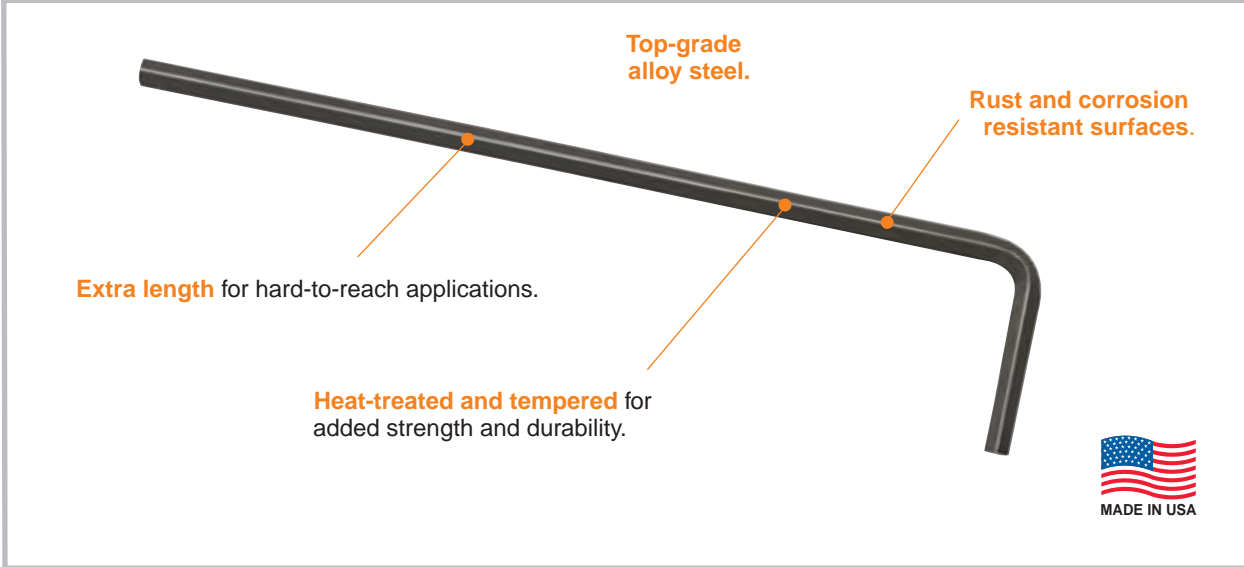

L-Style Ball-End Hex-Key Caddy Sets

Additional Features:

- L-style hex-keys in convenient caddy sets.
- Each set contains a unique locking feature and marked slots for each key.
- Ball-end works on angles up to 30°.
- Durable caddy keeps hex keys organized.



BLK12

12-Piece Ball-End Hex-Key Set – Inch

Cat. No.	Set Contains	Weight (lbs.)
BLK12		.53

Cat. No.	Hex Size	Size and Length	
		Short Arm Length	Long Arm Length
BL2	.050"	19/32"	2-29/32"
BL4	1/16"	5/8"	3-1/16"
BL5	5/64"	21/32"	3-1/4"
BL6	3/32"	23/32"	3-7/16"
BL7	7/64"	3/4"	3-5/8"
BL8	1/8"	13/16"	3-13/16"
BL9	9/64"	27/32"	4"
BL10	5/32"	29/32"	4-3/16"
BL12	3/16"	1"	4-15/32"
BL14	7/32"	1-3/32"	4-7/8"
BL16	1/4"	1-3/16"	5-5/16"
BL20	5/16"	1-5/16"	6"

9-Piece Ball-End Hex-Key Set – Metric

Cat. No.	Set Contains	Weight (lbs.)
BLMK10		.62

Cat. No.	Hex Size	Size and Length	
		Short Arm Length	Long Arm Length
BLM15	1.5 mm	1/2"	3"
BLM2	2 mm	5/16"	3-3/16"
BLM25	2.5 mm	2/32"	3-7/16"
BLM3	3 mm	23/32"	3-27/32"
BLM4	4 mm	29/32"	4-1/16"
BLM5	5 mm	1-1/32"	4-17/32"
BLM6	6 mm	1-3/16"	5-13/32"
BLM8	8 mm	1-11/32"	6-5/32"
BLM10	10 mm	1-1/2"	6-17/32"

▲WARNING: Do NOT use a pipe or similar extension to increase leverage.

▲WARNING: Always wear approved eye protection.

▲WARNING: NOT insulated. Will NOT protect against electrical shock.



L-Style Hex-Key Sets

L-Style Hex-Key Caddy Sets

Additional Features:

- L-style hex-keys in convenient caddy sets.
- Caddy contains a unique locking feature and marked slots for each key.
- Durable caddy keeps hex-keys organized.



12-Piece Hex-Key Set – Inch

Cat. No.	Set Contains	Weight (lbs.)
LLK12		.54

Cat. No.	Hex Size	Size and Length	
		Short Arm Length	Long Arm Length
LL2	.050"	5/8"	2-15/16"
LL4	1/16"	21/32"	3-3/32"
LL5	5/64"	11/16"	3-9/32"
LL6	3/32"	3/4"	3-15/32"
LL7	7/64"	25/32"	3-21/32"
LL8	1/8"	27/32"	3-27/32"
LL9	9/64"	7/8"	4-1/32"
LL10	5/32"	15/16"	4-7/32"
LL12	3/16"	1-1/32"	4-1/2"
LL14	7/32"	1-1/8"	4-29/32"
LL16	1/4"	1-7/32"	5-11/32"
LL20	5/16"	1-11/32"	6-1/32"

9-Piece Hex-Key Set – Metric

Cat. No.	Set Contains	Weight (lbs.)
LMK10		.63

Cat. No.	Hex Size	Size and Length	
		Short Arm Length	Long Arm Length
LLM15	1.5 mm	23/32"	3-1/8"
LLM2	2 mm	7/16"	3-1/32"
LLM25	2.5 mm	1/2"	3-9/32"
LLM3	3 mm	9/16"	3-1/2"
LLM4	4 mm	11/16"	3-31/32"
LLM5	5 mm	13/16"	4-3/8"
LLM6	6 mm	15/16"	4-27/32"
LLM8	8 mm	1-1/32"	5-1/32"
LLM10	10 mm	1-3/32"	5-9/32"

LLK12

L-Style Hex-Keys

L-Style Ball-End Hex-Keys

Additional Features:

- Allows easy access, even in restricted areas.
- Long side for accessing hard-to-reach places.
- Short side for higher torque situations and low clearances.



BL8

Cat. No.	Hex Size	Size and Length		Weight (lbs.)
		Short Arm Length	Long Arm Length	
Ball-End Hex-Key – Inch				
BL2	.050"	19/32"	2-29/32"	.002
BL4	1/16"	5/8"	3-1/16"	.002
BL5	5/64"	21/32"	3-1/4"	.005
BL6	3/32"	23/32"	3-7/16"	.005
BL7	7/64"	3/4"	3-5/8"	.01
BL8	1/8"	13/16"	3-13/16"	.02
BL9	9/64"	27/32"	4"	.02
BL10	5/32"	29/32"	4-3/16"	.03
BL12	3/16"	1"	4-15/32"	.05
BL14	7/32"	1-3/32"	4-7/8"	.06
BL16	1/4"	1-3/16"	5-5/16"	.09
BL20	5/16"	1-5/16"	6"	.17
BL24	3/8"	1-7/16"	6-13/16"	.23

Cat. No.	Hex Size	Size and Length		Weight (lbs.)
		Short Arm Length	Long Arm Length	
Ball-End Hex-Key – Metric				
BLM15	1.5 mm	1/2"	3"	.01
BLM2	2 mm	5/16"	3-3/16"	.01
BLM25	2.5 mm	2/32"	3-7/16"	.01
BLM3	3 mm	23/32"	3-27/32"	.02
BLM4	4 mm	29/32"	4-1/16"	.03
BLM5	5 mm	1-1/32"	4-17/32"	.05
BLM6	6 mm	1-3/16"	5-13/32"	.08
BLM8	8 mm	1-11/32"	6-5/32"	.14
BLM10	10 mm	1-1/2"	6-17/32"	.24

▲WARNING: Do NOT use a pipe or similar extension to increase leverage.


▲WARNING: Always wear approved eye protection.

▲WARNING: NOT insulated. Will NOT protect against electrical shock.



L-Style Hex-Keys

Long-Arm Hex-Keys – Inch

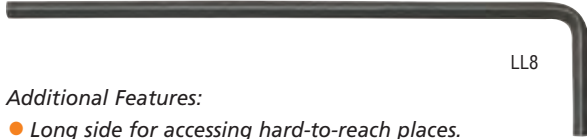


LL8

Additional Features:

- Long side for accessing hard-to-reach places.
- Short side for higher torque situations and low clearances.

Cat. No.	Hex Size	Size and Length		Weight (lbs.)
		Short Arm Length	Long Arm Length	
LL2	.050"	5/8"	2-15/16"	.005
LL4	1/16"	21/32"	3-3/32"	.005
LL5	5/64"	11/16"	3-9/32"	.005
LL6	3/32"	3/4"	3-15/32"	.01
LL7	7/64"	25/32"	3-21/32"	.02
LL8	1/8"	27/32"	3-27/32"	.02
LL9	9/64"	7/8"	4-1/32"	.03
LL10	5/32"	15/16"	4-7/32"	.03
LL12	3/16"	1-1/32"	4-1/2"	.05
LL14	7/32"	1-1/8"	4-29/32"	.70
LL16	1/4"	1-7/32"	5-11/32"	.10
LL20	5/16"	1-11/32"	6-1/32"	.18
LL24	3/8"	1-15/32"	6-27/32"	.25

Long-Arm Hex-Keys – Metric

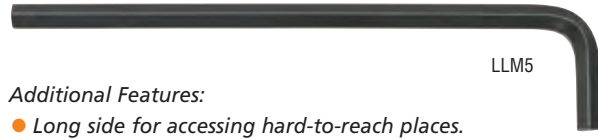

LLM5

Additional Features:

- Long side for accessing hard-to-reach places.
- Short side for higher torque situations and low clearances.

Cat. No.	Hex Size	Size and Length		Weight (lbs.)
		Short Arm Length	Long Arm Length	
LLM15	1.5 mm	17/32"	3-1/32"	.005
LLM2	2 mm	13/32"	3-7/32"	.005
LLM25	2.5 mm	11/16"	3-15/32"	.01
LLM3	3 mm	3/4"	3-7/8"	.02
LLM4	4 mm	15/16"	4-3/32"	.03
LLM5	5 mm	1-1/16"	4-9/16"	.05
LLM6	6 mm	1-7/32"	5-7/16"	.08
LLM8	8 mm	1-3/8"	6-3/16"	.15
LLM10	10 mm	1-17/32"	6-9/16"	.25

⚠WARNING: Do NOT use a pipe or similar extension to increase leverage on L-Style Hex-Keys.



⚠WARNING: Always wear approved eye protection.

⚠WARNING: NOT insulated. Will NOT protect against electrical shock.

T-Handle Hex-Key Sets

Features:

Color-coded handles: blue for metric, black for inch.

Cat. No. and hex size on handle for positive identification.

Treated steel for rust and corrosion resistance.

Molded-in finger grooves for comfort.

T-handle design delivers more torque to the fasteners.

9" length is available for hard-to-reach applications.



T-Handle Hex-Key Sets with Stand

Additional Features:

- Furnished complete with a rugged metal stand for mounting on bench or wall.
- T-handle design delivers more torque to the fasteners.



70152

Cat. No.	Set Contains	Weight (lbs.)
70152		2.00

Cat. No.	Hex Size	Blade Length
76206	3/32"	4" (102 mm)
76207	7/64"	4" (102 mm)
76208	1/8"	4" (102 mm)
76209	9/64"	4" (102 mm)
76210	5/32"	4" (102 mm)
76212	3/16"	4-1/2" (114 mm)
76214	7/32"	4-1/2" (114 mm)
76216	1/4"	4-1/2" (114 mm)
76220	5/16"	4-1/2" (114 mm)
76224	3/8"	4-1/2" (114 mm)

T-Handle Hex-Keys

Additional Features:

- T-handle design delivers more torque to the fasteners.
- Color-coded handles: blue for metric, black for inch.



79224

6" Length - Inch

9" Length - Inch

6" Length - Metric

Cat. No.	Hex Size	Blade Length	Weight (lbs.)	Cat. No.	Hex Size	Blade Length	Weight (lbs.)	Cat. No.	Hex Size	Blade Length	Weight (lbs.)
76209	9/64"	4" (102 mm)	.08	79206	3/32"	7-1/4" (184 mm)	.07	76302	2 mm	6" (152 mm)	.06
76214	7/32"	4-1/2" (114 mm)	.19	79207	7/64"	7-1/4" (184 mm)	.07	76325	2.5 mm	6" (152 mm)	.07
76220	5/16"	4-1/2" (114 mm)	.25	79209	9/64"	7-1/4" (184 mm)	.09	76305	5 mm	6" (152 mm)	.19
76232	1/2"	4-1/2" (114 mm)	.45	79212	3/16"	7-1/2" (191 mm)	.19	76306	6 mm	6" (152 mm)	.22
				79214	7/32"	7-1/2" (191 mm)	.22	76308	8 mm	6" (152 mm)	.31
				79216	1/4"	7-1/2" (191 mm)	.26	76310	10 mm	6" (152 mm)	.42
				79224	3/8"	7-1/2" (191 mm)	.45				
				79232	1/2"	7-1/2" (191 mm)	.65				

▲WARNING: Always wear approved eye protection.

▲WARNING: NOT insulated. Will NOT protect against electrical shock.



Journeyman™ T-Handle Hex-Keys

Features:


Tip-Ident® sizes marked on individual T-handles.

JOURNEYMAN™

Blade through handle design for high torque applications.

T-handle design delivers maximum power.

Soft touch grips for maximum control and comfort.

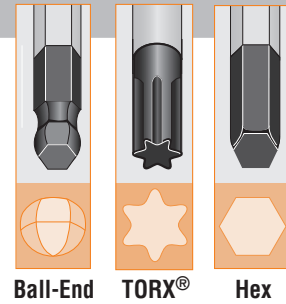


Ball-End

TORX®

Hex

Chamfered end for ease of use.

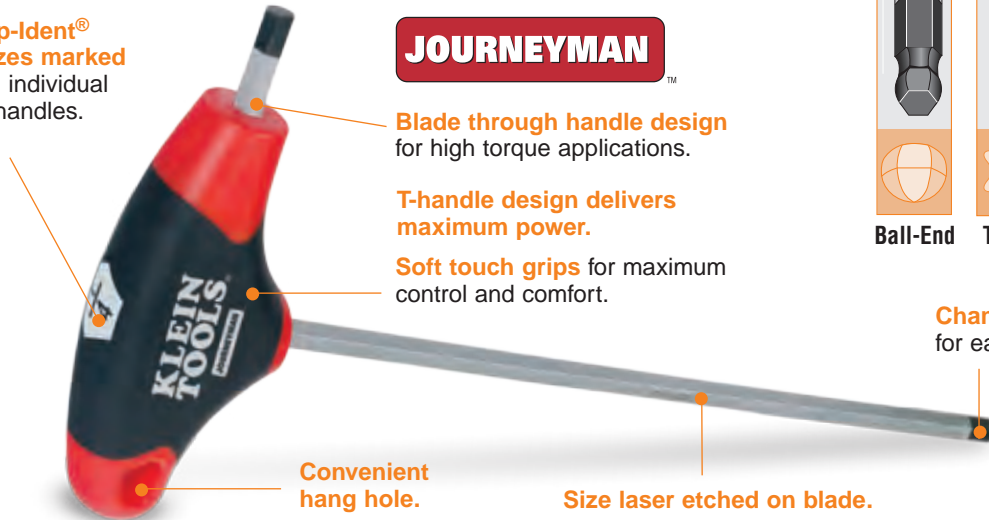

T-Handle Ball-End Hex-Key Set with Stand – Inch

JOURNEYMAN™

Additional features

- Metal stand for convenient hanging, storage on bench or wall.
- Short blade through handle provides maximum tool versatility.

6" Length - Inch

Cat. No.	Set Contains	Weight (lbs.)
JTH610EB		3.0
Cat. No.	Hex Size	Blade Length
JTH6E06BE	3/32"	6" (152 mm)
JTH6E07BE	7/64"	6" (152 mm)
JTH6E08BE	1/8"	6" (152 mm)
JTH6E09BE	9/64"	6" (152 mm)
JTH6E10BE	5/32"	6" (152 mm)
JTH6E11BE	3/16"	6" (152 mm)
JTH6E12BE	7/32"	6" (152 mm)
JTH6E13BE	1/4"	6" (152 mm)
JTH6E14BE	5/16"	6" (152 mm)
JTH6E15BE	3/8"	6" (152 mm)



JTH610EB

T-Handle Ball-End Hex-Keys – Inch


JOURNEYMAN™

Additional features

- Short blade through handle provides maximum tool versatility.
- Black oxide tips for precision fit.

6" Length - Inch

Cat. No.	Hex Size	Blade Length	Weight (lbs.)
JTH6E06BE	3/32"	6" (152 mm)	.04
JTH6E07BE	7/64"	6" (152 mm)	.05
JTH6E08BE	1/8"	6" (152 mm)	.06
JTH6E09BE	9/64"	6" (152 mm)	.07
JTH6E10BE	5/32"	6" (152 mm)	.12
JTH6E11BE	3/16"	6" (152 mm)	.14

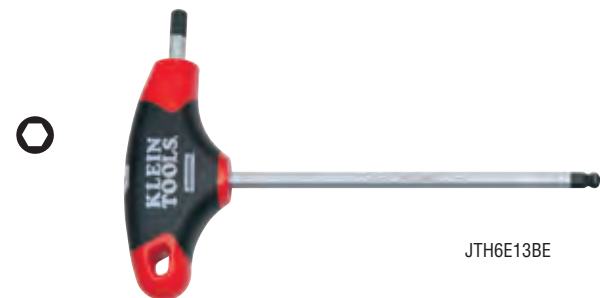

JTH6E13BE

Cat. No.	Hex Size	Blade Length	Weight (lbs.)
JTH6E12BE	7/32"	6" (152 mm)	.17
JTH6E13BE	1/4"	6" (152 mm)	.27
JTH6E14BE	5/16"	6" (152 mm)	.35
JTH6E15BE	3/8"	6" (152 mm)	.45
JTH6E17BE	1/2"	6" (152 mm)	.70

▲WARNING: Always wear approved eye protection.

▲WARNING: NOT insulated. Will NOT protect against electrical shock.

▲WARNING: Never use on or near live electrical circuits.



Journeyman™ T-Handle Hex-Keys

T-Handle Hex-Key Sets with Stand – Inch

JOURNEYMAN

Additional features

- Metal stand for convenient mounting on bench or wall.
- Short blade through handle provides maximum tool versatility.

4" Length – Inch

Cat. No.	Set Contains	Weight (lbs.)
JTH410E		2.7

Cat. No.	Hex Size	Blade Length
JTH4E06	3/32"	4" (102 mm)
JTH4E07	7/64"	4" (102 mm)
JTH4E08	1/8"	4" (102 mm)
JTH4E09	9/64"	4" (102 mm)
JTH4E10	5/32"	4" (102 mm)
JTH4E11	3/16"	4" (102 mm)
JTH4E12	7/32"	4" (102 mm)
JTH4E13	1/4"	4" (102 mm)
JTH4E14	5/16"	4" (102 mm)
JTH4E15	3/8"	4" (102 mm)



JTH610E

6" Length – Inch

Cat. No.	Set Contains	Weight (lbs.)
JTH610E		2.7

Cat. No.	Hex Size	Blade Length
JTH6E06	3/32"	6" (152 mm)
JTH6E07	7/64"	6" (152 mm)
JTH6E08	1/8"	6" (152 mm)
JTH6E09	9/64"	6" (152 mm)
JTH6E10	5/32"	6" (152 mm)
JTH6E11	3/16"	6" (152 mm)
JTH6E12	7/32"	6" (152 mm)
JTH6E13	1/4"	6" (152 mm)
JTH6E14	5/16"	6" (152 mm)
JTH6E15	3/8"	6" (152 mm)

9" Length – Inch

Cat. No.	Set Contains	Weight (lbs.)
JTH910E		3.56


Cat. No.	Hex Size	Blade Length
JTH9E06	3/32"	4" (102 mm)
JTH9E07	7/64"	4" (102 mm)
JTH9E08	1/8"	4" (102 mm)
JTH9E09	9/64"	4" (102 mm)
JTH9E10	5/32"	4" (102 mm)
JTH9E11	3/16"	4" (102 mm)
JTH9E12	7/32"	4" (102 mm)
JTH9E13	1/4"	4" (102 mm)
JTH9E14	5/16"	4" (102 mm)
JTH9E15	3/8"	4" (102 mm)

T-Handle Hex-Key Sets – Inch

JOURNEYMAN

Additional features

- Short blade through handle provides maximum tool versatility.
- Black oxide tips for precision fit.

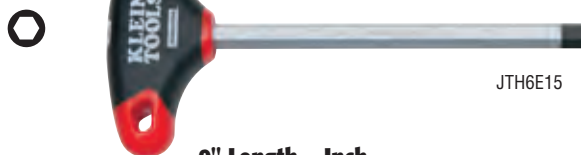

JTH6E15

4" Length – Inch

Cat. No.	Hex Size	Blade Length	Weight (oz.)
JTH4E06	3/32"	4" (102 mm)	.04
JTH4E07	7/64"	4" (102 mm)	.05
JTH4E08	1/8"	4" (102 mm)	.05
JTH4E09	9/64"	4" (102 mm)	.06
JTH4E10	5/32"	4" (102 mm)	.11
JTH4E11	3/16"	4" (102 mm)	.13
JTH4E12	7/32"	4" (102 mm)	.15
JTH4E13	1/4"	4" (102 mm)	.24
JTH4E14	5/16"	4" (102 mm)	.30
JTH4E15	3/8"	4" (102 mm)	.38
JTH4E17	1/2"	4" (102 mm)	.59

6" Length – Inch

Cat. No.	Hex Size	Blade Length	Weight (lbs.)
JTH6E06	3/32"	6" (152 mm)	.04
JTH6E07	7/64"	6" (152 mm)	.05
JTH6E08	1/8"	6" (152 mm)	.05
JTH6E09	9/64"	6" (152 mm)	.06
JTH6E10	5/32"	6" (152 mm)	.11
JTH6E11	3/16"	6" (152 mm)	.13
JTH6E12	7/32"	6" (152 mm)	.15
JTH6E13	1/4"	6" (152 mm)	.24
JTH6E14	5/16"	6" (152 mm)	.30
JTH6E15	3/8"	6" (152 mm)	.38
JTH6E17	1/2"	6" (152 mm)	.59

9" Length – Inch

Cat. No.	Hex Size	Blade Length	Weight (lbs.)
JTH9E06	3/32"	9" (229 mm)	.05
JTH9E07	7/64"	9" (229 mm)	.05
JTH9E08	1/8"	9" (229 mm)	.06
JTH9E09	9/64"	9" (229 mm)	.07
JTH9E10	5/32"	9" (229 mm)	.11
JTH9E11	3/16"	9" (229 mm)	.14
JTH9E12	7/32"	9" (229 mm)	.17
JTH9E13	1/4"	9" (229 mm)	.27
JTH9E14	5/16"	9" (229 mm)	.35
JTH9E15	3/8"	9" (229 mm)	.45
JTH9E17	1/2"	9" (229 mm)	.70

▲WARNING: Always wear approved eye protection.

▲WARNING: NOT insulated. Will NOT protect against electrical shock.

▲WARNING: Never use on or near live electrical circuits.



Journeyman™ T-Handle Hex-Keys

T-Handle Ball-End Hex-Key Set with Stand – Metric

JOURNEYMAN

Additional features

- Metal stand for convenient mounting 9 on bench or wall.
- Short blade through handle provides maximum tool versatility.

6" Length - Inch

Cat. No.	Set Contains	Weight (lbs.)
JTH68MB		2.7
Cat. No.	Hex Size	Blade Length
JTH6M2BE	2 mm	6" (152 mm)
JTH6M25BE	2.5 mm	6" (152 mm)
JTH6M3BE	3 mm	6" (152 mm)
JTH6M4BE	4 mm	6" (152 mm)
JTH6M5BE	5 mm	6" (152 mm)
JTH6M6BE	6 mm	6" (152 mm)
JTH6M8BE	8 mm	6" (152 mm)
JTH6M10BE	10 mm	6" (152 mm)



JTH68MB

T-Handle Ball-End Hex-Keys – Metric

JOURNEYMAN

Additional features

- Short blade through handle provides maximum tool versatility.
- Black oxide tips for precision fit.

Cat. No.	Hex Size	Blade Length	Weight (lbs.)
JTH6M2BE	2 mm	6" (152 mm)	.04
JTH6M25BE	2.5 mm	6" (152 mm)	.05
JTH6M3BE	3 mm	6" (152 mm)	.06
JTH6M4BE	4 mm	6" (152 mm)	.07
JTH6M5BE	5 mm	6" (152 mm)	.15
JTH6M6BE	6 mm	6" (152 mm)	.19
JTH6M8BE	8 mm	6" (152 mm)	.35
JTH6M10BE	10 mm	6" (152 mm)	.48



JTH6M8BE

T-Handle Hex-Key Sets with Stand – Metric

JOURNEYMAN

Additional features

- Metal stand for convenient mounting on bench or wall.
- Short blade through handle provides maximum tool versatility.

6" Length - Inch

Cat. No.	Set Contains	Weight (lbs.)
JTH68M		1.84
Cat. No.	Hex Size	Blade Length
JTH6M2	2 mm	6" (152 mm)
JTH6M25	2.5 mm	6" (152 mm)
JTH6M3	3 mm	6" (152 mm)
JTH6M4	4 mm	6" (152 mm)
JTH6M5	5 mm	6" (152 mm)
JTH6M6	6 mm	6" (152 mm)
JTH6M8	8 mm	6" (152 mm)
JTH6M10	10 mm	6" (152 mm)

9" Length - Inch

Cat. No.	Set Contains	Weight (lbs.)
JTH98M		2.14
Cat. No.	Hex Size	Blade Length
JTH9M2	2 mm	9" (229 mm)
JTH9M25	2.5 mm	9" (229 mm)
JTH9M3	3 mm	9" (229 mm)
JTH9M4	4 mm	9" (229 mm)
JTH9M5	5 mm	9" (229 mm)
JTH9M6	6 mm	9" (229 mm)
JTH9M8	8 mm	9" (229 mm)
JTH9M10	10 mm	9" (229 mm)



JTH68M

▲WARNING: Always wear approved eye protection.

▲WARNING: NOT insulated. Will NOT protect against electrical shock.

▲WARNING: Never use on or near live electrical circuits.



Journeyman™ T-Handle Hex-Keys

T-Handle Hex-Keys – Metric

JOURNEYMAN

Additional features

- Short blade through handle provides maximum tool versatility.
- Black oxide tips for precision fit.



JTH6M8

6" Length Inch

Cat. No.	Hex Size	Blade Length	Weight (lbs.)
JTH6M2	2 mm	6" (152 mm)	.04
JTH6M25	2.5 mm	6" (152 mm)	.05
JTH6M3	3 mm	6" (152 mm)	.06
JTH6M4	4 mm	6" (152 mm)	.07
JTH6M5	5 mm	6" (152 mm)	.15
JTH6M6	6 mm	6" (152 mm)	.17
JTH6M8	8 mm	6" (152 mm)	.35
JTH6M10	10 mm	6" (152 mm)	.48

9" Length Inch

Cat. No.	Hex Size	Blade Length	Weight (oz.)
JTH9M2	2 mm	9" (229 mm)	.05
JTH9M25	2.5 mm	9" (229 mm)	.06
JTH9M3	3 mm	9" (229 mm)	.07
JTH9M4	4 mm	9" (229 mm)	.10
JTH9M5	5 mm	9" (229 mm)	.18
JTH9M6	6 mm	9" (229 mm)	.23
JTH9M8	8 mm	9" (229 mm)	.42
JTH9M10	10 mm	9" (229 mm)	.48

T-Handle Hex-Key Set with Stand – TORX®

JOURNEYMAN

Additional features

- Metal stand for convenient mounting on bench or wall.
- Short blade through handle provides maximum tool versatility.

Cat. No.	Set Contains	Weight (lbs.)
JTH67T		1.32

Cat. No.	Hex Size	Blade Length
JTH6T10	T10	6" (152 mm)
JTH6T15	T15	6" (152 mm)
JTH6T20	T20	6" (152 mm)
JTH6T25	T25	6" (152 mm)
JTH6T27	T27	6" (152 mm)
JTH6T30	T30	6" (152 mm)
JTH6T40	T40	6" (152 mm)



JTH67T

T-Handle Hex-Keys – TORX®

JOURNEYMAN

Additional features

- Short blade through handle provides maximum tool versatility.
- Black oxide tips for precision fit.

Cat. No.	Hex Size	Blade Length	Weight (lbs.)
JTH6T10	T10	6" (152 mm)	.05
JTH6T15	T15	6" (152 mm)	.06
JTH6T20	T20	6" (152 mm)	.07
JTH6T25	T25	6" (152 mm)	.13
JTH6T27	T27	6" (152 mm)	.16
JTH6T30	T30	6" (152 mm)	.18
JTH6T40	T40	6" (152 mm)	.29



JTH6T40

TORX® is a trademark of Acument Intellectual Properties, LLC.

▲WARNING: Always wear approved eye protection.

▲WARNING: NOT insulated. Will NOT protect against electrical shock.

▲WARNING: Never use on or near live electrical circuits.

