


Chip Bead Inductors for Power Lines (FB series M type)

FBMJ1608HM230NT

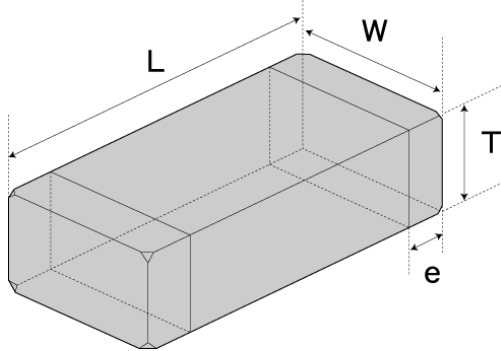

■ Features

- Item Summary
23Ω, 4A, 0603
- Lifecycle Stage
Mass Production
- Standard packaging quantity (minimum)
Taping 4000pcs

■ Products characteristics table

CaseSize (EIA/JIS)	0603/1608
Impedance	23Ω
Impedance Measuring Frequency	100MHz
Rated Current	4A
DC Resistance (max)	0.007Ω
Temperature Range	-40°C to 125°C
RoHS Compliance	Yes
Halogen Free	Yes
Soldering Method	Reflow/Wave

■ External Dimensions

L	1.6mm ±0.2
W	0.8mm ±0.2
T	0.8mm ±0.2
e	0.3mm ±0.2

■ Typical Characteristics Fig.

