


Part Number : PEH534PAB3470M2

Customer :

Customer p/n :

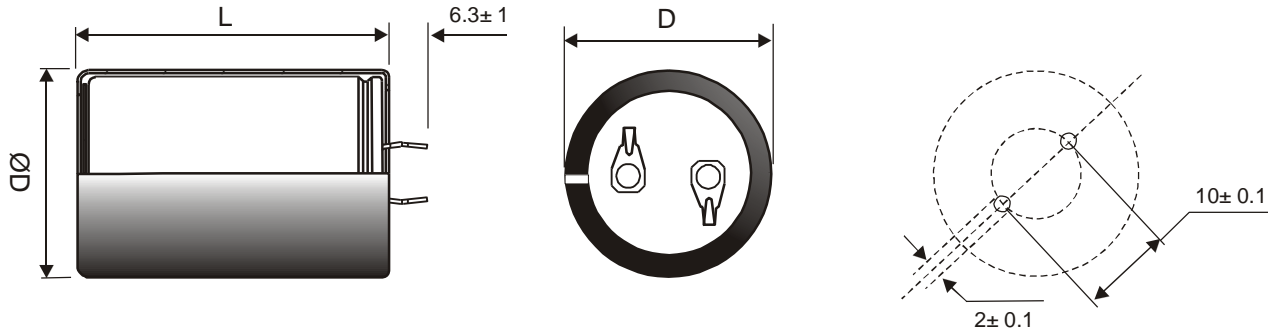

Diameter (mm) 22.5 +/-0.5
 Length (L or L2) (mm) 26 +/-1
 Terminals 2 Pin Snap-in
 Other Dimensions

Capacitance: 470 uF
 Lower Cap Tolerance: 20 %
 Upper Cap Tolerance: 20 %
 Working Voltage: 100 V DC
 Surge Test Voltage: 115 V DC

ESR 344 m'Ohms MAX @ 100 HZ,20°C
 IMPEDANCE 254 m'Ohms MAX @ 10 KHZ,20°C
 0
 DC LEAKAGE 0.14 mA max @ Test Volts
 Test Voltage 100.0V DC

Rated ripple current 1.1 A rms at 100 Hz and 105 °C
 Temperature range -40 °C to 105 °C

Expected life = 3000h (Ur, Ir, 105°C, 100Hz) considering EOL at 2x Initial Typical ESR

Approved _____ Date _____

Form : FM003.DES Iss : 3 Date :30/06/1