



T-2 Telephone Slide Base - Type 3

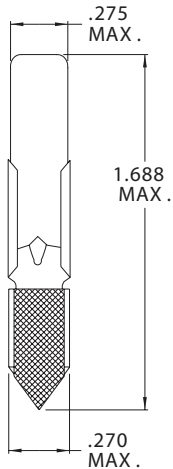

Part Number	Design Voltage	Amps	MSCP	Life Hours	Filament Type
24D	24.0	.100	1,500	5,000	C-7A
24E	24.0	.035	600	7,000	C-2F
24F	24.0	.090	1,120	7,000	C-2F
24H	24.0	.020	100	10,000	C-2F
24X	24.0	.035	600	8,000	C-2F
30A	30.0	.072	2,000	3,000	C-7A
30C	30.0	.038	1,000	4,000	C-2F
32B	32.0	.040	1,600	3,500	C-2F
30B	35.0	.100	3,000	4,000	C-7A
35A	35.0	.040	1,000	7,500	C-2F
35B	35.0	.072	700	5,000	C-7A
35C	35.0	.100	750	5,000	C-7A
40A	40.0	.072	480	5,000	C-7A
44A	44.0	.072	1,250	1,000	C-7A
48A	48.0	.072	2,000	5,000	C-7A
48B	48.0	.100	2,200	10,000	C-7A
48C	48.0	.035	400	7,000	C-7A
48D	48.0	.021	100	20,000	C-7A
48G	48.0	.052	800	5,000	C-7A
48H	48.0	.045	1,000	5,000	C-7A
55B	55.0	.100	1,800	5,000	C-7A
55C	55.0	.050	1,400	5,000	C-7A
60A	60.0	.050	1,600	5,000	C-7A

T-2 Miniature Bayonet Base

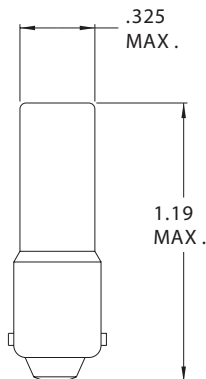

Part Number	Design Voltage	Amps	MSCP	Life Hours	Filament Type
6MB	6.0	.140	550	20,000	C-2V
12MB	12.0	.170	2,000	12,000	C-2F
24MB	24.0	.073	3,000	10,000	C-2F
28MB	28.0	.040	1,600	5,000	C-2F
48MB	48.0	.053	1,800	10,000	C-7A
60MB	60.0	.050	2,200	7,500	C-7A
120MB	120.0	.025	1,200	5,000	CC-7A
8-967	120.0	.025	1,200	5,000	CC-7A