


T-1 Wire Terminal (standard)

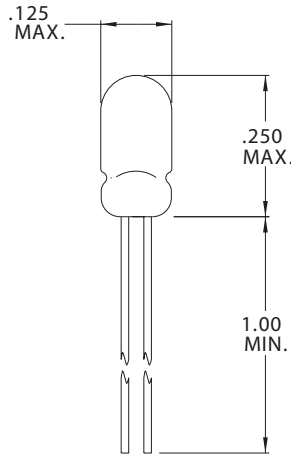

Part Number	Design Voltage	Amps	MSCP	Life Hours	Filament Type
8798	1.25	.012	.004	1,000	C-6
8910	1.35	.220	.020	25,000	C-2R
7201	1.50	.015	.010	5,000	C-2R
7202	1.50	.066	.015	100,000	C-2R
7203	1.50	.075	.030	16,000	C-2R
7018	2.50	.320	.210	10,000	C-2R
8601	2.50	.015	.001	10,000	C-2R
8711	2.50	.320	.210	5,000	C-2R
8732	2.50	.100	.100	10,000	C-2R
2128	3.0	.013	.001	10,000	C-2R
7205	3.0	.015	.020	5,000	C-2R
7206	3.0	.024	.020	10,000	C-2F
7207	3.0	.060	.030	100,000	C-2R
7208	3.0	.120	.150	16,000	C-2R
8846	3.0	.008	.001	16,000	C-2R
680	5.0	.060	.030	60,000	C-2R
683	5.0	.060	.050	25,000	C-2R
713	5.0	.075	.090	25,000	C-2R
715	5.0	.115	.150	40,000	C-2R
3022	5.0	.021	.030	10,000	C-2R
3211	5.0	.115	.200	5,000	C-2R
6022	5.0	.021	.030	10,000	C-2R
6150	5.0	.060	.150	5,000	C-2R
6212	5.0	.080	.150	15,000	C-2R
6801	5.0	.060	.030	100,000	C-2R
6830	5.0	.060	.050	25,000	C-2R
6831	5.0	.060	.050	25,000	C-2R
7007	5.0	.064	.080	40,000	C-2R
7008	5.0	.064	.080	40,000	C-2R
7019	5.0	.015	.010	10,000	C-2V
7131	5.0	.075	.090	25,000	C-2R
7151	5.0	.115	.150	40,000	C-2R
7209	5.0	.015	.020	10,000	C-2F
7210	5.0	.030	.030	16,000	C-2F
7211	5.0	.080	.150	15,000	C-2R
7212	5.0	.115	.200	5,000	C-2R
7213	5.0	.115	.200	5,000	C-2R