

3 Piece Crimp

BNC three piece crimp connectors feature semi-captive contacts that “click” into place assuring perfect installation. Each crimp pin has a vent hole for optional soldering. Soldering is recommended for all stranded conductors 26 AWG or smaller.

Part Number (Male)	“A” Dim. (I.D.)	Fig. No.	RG/U Cable
310A205A	.200 In.	Fig. 1	6, 21 AWG Center Conductor
310A205A18	.200 In.	Fig. 1	6 CATV, 18 AWG Center Conductor
310A205F	.124 In.	Fig. 1	58A/U, 58C/U Stranded, 141, Thin PVC
310A205FS	.124 In.	Fig. 1	58/U Solid Conductor
310A205FV	.125 In.	Fig. 2	58/U Thin-Net Plenum
310A205FV2	.125 In.	Fig. 2	Mini 59, RGB Cable (23 AWG)
310A205FV3	.125 In.	Fig. 2	Mini 59, RGB Cable (26 AWG)
310A204G	.150 In.	Fig. 1	59, 62, 210
310A205G20	.150 In.	Fig. 1	RG59 20 AWG Center Cond.
310A205G23	.150 In.	Fig. 1	Belden 8241
310A205MV	.125 In.	Fig. 3	174, 178, 196, Mini RGB Cable 50 Ω
310B205MV	.125 In.	Fig. 3	174, 178, 196, Mini RGB Cable 75 Ω
310A205N	.090 In.	Fig. 3	179, 187
310A205P	.125 In.	Fig. 1	223
310B205Q	.205 In.	Fig. 1	Belden 8281 True 75 Ohms
310A204T	.150 In.	Fig. 2	59, 62, Plenum
310A208W2	.103 In.	Fig.1	Mini 59, RGB Cable (26 AWG)

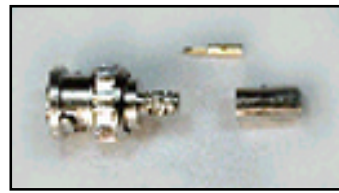


Fig.1



Fig.2



Fig.3



Fig.4

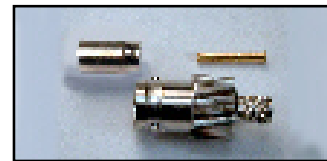


Fig.5