


EDL-612 - PA Loudspeaker

100V

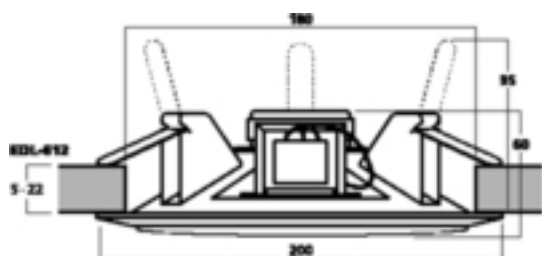

PA ceiling speaker

- 100 V line technique via audio transformer with power taps
- For a ceiling thickness from 5 to 22 mm
- Full range speaker, type 180
- A more powerful reproduction of the range of fundamental notes
- Robust metal version (basket and protective grille)



Technical data

Frequency range	: 100-20,000 Hz
Power capability, 100 V	: 12/6/3 W _{RMS}
Power capability, 8 Ohm	: -
SPL (1 W/m)	: -
Max. rated SPL	: -
Type of speaker	: 180
Mounting cutout	: Ø 180 mm
Mounting depth	: 60 mm
Admiss. ambient temp.	: 0-40 °C
Dimensions	: Ø 200 mm x 60 mm
Weight	: 750 g
Other features	: -