


PIXMA MX495

Affordable, cloud connected, colour All-In-One for the home

Connect to the cloud with this affordable Wi-Fi® All-In-One. Ideal for the home you can print, copy, scan and fax with ease as well as share functions between multiple devices including smartphones and tablets.

Wi-Fi® is trademark of Wi-Fi Alliance

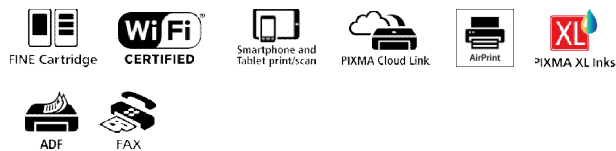

- Wirelessly share print, copy, scan and fax functions using this affordable, space saving All-In-One
- PIXMA Printing Solutions app lets you print from, and scan to smartphones or tablets with ease
- Print from and scan to cloud services – without a PC - using PIXMA Cloud Link
- Optional XL cartridges can save up to 30 % cost per page and last longer between ink replacements
- A 20 sheet Auto Document Feeder enables quick processing of multipage documents

Product Range



PIXMA MX925

PIXMA MX725

PIXMA MX535

PIXMA MX535

PIXMA MX475

PIXMA MX495



PIXMA MX475



PIXMA MX495

Canon

Technical Specifications

GENERAL SPECIFICATIONS

Functions	Wi-Fi, Print, Copy, Scan, Fax, Cloud
PRINTER SPECIFICATIONS	
Print Resolution	Up to 4800 ^[1] x 1200 dpi
Print Technology	2 FINE Cartridges (BK, CL) Inkjet system with 2 pl (min.) ink droplet size Approx. 8.8 ipm ^[2] Approx. 4.4 ipm ^[2]
Mono Document Print Speed	Borderless 10 x 15 cm: Approx. 70 seconds ^[3]
Colour Document Print Speed	Yes (A4, LTR, 20 x 25 cm, 13 x 18 cm, 10 x 15 cm)
Photo Print Speed	Manual
Borderless Printing	
Two Sided Printing	

SCANNER SPECIFICATIONS

Scanner Type	Flatbed & ADF
Scanner Resolution (Optical)	Up to 600 x 1200 dpi ^[4]
A4 Scan Speed	Approx. 15 seconds ^[5]
Maximum Document Size	Flatbed: A4, LTR (216 x 297 mm) ADF: A4, LTR, LGL
(OCR) Optical Character Recognition	Yes
Scanning Depth (Input / Output)	Colour: 48 bit / 24 bit Greyscale: 16 bit / 8 bit

COPIER SPECIFICATIONS

Copy Speed - Colour Document	sFCOT: Approx. 28 seconds ^[6] sESAT: Approx. 3.6 ipm ^[6] sESAT ADF: Approx. 2.7 ipm ^[6]
Multiple Copy	1 to 99 pages
Copy zoom	25 - 400 %
Copy functions	Document Copying, Photo Copying, Fit-to-Page Copying, Borderless Copying
Copy quality settings	Fast, Standard, High

FAX SPECIFICATIONS

Fax Type	Super G3 / Colour
Fax Resolution	Mono: up to 300 x 300 dpi Colour: 200 x 200 dpi
Fax Speed	Mono: approx. 3 sec. (33.6 kbps) ^[7] Colour: approx. 1 min. (33.6 kbps) ^[7]
Fax Memory	Up to 50 pages

COMPATIBLE INKS

Standard Ink Cartridges	PG-545 (Black) CL-546 (Colour)
Optional XL Ink Cartridges	PG-545XL (Black) CL-546XL (Colour)

INK YIELDS

BK (Pigment Black)	Black: 180 pages Black XL: 400 pages
CL (Colour - CMY)	Colour: 180 pages Colour XL: 300 pages
Testing standards	ISO/IEC 24711 for A4 colour document pages Values obtained by continuous printing * Estimated supplemental yield

PAPER SUPPORT

Paper Types	Plain Paper Photo Paper Pro Platinum (PT-101) Photo Paper Plus Glossy II (PP-201) Photo Paper Pro Luster (LU-101) Photo Paper Plus Semi-gloss (SG-201) Glossy Photo Paper "Everyday Use" (GP-501 / GP-601) Matte Photo Paper (MP-101)
Maximum Paper Input	Max. 100 sheets of plain paper Max. 20 sheets of photo paper
Paper Sizes	A4, A5, B5, LTR, LGL, 13 x 18 cm, 10 x 15 cm
Paper Weight	Plain paper: 64 - 105 g/m ² Canon photo paper up to 300 g/m ² (PT-101)

INTERFACE

Interface Type - PC / Mac	Hi-Speed USB (B Port) Wi-Fi: IEEE802.11 b/g/n Wi-Fi Security: WPA-PSK, WPA2-PSK, WEP, Administration password
Interface Type - OTHER	PIXMA Cloud Link (from smartphone / tablet) PIXMA Printing Solutions app Canon Print Service Plugin (Android) Google Cloud Print Access point mode Apple AirPrint

SOFTWARE

Supported Operating System	Windows 8.1 / 8 / 7 / Vista SP1 & SP2 / XP SP3 32-bit Mac OS X v10.7.5 or later
Supported Mobile Systems	iOS Android Windows RT Windows: 3 GB disk space, Internet Explorer 8 Mac: Internet connection, 1.5 GB disk space, Safari 5 Display: 1024 x 768 XGA MP Driver including Scanning Utility Quick Menu My Image Garden Easy-WebPrint EX (plug-in for IE8 or higher)
Minimum System Requirements	
Software Included	

PHYSICAL FEATURES

Display Type & Size	Full dot LCD display
Display languages	English, German, French, Italian, Spanish, Dutch, Portuguese, Norwegian, Swedish, Danish, Finnish, Russian, Czech, Hungarian, Polish, Slovene, Turkish, Greek, Japanese, Simplified Chinese, Traditional Chinese, Korean, Indonesian, Slovak, Estonian, Latvian, Lithuanian, Ukrainian, Romanian, Bulgarian, Croatian, Vietnamese
Automatic Document Feeder	Up to 20-sheets
Dimensions (W x D x H)	approx. 435 x 295 x 189 mm
Weight	5.9 kg
Power Source	AC 100 - 240 V, 50/60 Hz
Power Consumption	Off: Approx. 0.3 W Standby (USB connection to PC): Approx. 0.9 W (scanning lamp off) Standby (all ports connected): Approx. 1.6 W (scanning lamp off) Time to enter Standby mode: 7 minutes Copying: Approx. 7 W ^[8]
Acoustic Noise Levels (Photo 4 x 6)	Approx. 44.5 dB(A) ^[9]
Operating Temperature	15 - 30° C
Operating Humidity	10-90 % RH (no dew condensation)
Duty Cycle	up to 1,000 pages / month
Operating Temperature	15 - 30° C
Operating Humidity	10 - 90 % RH (no dew condensation)
Duty Cycle	up to 1,000 pages / month

Footnotes

- ^[1] Ink droplets can be placed with a minimum pitch of 1/4800 inch
- ^[2] Document print speed on plain paper is measured based on average of ESAT in Office Category Test of ISO/IEC 24734 standard.
- ^[3] Photo print speed is based on default driver setting using ISO/JIS-SCID N2 standard on Canon Photo Paper Plus Glossy II and does not take into account data processing time on host computer.
- ^[4] Optical resolution is a measure of maximum hardware sampling resolution based on ISO 14473 standard. When scanning in high resolution, the scan size is restricted.
- ^[5] Color document scan speed is measured with ISO/IEC 29183 Target A. Scan speed indicates the time measured between pressing the scan button of the scanner driver and the moment the on-screen status display turns off. Scan speed may vary depending on system configuration, interface, software, scan mode settings and document size etc.
- ^[6] Copy speeds for sFCOT and sESAT stated are the averaged results, using the ISO/IEC 29183 test method. ADF copy speed is the average of ESAT in General Performance Test for the default simplex mode, ISO/IEC 24735, excluding time to copy the first set. Copy speed may vary depending on document complexity, copy mode, page coverage, type of paper used etc. and does not take into account warming up time.
- ^[7] Fax transmission speed is based on default setting using ITU-T No.1 chart for mono and Canon Colour Fax Test Sheet for colour. Actual transmission speed may vary depending on document complexity, fax settings at receiving end, and line conditions etc.
- ^[8] When copying ISO/JIS-SCID N2 (printed by inkjet printer) on A4 plain paper using default settings.
- ^[9] When printing ISO/JIS-SCID N2 pattern on 4"x6" Photo Paper Plus Glossy II using default settings.

Standard disclaimers

All specifications subject to change without notice.
Print speed may vary depending on system configuration, interface, software, document complexity, print mode, page coverage, type of paper used etc.
Scan speed may vary depending on system configuration, interface, software, scan mode settings and document size etc.
Copy speed may vary depending on document complexity, copy mode, page coverage: type of paper used etc. and does not take into account warming up time.
Ink yield may vary depending on texts/photos printed, applications software used, print mode and type of paper used. For more information see www.canon-europe.com/ink/yield
All brand and product names are trademarks of their respective companies.

Affordable, cloud connected, colour All-In-One for the home

Connect to the cloud with this affordable Wi-Fi® All-In-One. Ideal for the home you can print, copy, scan and fax with ease as well as share functions between multiple devices including smartphones and tablets.

Wi-Fi® is trademark of Wi-Fi Alliance



Sales Start Date: PIXMA MX495 BK March, 2015
PIXMA MX495 WH April, 2015

Product Details:

Product Name	Mercury Code	EAN Code	Recommended Retail Price
PIXMA MX495 BK DE	0013C006AA	4549292023473	<Please fill in RRP>
PIXMA MX495 WH DE	0013C026AA	4549292041354	<Please fill in RRP>
PIXMA MX495 BK GB	0013C008AA	4549292023497	<Please fill in RRP>
PIXMA MX495 WH GB	0013C028AA	4549292041316	<Please fill in RRP>
PIXMA MX495 BK EUR	0013C009AA	4549292023503	<Please fill in RRP>
PIXMA MX495 WH EUR	0013C029AA	4549292041323	<Please fill in RRP>
PIXMA MX495 BK NORD	<Please fill in>	<Please fill in>	<Please fill in RRP>
PIXMA MX495 WH NORD	<Please fill in>	<Please fill in>	<Please fill in RRP>
PIXMA MX495 BK AT	<Please fill in>	<Please fill in>	<Please fill in RRP>
PIXMA MX495 WH AT	<Please fill in>	<Please fill in>	<Please fill in RRP>
PIXMA MX495 BK CH	<Please fill in>	<Please fill in>	<Please fill in RRP>
PIXMA MX495 WH CH	<Please fill in>	<Please fill in>	<Please fill in RRP>

Optional Accessories:

Consumables	Mercury Code	EAN Code	Recommended Retail Price
PG-545	8287B001AA	4960999974507	<Please fill in RRP>
CL-546	8289B001AA	4960999974521	<Please fill in RRP>
PG-545XL	8286B001AA	4960999974491	<Please fill in RRP>
CL-546XL	8288B001AA	4960999974514	<Please fill in RRP>

PIXMA MX495

Affordable, cloud connected,
colour All-In-One for the home

Connect to the cloud with this affordable Wi-Fi® All-In-One. Ideal for the home you can print, copy, scan and fax with ease as well as share functions between multiple devices including smartphones and tablets.

Wi-Fi® is trademark of Wi-Fi Alliance



Measurement / Logistic Information:

Product Name	Mercury Code	Package Style	Quantity per pack	Length (mm)	Width (mm)	Height (mm)	Net Weight (kg)	Gross Weight (kg)
PIXMA MX495 BK	0013C008AA	Individual	1	555.5	261	381	5.7	7.8
PIXMA MX495 WH	0013C028AA	Pallet (Upper)	16	1117	1050	766.5	-	128.6
		Pallet (Bottom)	24	1117	1050	1147.5	-	192.6

What's in the box?

- All-In-One printer – PIXMA MX495
- Fine cartridges
- Power cord
- Fax cable
- Setup CD-ROM (CD only for Windows – Mac drivers available online*)
- Starter guide

*All drivers and mobile apps are available online at <http://www.canon.com/i/setup>