


Capacitor, film, 12 uF, +/-5% Tol, 470 VAC, Motor Run

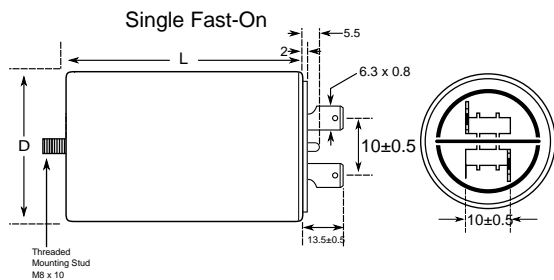

General Information

Supplier:	KEMET
Dielectric:	Film-Foil Polypropylene
Application:	Motor Run
Style:	Round Can
Lead Type:	Fast-On (1+1)
Mounting Type:	Bolt: M8x10
Features:	Safety Class P0, UL_94 V0 Disk
Approvals:	UL,VDE, UL (construction only)
RoHS:	Yes

Dimensions (mm)

Symbol	Dimension	Tolerance
D	35	+1
L	73.5	+/-2

Packaging Specifications

Package Kind:	Bulk
----------------------	------

Specifications

Capacitance:	12 uF
Voltage AC:	470 VAC
Tolerance:	+/-5%
Temperature Range:	-25/+85C
Rated Temperature:	85C
Life:	10000 Hrs
Life:	30000 Hrs 85C 420V
Maximum dVdT:	20 v/us