

# PCB TERMINAL BLOCKS

## 5mm Pitch Standard Profile Terminal Block

- 2 & 3 pole interlocking
- Test probe facility
- Moulded in black  
UL94V-0 PA (GF)
- Wire protector terminals
- UL approved
- Guided pin alignment


CTB1202



TYPE NO.	POLES	LENGTH
CTB1202/2	2	10mm
CTB1202/3	3	15mm
CTB1202/4	4	20mm
CTB1202/5	5	25mm
CTB1202/6	6	30mm
CTB1202/7	7	35mm
CTB1202/8	8	40mm
CTB1202/9	9	45mm
CTB1202/10	10	50mm
CTB1202/11	11	55mm
CTB1202/12	12	60mm

### SPECIFICATION

Rating	300V/10A
Insulation resistance	5000M $\Omega$ at 1000V
Operating temperature	-33°C to 120°C
Clamp	Brass/Steel
Withstand Voltage	AC2000V/1min
Recommended PCB hole size	$\phi$ 1.3mm

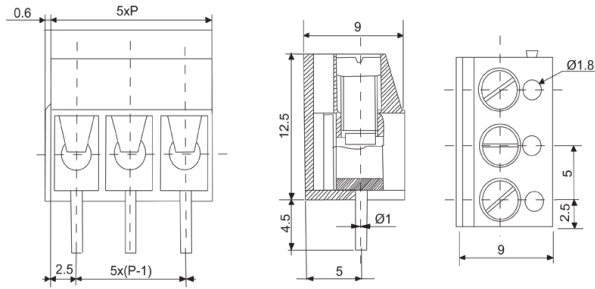

## 10mm Pitch Standard Profile Terminal Block

- 2 & 3 pole interlocking
- Test probe facility
- Moulded in black  
UL94V-0 PA (GF)
- Wire protector terminals
- UL approved
- Guided pin alignment


CTB2202



TYPE NO.	POLES	LENGTH
CTB2202/2	2	20mm
CTB2202/3	3	30mm
CTB2202/4	4	40mm
CTB2202/5	5	50mm
CTB2202/6	6	60mm
CTB2202/7	7	70mm
CTB2202/8	8	80mm
CTB2202/9	9	90mm
CTB2202/10	10	100mm
CTB2202/11	11	110mm
CTB2202/12	12	120mm

### SPECIFICATION

Rating	250V/16A
Insulation resistance	5000M $\Omega$ at 1000V
Operating temperature	-33°C to 120°C
Wire Protector	Stainless Steel
Cable entry	2mm <sup>2</sup>
Withstand Voltage	AC2000V/1min
Recommended PCB hole size	$\phi$ 1.3mm

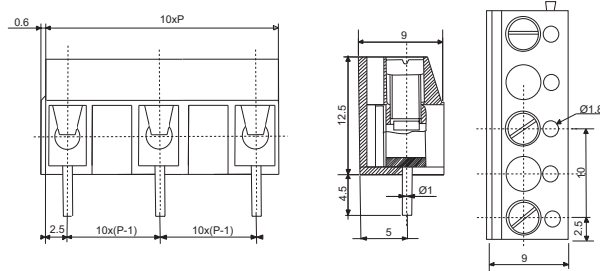

PCB  
TERMINAL  
BLOCKS

INTER-  
CONNECTION

FUSES &  
FUSE-  
HOLDERS

LEDs &  
INDICATORS

MINIATURE  
SWITCHES

LIMIT &  
SAFETY  
SWITCHES

CONTROL  
PRODUCTS

INTERFACE  
MODULES &  
SUPPORTS

RELAY  
BASES

ENCLOSURES

BATTERIES

TRANS-  
FORMERS



+44 (0)1638 716101  
info@camdenboss.com  
www.camdenboss.com

We operate a constant improvement policy,  
our products are subject to change without notice.

**CAMDENBOSS**  
ELECTRONICS & ENCLOSURES

NEW