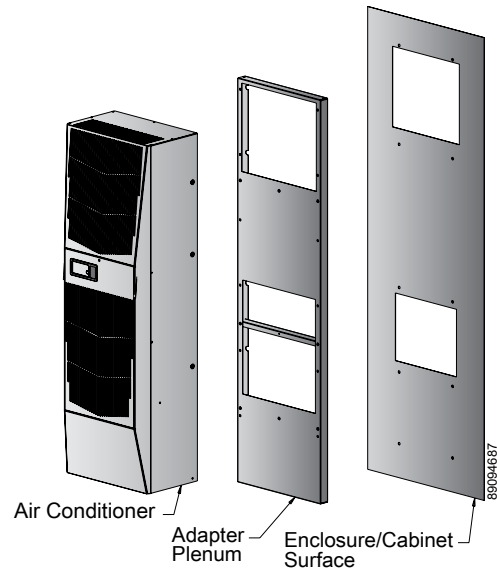


HOFFMAN® EASY SWAP ADAPTOR PLENUMS FOR AIR CONDITIONERS

INDUSTRY STANDARDS

Maintains NEMA Type 12 rating when properly installed on a Type 12 enclosure.

NEMA Type 12
IP 54

APPLICATION

When existing air conditioners are damaged or have reached end-of-life, EASY SWAP Adaptor Plenums provide a quick and easy means for attaching newer Hoffman® air conditioners to the cut-out left on the enclosure.

FEATURES


- No modification of the enclosure required - designed to match the enclosure cut-out and mounting holes of the air conditioner being replaced
- Plenum design allows for optimum air flow (vs. a flat plate that can block the air intake and air outtake left by the older air conditioner)
- Gasket included

SPECIFICATIONS

- 18 gauge steel

FINISH

- Painted to match the standard Hoffman® air conditioner color (light gray)
- Other colors available upon request

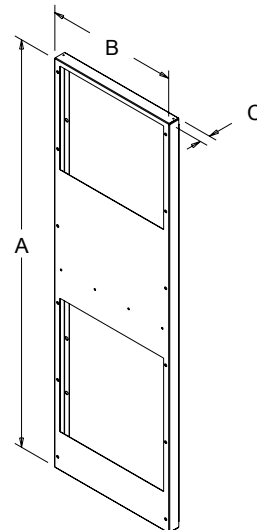

EASY SWAP Adaptor Plenum Cross Reference For Hoffman/McLean

Air Conditioner Manufacturer To Replace	Air Conditioner Series To Replace	Air Conditioner Part Number To Replace	Use This Hoffman Air Conditioner Catalog Number	With This Adaptor Plenum Catalog Number	Adaptor Plenum Dimensions AxBxC* (in./mm)
Hoffman/McLean	Genesis	M130116G014	N170116G010	PLM13N17	17.65x14.25x1.50 448x362x38
Hoffman/McLean	Genesis	M130116G014	N170126G010	PLM13N17	17.65x14.25x1.50 448x362x38
Hoffman/McLean	Genesis	M130116G014	N170146G010	PLM13N17	17.65x14.25x1.50 448x362x38
Hoffman/McLean	Genesis	M170216G009	N170216G010	Not Required	---
Hoffman/McLean	Genesis	M170226G004	N170226G010	Not Required	---
Hoffman/McLean	Genesis	M170246G400	N170246G010	Not Required	---
Hoffman/McLean	Genesis	M280216G013	N170216G010	PLM28N17	28.50x17.00x1.50 724x432x38
Hoffman/McLean	Genesis	M280226G004	N170226G010	PLM28N17	28.50x17.00x1.50 724x432x38
Hoffman/McLean	Genesis	M280246G400	N170246G010	PLM28N17	28.50x17.00x1.50 724x432x38
Hoffman/McLean	Genesis	M280416G007	G280416G050	PLM28G28	28.50x17.00x1.50 724x432x38
Hoffman/McLean	Genesis	M280426G032	G280426G050	PLM28G28	28.50x17.00x1.50 724x432x38
Hoffman/McLean	Genesis	M280446G400	G280446G050	PLM28G28	28.50x17.00x1.50 724x432x38
Hoffman/McLean	Genesis	M280616G005	G280616G050	PLM28G28	28.50x17.00x1.50 724x432x38
Hoffman/McLean	Genesis	M280626G005	G280626G050	PLM28G28	28.50x17.00x1.50 724x432x38
Hoffman/McLean	Genesis	M280646G400	G280646G050	PLM28G28	28.50x17.00x1.50 724x432x38
Hoffman/McLean	Genesis	M330416G010	N280416G050	PLM33N28	34.31x12.00x1.50 871x305x38
Hoffman/McLean	Genesis	M330426G009	N280426G050	PLM33N28	34.31x12.00x1.50 871x305x38
Hoffman/McLean	Genesis	M330446G400	N280446G050	PLM33N28	34.31x12.00x1.50 871x305x38
Hoffman/McLean	Genesis	M360616G307	N360616G050	PLM36N36	38.75x15.00x1.50 984x381x38
Hoffman/McLean	Genesis	M360626G306	N360626G050	PLM36N36	38.75x15.00x1.50 984x381x38
Hoffman/McLean	Genesis	M360646G400	N360646G050	PLM36N36	38.75x15.00x1.50 984x381x38
Hoffman/McLean	Genesis	M520816032	G520816G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Hoffman/McLean	Genesis	M520826015	G520826G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Hoffman/McLean	Genesis	M520846G002	G520846G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Hoffman/McLean	Genesis	M521046G002	G521246G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Hoffman/McLean	Genesis	M521216017	G521216G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Hoffman/McLean	Genesis	M521226034	G521226G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Hoffman/McLean	T-Series	T290416G100	G280416G050	PLT29G28	28.50x17.00x1.50 724x432x38
Hoffman/McLean	T-Series	T290416G150	G280416G150	PLT29G28	28.50x17.00x1.50 724x432x38
Hoffman/McLean	T-Series	T290426G100	G280426G050	PLT29G28	28.50x17.00x1.50 724x432x38
Hoffman/McLean	T-Series	T290426G150	G280426G150	PLT29G28	28.50x17.00x1.50 724x432x38
Hoffman/McLean	T-Series	T290446G400	G280446G050	PLT29G28	28.50x17.00x1.50 724x432x38
Hoffman/McLean	HC52	HC52 SERIES	G57XXXXXXXX	PLHC52G57	57.60x22.97x1.50 1463x583x38
Hoffman/McLean	HC52	HC52 SERIES	T53XXXXXXXX	PLHC52T53	52.85x23.00x1.50 1342x584x38

*Prior to ordering, ensure Adaptor Plenum dimensions do not exceed available space on the enclosure mounting surface. Please contact Customer Service for support in finding an appropriate cross for older Hoffman/McLean models not shown above.

EASY SWAP Adaptor Plenum Cross Reference For ISC

Air Conditioner Manufacturer To Replace	Air Conditioner Series To Replace	Air Conditioner Part Number To Replace	Use This Hoffman Air Conditioner Catalog Number	With This Adaptor Plenum Catalog Number	Adaptor Plenum Dimensions AxBxC* (in./mm)
ISC	Narrow Edge Series	ISC-NE-010-126-12	N170116G010	PLKTN17	19.00x12.00x1.50 483x305x38
ISC	Narrow Edge Series	ISC-NE-010-236-12	N170126G010	PLKTN17	19.00x12.00x1.50 483x305x38
ISC	Narrow Edge Series	ISC-NE-015-126-12	N170216G010	PLKTN17	19.00x12.00x1.50 483x305x38
ISC	Narrow Edge Series	ISC-NE-015-236-12	N170226G010	PLKTN17	19.00x12.00x1.50 483x305x38
ISC	Narrow Edge Series	ISC-NE-020-126-12	N280416G050	PLRN28	29.00x11.50x150 737x292x38
ISC	Narrow Edge Series	ISC-NE-020-236-12	N280426G050	PLRN28	29.00x11.50x150 737x292x38
ISC	Narrow Edge Series	ISC-NE-030-126-12	N280416G050	PLKTN28	33.25x12.25x1.50 845x311x38
ISC	Narrow Edge Series	ISC-NE-030-236-12	N280426G050	PLKTN28	33.25x12.25x1.50 845x311x38
ISC	Narrow Edge Series	ISC-NE-040-126-12	N280416G050	PLKTN28	33.25x12.25x1.50 845x311x38
ISC	Narrow Edge Series	ISC-NE-040-236-12	N280426G050	PLKTN28	33.25x12.25x1.50 845x311x38
ISC	Narrow Edge Series	ISC-NE-050-126-12	N360616G050	PLPN36	36.50x12.00x1.50 927x305x38
ISC	Narrow Edge Series	ISC-NE-050-236-12	N360626G050	PLPN36	36.50x12.00x1.50 927x305x38
ISC	Narrow Edge Series	ISC-NE-060-126-12	N360616G050	PLPN36	36.50x12.00x1.50 927x305x38
ISC	Narrow Edge Series	ISC-NE-060-236-12	N360626G050	PLPN36	36.50x12.00x1.50 927x305x38
ISC	Narrow Edge Series	ISC-NE-080-126-12	N360816G050	PLPN36	36.50x12.00x1.50 927x305x38
ISC	Narrow Edge Series	ISC-NE-080-236-12	N360826G050	PLPN36	36.50x12.00x1.50 927x305x38

*Prior to ordering, ensure Adaptor Plenum dimensions do not exceed available space on the enclosure mounting surface.

ISC is a registered trademark of ISC Sales, Inc.

EASY SWAP Adaptor Plenum Cross Reference For Kooltronic

Air Conditioner Manufacturer To Replace	Air Conditioner Series To Replace	Air Conditioner Part Number To Replace	Use This Hoffman Air Conditioner Catalog Number	With This Adaptor Plenum Catalog Number	Adaptor Plenum Dimensions AxBxC ¹ (in./mm)
Kooltronic	Micro-Mini	KA4C1.0MML	M130116G1014	Not Required	---
Kooltronic	Micro-Mini	K2A4C1.0MML	M130126G1008	Not Required	---
Kooltronic	TrimLine Series NP17	KA4C2.0NP17L	N170216G010	PLKTN17	19.00x12.00x1.50 483x305x38
Kooltronic	TrimLine Series NP17	K2A4C2.0NP17L	N170226G010	PLKTN17	19.00x12.00x1.50 483x305x38
Kooltronic	TrimLine Series Narrow-Mini	KA4C2.5NML	N170216G010	PLKTN17	19.00x12.00x1.50 483x305x38
Kooltronic	TrimLine Series Narrow-Mini	K2A4C2.5NML	N170226G010	PLKTN17	19.00x12.00x1.50 483x305x38
Kooltronic	TrimLine NP28	KA4C4NP28L	N280416G050	PLRN28	29.00x11.50x1.50 737x292x38
Kooltronic	TrimLine NP28	K2A4C4NP28L	N280426G050	PLRN28	29.00x11.50x1.50 737x292x38
Kooltronic	TrimLine NP33	KA4C4NP33L	N280416G050	PLKTN28	33.25x12.25x1.50 845x311x38
Kooltronic	TrimLine NP33	K2A4C4NP33L	N280426G050	PLKTN28	33.25x12.25x1.50 845x311x38
Kooltronic	TrimLine NPT33	KA6C4NPT33L	N280416G050	PLKTN28	33.25x12.25x1.50 845x311x38
Kooltronic	TrimLine NPT33	K2A6C4NPT33L	N280426G050	PLKTN28	33.25x12.25x1.50 845x311x38
Kooltronic	TrimLine NP36	KA4C4NP36L	G280416G050	PLRG28	37.40x16.97x1.50 950x431x38
Kooltronic	TrimLine NP36	K2A4C4NP36L	G280426G050	PLRG28	37.40x16.97x1.50 950x431x38
Kooltronic	TrimLine NP36	KA4C6NP36R	G280616G050	PLRG28	37.40x16.97x1.50 950x431x38
Kooltronic	TrimLine NP36	K2A4C6NP36L	G280626G050	PLRG28	37.40x16.97x1.50 950x431x38
Kooltronic	TrimLine NP47	KA4C7NP47R	G520816G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Kooltronic	TrimLine NP47	K2A4C7NP47L	G520826G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Kooltronic	TrimLine NPT47	KA6C10NPT47L	G520816G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Kooltronic	TrimLine NPT47	K2A6C10NPT47L	G520826G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Kooltronic	TrimLine NPT47	K2A6C10NPT47L	G520826G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Kooltronic	TrimLine NPT47	K2A6C13NPT47L	G520826G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Kooltronic	TrimLine NPT47	K2A6C13NPT47L	G520826G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Kooltronic	Traditional Series P28	KA4C4P28L	G280416G050	PLKG28	36.87x19.13x1.50 936x486x38
Kooltronic	Traditional Series P28	K2A4C4P28L	G280426G050	PLKG28	36.87x19.13x1.50 936x486x38
Kooltronic	Traditional Series P28	KA4C6P28R	G280616G050	PLKG28	36.87x19.13x1.50 936x486x38
Kooltronic	Traditional Series P28	K2A4C6P28L	G280626G050	PLKG28	36.87x19.13x1.50 936x486x38
Kooltronic	Traditional Series P36	KA4C4P36L	G280416G050	PLKG28	36.87x19.13x1.50 936x485x38
Kooltronic	Traditional Series P36	K2A4C4P36L	G280426G050	PLKG28	36.87x19.13x1.50 936x485x38
Kooltronic	Traditional Series P36	KA4C6P36R	G280616G050	PLKG28	36.87x19.13x1.50 936x485x38
Kooltronic	Traditional Series P36	K2A4C6P36L	G280626G050	PLKG28	36.87x19.13x1.50 936x485x38
Kooltronic	Traditional Series P47	KA4C6P47R	G520816G050	PLKG52	52.56x19.13x1.50 1335x485x38
Kooltronic	Traditional Series P47	K2A4C6P47L	G520826G050	PLKG52	52.56x19.13x1.50 1335x485x38
Kooltronic	Traditional Series P47	K2A4C12P47L	G521226G050	PLKG52	52.56x19.13x1.50 1335x485x38
Kooltronic	Traditional Series P52	KA4C6P52R	G520816G050	PLKG52	52.56x19.13x1.50 1335x485x38
Kooltronic	Traditional Series P52	K2A4C6P52L	G520826G050	PLKG52	52.56x19.13x1.50 1335x485x38
Kooltronic	Traditional Series P52	K2A4C12P52L	G521226G050	PLKG52	52.56x19.13x1.50 1335x485x38

*Prior to ordering, ensure Adaptor Plenum dimensions do not exceed available space on the enclosure mounting surface.

Kooltronic is a registered trademark of Kooltronic, Inc.

EASY SWAP Adaptor Plenum Cross Reference For Pfannenberg

Air Conditioner Manufacturer To Replace	Air Conditioner Series To Replace	Air Conditioner Part Number To Replace	Use This Hoffman Air Conditioner Catalog Number	With This Adaptor Plenum Catalog Number	Adaptor Plenum Dimensions AxBxC* (in./mm)
Pfannenberg	DTS 1200	13340110055	M130126G1008	Not Required	---
Pfannenberg	DTS 1200	13340110200	M130126G1008	Not Required	---
Pfannenberg	DTS 1200	13340114055	M130116G014	Not Required	---
Pfannenberg	DTS 1200	13340114200	M130116G014	Not Required	---
Pfannenberg	DTS 2000	13340210055	N170226G010	Not Required	---
Pfannenberg	DTS 2000	13340210200	N170226G010	Not Required	---
Pfannenberg	DTS 2000	13340214055	N170216G010	Not Required	---
Pfannenberg	DTS 2000	13340214200	N170216G010	Not Required	---
Pfannenberg	DTS 3041	13382341251	T200226G100	Not Required	---
Pfannenberg	DTS 3041	13382341255	T200226G100	Not Required	---
Pfannenberg	DTS 3041	13382344251	T200216G100	Not Required	---
Pfannenberg	DTS 3041	13382344255	T200216G100	Not Required	---
Pfannenberg	DTS 3041	13385436251	G280446G050	PLRG28	37.40x16.97x1.50 950x431x38
Pfannenberg	DTS 3041	13385436255	G280446G050	PLRG28	37.40x16.97x1.50 950x431x38
Pfannenberg	DTS 3041	13385441251	G280426G050	PLRG28	37.40x16.97x1.50 950x431x38
Pfannenberg	DTS 3041	13385441255	G280426G050	PLRG28	37.40x16.97x1.50 950x431x38
Pfannenberg	DTS 3041	13385444251	G280416G050	PLRG28	37.40x16.97x1.50 950x431x38
Pfannenberg	DTS 3041	13385444255	G280416G050	PLRG28	37.40x16.97x1.50 950x431x38
Pfannenberg	DTS 3141 SL	13383436251	N360646G050	PLPN36	36.50x12.00x1.50 927x305x38
Pfannenberg	DTS 3141 SL	13383436255	N360646G050	PLPN36	36.50x12.00x1.50 927x305x38
Pfannenberg	DTS 3141 SL	13383441251	N360626G050	PLPN36	36.50x12.00x1.50 927x305x38
Pfannenberg	DTS 3141 SL	13383441255	N360626G050	PLPN36	36.50x12.00x1.50 927x305x38
Pfannenberg	DTS 3141 SL	13383444251	N360616G050	PLPN36	36.50x12.00x1.50 927x305x38
Pfannenberg	DTS 3141 SL	13383444255	N360616G050	PLPN36	36.50x12.00x1.50 927x305x38
Pfannenberg	DTS 3145	13383636251	N360846G050	PLPN36	36.50x12.00x1.50 927x305x38
Pfannenberg	DTS 3145	13383636255	N360846G050	PLPN36	36.50x12.00x1.50 927x305x38
Pfannenberg	DTS 3145	13383639251	N360826G050	PLPN36	36.50x12.00x1.50 927x305x38
Pfannenberg	DTS 3145	13383639255	N360826G050	PLPN36	36.50x12.00x1.50 927x305x38
Pfannenberg	DTS 3145	13383644251	N360821G050	PLPN36	36.50x12.00x1.50 927x305x38
Pfannenberg	DTS 3145	13383644255	N360821G050	PLPN36	36.50x12.00x1.50 927x305x38
Pfannenberg	DTS 3241	13385736251	G520846G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Pfannenberg	DTS 3241	13385736255	G520846G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Pfannenberg	DTS 3241	13385741251	G520826G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Pfannenberg	DTS 3241	13385741255	G520826G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Pfannenberg	DTS 3241	13385744251	G520816G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Pfannenberg	DTS 3241	13385744255	G520816G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Pfannenberg	DTS 3245	13383836251	G521246G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Pfannenberg	DTS 3245	13383836255	G521246G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Pfannenberg	DTS 3245	13383839251	G521226G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Pfannenberg	DTS 3245	13383839255	G521226G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Pfannenberg	DTS 3245	13383844251	G521216G050	PLM52G52	52.56x17.03x1.50 1335x433x38
Pfannenberg	DTS 3245	13383844255	G521216G050	PLM52G52	52.56x17.03x1.50 1335x433x38

*Prior to ordering, ensure Adaptor Plenum dimensions do not exceed available space on the enclosure mounting surface.

Pfannenberg is a registered trademark of Pfannenberg Incorporated

EASY SWAP Adaptor Plenum Cross Reference For Rittal

Air Conditioner Manufacturer To Replace	Air Conditioner Series To Replace	Air Conditioner Part Number To Replace	Use This Hoffman Air Conditioner Catalog Number	With This Adaptor Plenum Catalog Number	Adaptor Plenum Dimensions AxBxC* (in./mm)
Rittal	Top-Therm - Exterior Mount Only**	3302.100	N170126G010	PLR1N17	21.65x13.00x1.50 550x330x38
Rittal	Top-Therm - Exterior Mount Only**	3302.110	N170116G010	PLR1N17	21.65x13.00x1.50 550x330x38
Rittal	Top-Therm - Exterior Mount Only**	3302.300	M130126G1008	PLRM13	20.67x13.38x1.50 525x340x38
Rittal	Top-Therm - Exterior Mount Only**	3302.310	M130116G1014	PLRM13	20.67x13.38x1.50 525x340x38
Rittal	Top-Therm - Exterior Mount Only**	3303.100	N170226G010	PLR2N17	21.65x12.00x1.50 550x305x38
Rittal	Top-Therm - Exterior Mount Only**	3303.500	N170226G010	PLR2N17	21.65x12.00x1.50 550x305x38
Rittal	Top-Therm - Exterior Mount Only**	3303.110	N170216G010	PLR2N17	21.65x12.00x1.50 550x305x38
Rittal	Top-Therm - Exterior Mount Only**	3303.510	N170216G010	PLR2N17	21.65x12.00x1.50 550x305x38
Rittal	Top-Therm - Exterior Mount Only**	3304.100	G280426G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Top-Therm - Exterior Mount Only**	3304.500	G280426G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Top-Therm - Exterior Mount Only**	3304.110	G280416G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Top-Therm - Exterior Mount Only**	3304.510	G280416G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Top-Therm - Exterior Mount Only**	3304.140	G280446G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Top-Therm - Exterior Mount Only**	3304.540	G280446G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Top-Therm - Exterior Mount Only**	3305.100	G280626G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Top-Therm - Exterior Mount Only**	3305.500	G280626G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Top-Therm - Exterior Mount Only**	3305.110	G280616G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Top-Therm - Exterior Mount Only**	3305.510	G280616G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Top-Therm - Exterior Mount Only**	3305.140	G280646G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Top-Therm - Exterior Mount Only**	3305.540	G280646G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Top-Therm - Exterior Mount Only**	3328.100	G520826G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Top-Therm - Exterior Mount Only**	3328.500	G520826G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Top-Therm - Exterior Mount Only**	3328.110	G520816G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Top-Therm - Exterior Mount Only**	3328.510	G520816G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Top-Therm - Exterior Mount Only**	3328.140	G520846G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Top-Therm - Exterior Mount Only**	3328.540	G520846G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Top-Therm - Exterior Mount Only**	3329.100	G521226G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Top-Therm - Exterior Mount Only**	3329.500	G521226G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Top-Therm - Exterior Mount Only**	3329.110	G521216G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Top-Therm - Exterior Mount Only**	3329.510	G521216G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Top-Therm - Exterior Mount Only**	3329.140	G521246G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Top-Therm - Exterior Mount Only**	3329.540	G521246G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Top-Therm - Exterior Mount Only**	3332.140	G572046G050	PLRG57	61.13x20.88x1.50 1552x530x38
Rittal	Top-Therm - Exterior Mount Only**	3332.540	G572046G050	PLRG57	61.13x20.88x1.50 1552x530x38
Rittal	Top-Therm - Exterior Mount Only**	3361.100	N280426G050	PLRN28	29.00x11.50x150 737x292x38

Air Conditioner Manufacturer To Replace	Air Conditioner Series To Replace	Air Conditioner Part Number To Replace	Use This Hoffman Air Conditioner Catalog Number	With This Adaptor Plenum Catalog Number	Adaptor Plenum Dimensions AxBxC* (in./mm)
Rittal	Top-Therm - Exterior Mount Only**	3361.500	N280426G050	PLRN28	29.00x11.50x150 737x292x38
Rittal	Top-Therm - Exterior Mount Only**	3361.110	N280416G050	PLRN28	29.00x11.50x150 737x292x38
Rittal	Top-Therm - Exterior Mount Only**	3361.510	N280416G050	PLRN28	29.00x11.50x150 737x292x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3203.100	N170126G010	PLR1N17	21.65x13.00x1.50 550x330x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3204.100	M130126G1008	PLRM13	20.67x13.38x1.50 525x340x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3205.100	N170116G010	PLR1N17	21.65x13.00x1.50 550x330x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3206.100	M130116G1014	PLRM13	20.67x13.38x1.50 525x340x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3281.100	G280416G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3293.100	G280426G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3293.140	G280446G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3293.146	G280446G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3381.100	G280416G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3390.100	G520826G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3390.115	G520816G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3390.140	G520846G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3390.146	G520846G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3391.123	G572026G050	PLRG57	61.13x20.88x1.50 1552x530x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3391.140	G572046G050	PLRG57	61.13x20.88x1.50 1552x530x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3391.146	G572046G050	PLRG57	61.13x20.88x1.50 1552x530x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3392.100	G521226G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3392.115	G521216G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3392.146	G521246G050	PLRG52	61.13x17.13x1.50 1552x435x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3393.100	G280426G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3393.140	G280446G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3393.146	G280446G050	PLRG28	37.40x16.97x1.50 950x431x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3279.100	G280616G050	PLR2G28	49.80x16.97x1.50 1265x431x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3298.100	G280626G050	PLR2G28	49.80x16.97x1.50 1265x431x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3260.146	G280646G050	PLR2G28	49.80x16.97x1.50 1265x431x38
Rittal	Legacy (Pre Top-Therm) - Exterior Mount Only**	3367.200	N360826G050	PLRN36	38.00x15.75x1.50 965x400x38

*Prior to ordering, ensure Adaptor Plenum dimensions do not exceed available space on the enclosure mounting surface.

**Adaptor Plenums are not suitable for replacing partial-recessed or fully-recessed mounted air conditioners.

Rittal is a registered trademark of Rittal Corporation

EASY SWAP Adaptor Plenum Cross Reference For Thermal Edge

Air Conditioner Manufacturer To Replace	Air Conditioner Series To Replace	Air Conditioner Part Number To Replace	Use This Hoffman Air Conditioner Catalog Number	With This Adaptor Plenum Catalog Number	Adaptor Plenum Dimensions AxBxC* (in./mm)
Thermal Edge	NE Series - Narrow Edge	NE010-126-12	N170116G010	PLKTN17	19.00x12.00x1.50 483x305x30
Thermal Edge	NE Series - Narrow Edge	NE010-236-12	N170126G010	PLKTN17	19.00x12.00x1.50 483x305x30
Thermal Edge	NE Series - Narrow Edge	NE015-126-12	N170216G010	PLKTN17	19.00x12.00x1.50 483x305x30
Thermal Edge	NE Series - Narrow Edge	NE015-236-12	N170226G010	PLKTN17	19.00x12.00x1.50 483x305x30
Thermal Edge	NE Series - Narrow Edge	NE020-126-12	N280416G050	PLRN28	29.00x11.50x1.50 737x292x38
Thermal Edge	NE Series - Narrow Edge	NE020-236-12	N280426G050	PLRN28	29.00x11.50x1.50 737x292x38
Thermal Edge	NE Series - Narrow Edge	NE030-126-12	N280416G050	PLKTN28	33.25x12.25x1.50 845x311x38
Thermal Edge	NE Series - Narrow Edge	NE030-236-12	N280426G050	PLKTN28	33.25x12.25x1.50 845x311x38
Thermal Edge	NE Series - Narrow Edge	NE040-126-12	N280416G050	PLKTN28	33.25x12.25x1.50 845x311x38
Thermal Edge	NE Series - Narrow Edge	NE040-236-12	N280426G050	PLKTN28	33.25x12.25x1.50 845x311x38
Thermal Edge	NE Series - Narrow Edge	NE050-126-12	N360616G050	PLPN36	36.50x12.00x1.50 927x305x38
Thermal Edge	NE Series - Narrow Edge	NE050-236-12	N360626G050	PLPN36	36.50x12.00x1.50 927x305x38
Thermal Edge	NE Series - Narrow Edge	NE060-126-12	N360616G050	PLPN36	36.50x12.00x1.50 927x305x38
Thermal Edge	NE Series - Narrow Edge	NE060-236-12	N360626G050	PLPN36	36.50x12.00x1.50 927x305x38
Thermal Edge	NE Series - Narrow Edge	NE080-126-12	N360816G050	PLPN36	36.50x12.00x1.50 927x305x38
Thermal Edge	NE Series - Narrow Edge	NE080-236-12	N360826G050	PLPN36	36.50x12.00x1.50 927x305x38

*Prior to ordering, ensure Adaptor Plenum dimensions do not exceed available space on the enclosure mounting surface.

Thermal Edge is a registered trademark of Thermal Edge, Inc.