

Item #	Description	Color	1-9	10-24	25-99	100+
--------	-------------	-------	-----	-------	-------	------

**USB Coil Cable - Type A Latching Connector to Type B Connector, 12.5 Feet (3.8m) Extended**

This unique cable assembly features a polyurethane jacketed coil cable plus a latching Type A USB connector providing improved mating retention with any USB Type A jack. The latches lock into the channels on each side of a USB jack when fully mated. Retracted length is approximately 2.5 feet (0.8m) expanding to 12.5 feet (3.8m). Fully shielded and USB 2.0 compliant, this cable contains two 28 AWG power conductors plus one 28 AWG twisted pair for data lines.

COILUAB	USB Coil Cable, Latching Type A Male/Type B Male	Black	18.65	17.90	17.16	CALL
---------	--	-------	-------	-------	-------	------



COILUAB

**Variable Length USB Coil Cable - Mini B 5 Position Male to Female**

This innovative USB coil cable from L-com features a retracted length 0.5 meters and an expanded length of two meters and can be used with GPS systems as well as cameras and other peripherals using the USB Mini B5 interface. All 5 mini B positions are connected to insure proper functionality in every application. The tough, durable polyurethane jacket enhances recoil memory and 30 microinch (0.762µm) gold plated contacts provide reliable connections with repeated mating cycles.

COILMB5EXT-2M	USB Coil Cable, Mini B 5 Position Male/Female, 0.5m to 2.0m	Black	12.65	11.64	10.63	CALL
---------------	---	-------	-------	-------	-------	------




COILMB5EXT-2M

**USB 2.0 Adapters - Molded and Fully Shielded**

These adapters provide an economical way for users to solve gender and connector type mismatches among standard USB connectors.

UAD010MF	USB Adapter, Type A Male/Type B Female	Lt. Gray	4.80	4.70	4.51	CALL
UAD011FM	USB Adapter, Type A Female/Type B Male	Lt. Gray	4.80	4.70	4.51	CALL
UAD012FF	USB Adapter, Type B Female/Type B Female	Lt. Gray	4.80	4.70	4.51	CALL
UAD013FF	USB Adapter, Type A Female/Type B Female	Lt. Gray	4.80	4.70	4.51	CALL
UAD014MM	USB Adapter, Type A Male/Type A Male	Lt. Gray	4.80	4.70	4.51	CALL
UAD015FF	USB Adapter, Type A Female/Type A Female	Lt. Gray	4.80	4.70	4.51	CALL
UAD016MM	USB Adapter, Type B Male/Type B Male	Lt. Gray	4.80	4.70	4.51	CALL
UAD017FM	USB Adapter, Type A Female/Mini DIN 6 Male	Green	4.80	4.70	4.51	CALL
UAD018MF	USB Adapter, Type A Male/Mini DIN 6 Female	Lt. Gray	4.80	4.70	4.51	CALL
UAD019FM	USB Adapter, Type A Female/Mini-B5 Male	Black	4.80	4.70	4.51	CALL
UAD026MF	USB Adapter, Type A Male/Female	Lt. Gray	4.80	4.70	4.51	CALL
UAD027MF	USB Adapter, Type B Male/Female	Lt. Gray	4.80	4.70	4.51	CALL

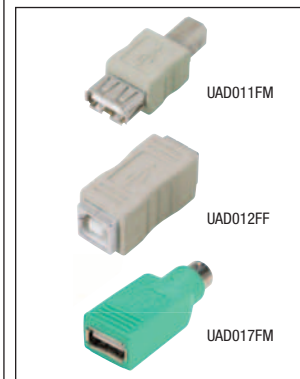

UAD011FM

UAD012FF

UAD017FM

**USB 2.0 Micro B Adapters**

UAD030MF	USB Adapter, Micro B Male/Mini B5 Female	Black	4.80	4.70	4.51	CALL
UAD031MM	USB Adapter, Micro B Male/Standard A Male	Black	4.80	4.70	4.51	CALL
UAD032FM	USB Adapter, Micro B Male/Standard A Female	Lt. Gray	4.80	4.70	4.51	CALL
UAD033FM	USB Adapter, Micro B Male/Standard B Female	Lt. Gray	4.80	4.70	4.51	CALL

**USB 3.0 Adapters**

UAD035MF	USB 3.0 Socket Saver, Type A Male/Type A Female	Blue	9.80	9.60	9.21	CALL
UAD036FF	USB 3.0 Gender Changer, Type A Female/Type A Female	Blue	9.80	9.60	9.21	CALL
UAD037MM	USB 3.0 Gender Changer, Type A Male/Type A Male	Blue	9.80	9.60	9.21	CALL

**USB Type A Low Profile Right Angle Adapters**

L-com's UADAA90 series low profile right angle USB adapters are perfect for tight fit applications. Two exit options are available allowing cables to exit in opposite directions. These USB adapters are a much lower cost solution when compared to rotating USB adapters.

UADAA90-1	Right Angle USB Adapter, Type A Male/Female, Exit 1	Lt. Gray	5.69	5.23	4.78	CALL
UADAA90-2	Right Angle USB Adapter, Type A Male/Female, Exit 2	Lt. Gray	5.69	5.23	4.78	CALL

**USB Type B Low Profile Right Angle Adapters**


L-com's UADBB90 series low profile right angle USB adapters feature two exit options allowing cables to exit in opposite directions. Our UADBB90 series USB adapters are a much lower cost solution when compared to rotating USB adapters. Additionally, these robust 90° USB adapters feature 20 AWG power leads for maximum power transfer and 100% shielding throughout for protection against data corrupting EMI/RFI.

UADBB90-1	Right Angle USB Adapter, Type B Male/Female, Exit 1	Lt. Gray	5.69	5.23	4.78	CALL
UADBB90-2	Right Angle USB Adapter, Type B Male/Female, Exit 2	Lt. Gray	5.69	5.23	4.78	CALL

**USB 2.0 Mini B5 or Micro B Male to Female Low Profile Right Angle Adapters**

L-com's low profile right angle USB adapters are perfect for tight fit applications. Two exit options are available allowing cables to exit in opposite directions. Additionally, these robust 90° USB adapters feature 30 microinch (0.762µm) gold plated contacts to stand up to many mating cycles and 100% shielding throughout for protection against data corrupting EMI/RFI.

UAD2.0MB5-1	Right Angle USB Adapter, Mini B Male/Female, Exit 1	Black	5.69	5.23	4.78	CALL
UAD2.0MB5-2	Right Angle USB Adapter, Mini B Male/Female, Exit 2	Black	5.69	5.23	4.78	CALL
UAD2.0MICB-1	Right Angle USB Adapter, Micro B Male/Female, Exit 1	Black	5.69	5.23	4.78	CALL
UAD2.0MICB-2	Right Angle USB Adapter, Micro B Male/Female, Exit 2	Black	5.69	5.23	4.78	CALL

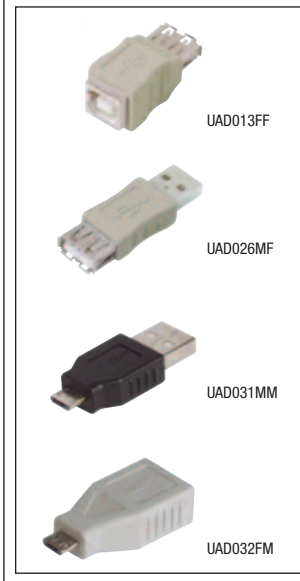


UAD013FF

UAD026MF

UAD031MM

UAD032FM

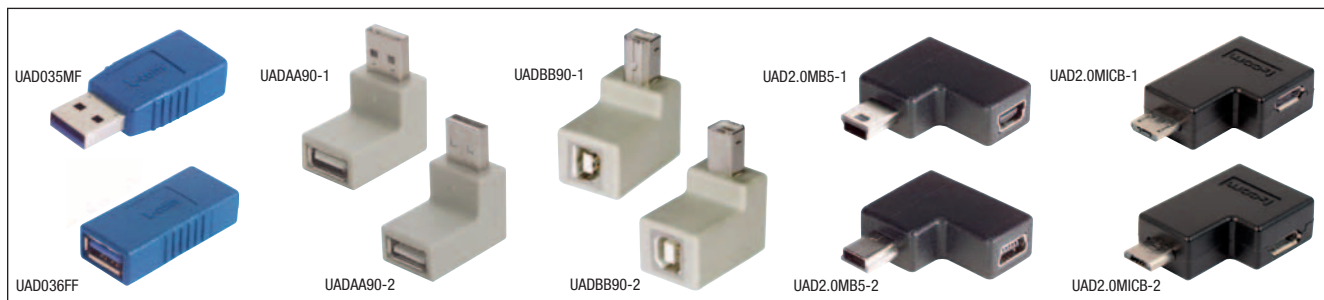

UAD035MF

UADAA90-1

UADBB90-1

UAD2.0MB5-1

UAD2.0MICB-1

UAD036FF

UADAA90-2

UADBB90-2

UAD2.0MB5-2

UAD2.0MICB-2