
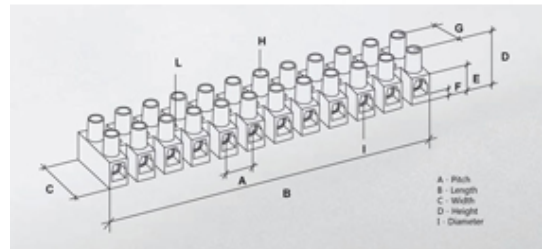


OK435/12 FV

12 pole red-brown polyamide PA6.6, with 25% glass fibre reinforced pillar terminal block 14.5mm pitch 76a 450v

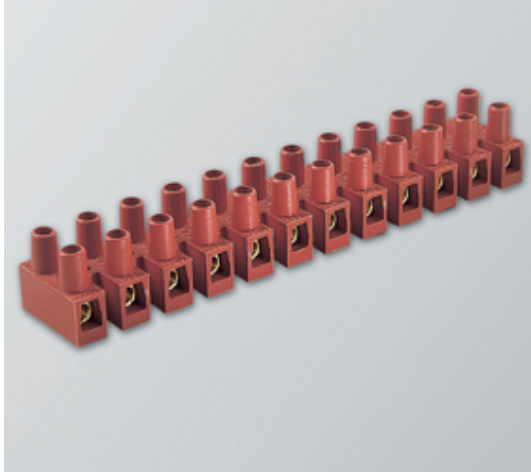

SPECIFICATION

Number of Poles	12
Terminal Material	OT58 nickel plated
Body Material	Polyamide PA6.6, with 25% glass fibre reinforced
Colour	Red-brown
Glow Wire Resistance Test Temp	GWT750°C in 2 sec (EN60695-2-11)
Max Conductor Size (Sq mm)	16
Max Current (A)	76
Max Voltage (V)	450
Working Temperature	150
Pitch (mm)	14.5
Height (mm)	25
Width (mm)	32.2
Length (mm)	173.5
Diameter (mm)	5.8
Terminal Screw Material	White zinc plated steel