

EAO – Your Expert Partner for Human Machine Interfaces

45-2C36.1920.000 - Emergency-stop switch actuator, foolproof EN IEC 60947-5-5

45-2C36.1920.000 - Emergency-stop switch actuator, foolproof EN IEC 60947-5-5



Attention: The preview is based on a sample product. This can differ from your current configuration.

Mounting

Mounting cut-out Design Ø 22.5 mm raised

Front

Front shape round
Front dimension Ø 40 mm
Front ring material Plastic
Front ring colour black

Other Attributes

Weight 0.046 kg

Operating-/Indication part

Lens optics opaque
Lens material Plastic
Lens colour red
Lens profile Mushroom
Lens illumination non-illuminative

IP-Rating

Front protection IP66, IP67, IP69K

Actuator

Switching action Maintained
Housing material Plastic

Switching element

6


Function

Emergency stop switch


EAO – Your Expert Partner for Human Machine Interfaces

45-2C36.1920.000 - Emergency-stop switch actuator, foolproof EN IEC 60947-5-5

Dimensions

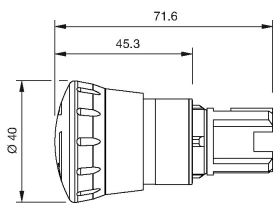

Mounting cut-outs

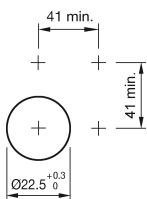

Wiring diagram



Additional information

Application as per DIN EN ISO 13850 and EN 60204-1
twist to release

Legend

Switching action: C = Maintained