

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0192040008**
Status: **Active**
Overview: Splices
Description: Avikrimp™ 4 Way Splice for 18-22 AWG Wire

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013 \(PDF\)](#)
[Product Specification PS-19902-009 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)

General

Product Family	Splices
Series	<u>19204</u>
Comments	4 Way Connector
Crimp Quality Equipment	Yes
Mil-Spec	N/A
MolexKits	Yes
Overview	<u>Splices</u>
Product Name	4 Way, Avikrimp™
UPC	800753051607

Physical

Barrel Type	Closed
Color - Resin	Red
Insulation	Nylon (PA)
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	10.284/g
Packaging Type	Bag
Temperature Range - Operating	-55°C to +105°C
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	3.56mm max.
Wire Size AWG	18, 20, 22
Wire Size mm²	0.35-0.80

Electrical


Voltage - Maximum	600V
-------------------	------

Material Info

Old Part Number	A-5XC
-----------------	-------

Reference - Drawing Numbers

Product Specification	PS-19902-009, PS-19902-011, PS-19902-013
Sales Drawing	SD-19204-002

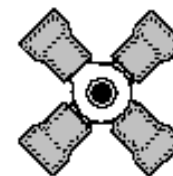

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
-ED/79/2015 (17
December 2015)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

Green Image

Not Relevant

Search Parts in this Series

19204 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade™ Hand Crimp Tool	<u>0640010100</u>
Crimp Head for the AT-200™ Pneumatic Hand Tool	<u>0640050100</u>