


JDAE20PA7035

Venting element thread length 10 Light Grey - RAL 7035

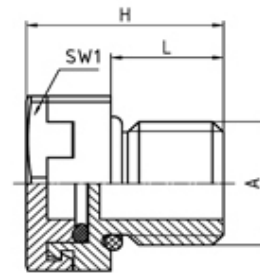

SPECIFICATION

Product Type	Standard
Body Material	Polyamide
Min Temperature °C	-40
Max Temperature °C	100
IP Rating	IP66/IP68/IP69K
Colour	Light Grey - RAL 7035
External Connecting Thread Type	Metric
Thread Length (mm)	10
Membrane	Polyether sulphone PES
Typical Air Flow	400 ml/min/cm ² at Ap = 0,07 bar
Water Entry Pressure	> 0,83 bar
Width Across Flat 1 (mm)	27
Height (mm)	21.6
Connecting Thread Size	M20x1.5
Test Standard	Washers - Steel zinc-plated, Locknut - Brass CuZn39Pb3, nickel-plated, O-Ring - Nitrile rubber