

RLY9158



14-Pin Blade Socket

Features

- PC Board Mount
- Solder Terminals
- Accepts .187" Blade Terminals
- 4PDT Applications

Electrical Rating:

300 Volts, 10 Amps

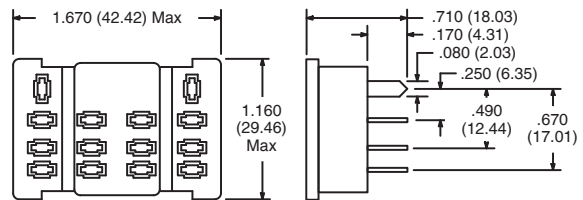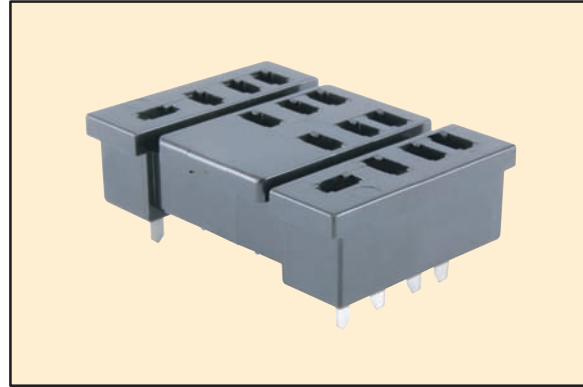

RLY9159



14-Pin Blade Socket

Features

- DIN Rail/Surface Mount
- Pressure Clamp Screws
- Accepts .187" Blade Terminals
- 4PDT Applications

Electrical Rating:

250 Volts, 10 Amps

