



21:9 ULTRAWIDE FULL HD IPS 29UB67

29UB67

 ZOOM

Key Features

21:9 ULTRAWIDE FULL HD IPS (2560x1080)

| SWIVEL & HEIGHT & TILT & PIVOT / VESA COMPATIBLE | COLOUR CALIBRATION

| 4-SCREEN SPLIT (MAC COMPATIBLE) | DUAL LINKUP & DUAL CONTROLLER

| READER MODE & FLICKER SAFE

Where to Buy

Add to Compare | PRINT | SHARE 

★★★★★ 0/5

Based on 0 user reviews

STOCK LIST



Visit Store



Visit Store



21:9 UltraWide



IPS



Colour Calibrated




sRGB over 99%

COVERING THE ENTIRE PROGRAMS WITHOUT SCROLLING AND SWITCHING.

29-inch 21:9 UltraWide single screen offers more space to activate multiple programs without any overlapping of windows, while replacing a dual monitor environment expedites the process for maximum work efficiency.

Moreover, the 4-Screen Split is more useful in the 29-inch screen of 29UB67. This 4-Screen Split feature conveniently divides the monitor screen from 2 to 4 customizable sub screens of preferred size.

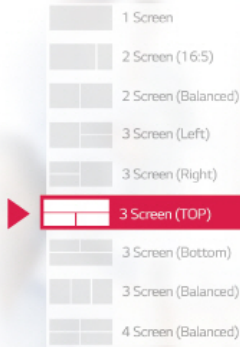

UPGRADE YOUR MULTITASKING PERFORMANCE ON THE UPSCALE SCREEN.

29UB67's Dual Controller enables the seamless control of two devices with a single keyboard and mouse under Dual Link-up mode. Therefore, sharing MS office's image clip or file became easier to provide more efficient multitasking environment by simple copy and paste between two devices with the combination of Dual controller and Dual Link-up.



OPTIMIZED WORKING ENVIRONMENT WITH ADJUSTABLE DESIGN

The 21:9 UltraWide 29UB67 monitor allow office managers to work in more comfortable office conditions by providing advanced ergonomic design and features.



BUILD A BEST FIT WORKSTATION WITH OFFICE MANAGEMENT FEATURES.

29UB67 help to establish a comfortable working environment with suitable spec-in qualifications based on TUV-GS and VESA standards.



ACCURATE colour EXPRESSION FOR BETTER ARTWORK.

The UB67 series are designed to help office manager whose daily work involves viewing text or editing the visual on-screen for long periods of time. The Hardware Calibration (True colour Finder) and sRGB over 99% provide accurate colour expression based on optimal level of brightness & contrast with the IPS display.

IPS

OVER
sRGB 99%



Color
Calibrated



LONG-LASTING COMFORTABLE WORK WITH EYE-COMFORT FEATURES.

For office workers, reading on-screen text is also a large portion of everyday tasks, and Reader Mode is a useful feature that automatically modifies colours into softer tones so that viewing the screen is as comfortable as reading a book. Also, Flicker Safe minimizes the flicker level on the screen to nearly zero, which reduces eye fatigue and also enhances the working environment.

General

Screen size (inches)	29
Panel Type	IPS
Aspect Ratio	21:9
Resolution	2560 x 1080
Brightness (cd/m2)	300
Response Time (ms)	5
Response Time_Typ. (ms)	14
Viewing Angle (°)	178 / 178
Colour Depth (Num of Colours)	6bit + A-FRC, 1 6.7M
Pixel Pitch (mm)	0.2628(H) x 0.2628(V)
Surface Treatment	Hard Coating(3H), Anti-glare
Colour Gamut	sRGB 99%

Input / Output

DVI-D	Yes
HDMI	Yes(2EA)
DisplayPort	Yes
Audio Inputs	PC Audio In
Audio Output	Headphone Out

Audio

Type	2ch
Built-in Speaker	Yes – 2x5W

Features

DDC/CI	Yes
HDCP	Yes
Plug & Play	Yes
Response Time Control	Yes
Key Lock	Yes

Special Features

Screen split	Yes(S/W)
Flicker safe	Yes
Dual controller	Yes(S/W)
SIX Axis Control	Yes
Auto resolution	Yes
Off Timer	Yes
Colour Calibrated	Yes
H/W Calibration	Yes

Stand

Base detachable	Yes
Tilt(Angle)	Yes: -5° ~ 35° Degree
Swivel(Angle)	Yes: -45 ~ 45 Degree
Height(mm)	130mm
Pivot	0-90°

Standard (Certification) & VESA Mounting

TCO6.0	Yes
UL(cUL)	Yes
TUV-GS	Yes
TUV-Ergo	Yes

FCC-B, CE	Yes
CCC, BSMI	Yes
ISO13406-2	Yes
VESA Mounting (mm)	200mm x 100mm

Power

Type / Input	Built-in power / 100-240V
Consumption Normal On (Typ.)	31W
Normal On(EPA)	46W
Consumption Power Save/Sleep Mode(Max)	1.2W (with USB3.0 connection)
DC Off (Max)	0.3W, 0.0W(AC Switch)

Dimensions - WxDxH (mm)

Set (with Stand)	703 x 252.3 x 404
Set (without Stand)	703 x 64 x 321.2
Box Dimension	864 x 190 x 375

Weight(Kg)

Set with Stand (Kg)	8.6
Set without Stand (Kg)	6.3
Shipping Weight (Kg)	10

Accessory

Power Cord	Yes
DisplayPort	Yes

ECO

[ENERGY LABEL](#)

[PRODUCT FICHE](#)

[WEB INFO](#)

More Compliance Information

WHAT PEOPLE ARE SAYING

[USER REVIEWS](#)

BE THE FIRST TO WRITE A REVIEW

[WRITE YOUR OWN REVIEW](#)

QUESTIONS? LET US HELP

Product Support

Simply choose a support option from the icons below:



Email

Send an Email to LG Customer Support to receive a response from an LG support representative.



Phone

Call an LG Support Representative on
UK : 0344-847-5454
IE : 01-686-9454
Monday to Saturday: 9am to 6pm
Sunday: Closed
Bank Holidays: Closed



Live Chat

You can chat with LG Support Representative in real time!
Monday to Saturday: 9am to 5pm
Sunday: Closed
Bank Holidays: Closed

RECENTLY VIEWED



21:9 ULTRAWIDE
FULL HD IPS 29UB67

29UB67



23" Class Full HD IPS
LED Monitor (23"
Diagonal)

23MP68VQ-P



22" Class Full HD IPS
LED Monitor (22"
Diagonal)

22MP68VQ-P



20" Class Full HD LED
Monitor (19.5"
Diagonal)

20M38A



