

Printview: 4-conductor terminal block; with fixing flange; for screw or similar mounting types; fixing hole 3.2 mm Ø; with 209-123 mounting carrier for DIN 35 rail - Item No.: 260-331

WAGO® online catalog / eShop

4-conductor terminal block; with fixing flange; for screw or similar mounting types; fixing hole 3.2 mm Ø; with 209-123 mounting carrier for DIN 35 rail

Item No.: 260-331



4-conductor terminal block; with fixing flange; for screw or similar mounting types; fixing hole 3.2 mm Ø; with 209-123 mounting carrier for DIN 35 rail

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	260-331
GTIN / EAN	4044918592802
Content	1
Order amount	50
Customer item number	

Notes

Technical data

Miscellaneous



Total number of connection points	4
Total number of potentials	1
Color	gray
Pollution degree (1)	3
Rated voltage EN (1) [V]	400 [V]
Rated surge voltage (1) [kV]	6 [kV]
Nominal current [A]	18 [A]
Connection technology (1)	CAGE CLAMP®

Printview: 4-conductor terminal block; with fixing flange; for screw or similar mounting types; fixing hole 3.2 mm Ø; with 209-123 mounting carrier for DIN 35 rail - Item No.: 260-331

Technical data	
<i>Solid sizes 1</i>	<i>0.08 ... 1.5 mm² / 28 ... 16 AWG</i>
<i>Fine-stranded wires 1</i>	<i>0.08 ... 1.5 mm² / 28 ... 16 AWG</i>
<i>Strip length 1</i>	<i>8 ... 9 mm / 0.31 ... 0.35 in</i>
<i>Type of wiring</i>	<i>Side-entry wiring</i>
<i>Design</i>	<i>horizontal</i>
<i>Marking level</i>	<i>Side marking</i>
<i>Fire load [MJ]</i>	<i>0.042 [MJ]</i>
<i>Weight [g]</i>	<i>2.524 [g]</i>
<i>Width</i>	<i>8 mm / 0.315 in</i>
<i>Height from the surface</i>	<i>17 mm / 0.669 in</i>
<i>Length</i>	<i>25 mm / 0.984 in</i>

Printview: 4-conductor terminal block; with fixing flange; for screw or similar mounting types; fixing hole 3.2 mm Ø; with 209-123 mounting carrier for DIN 35 rail - Item No.: 260-331

Images & drawings

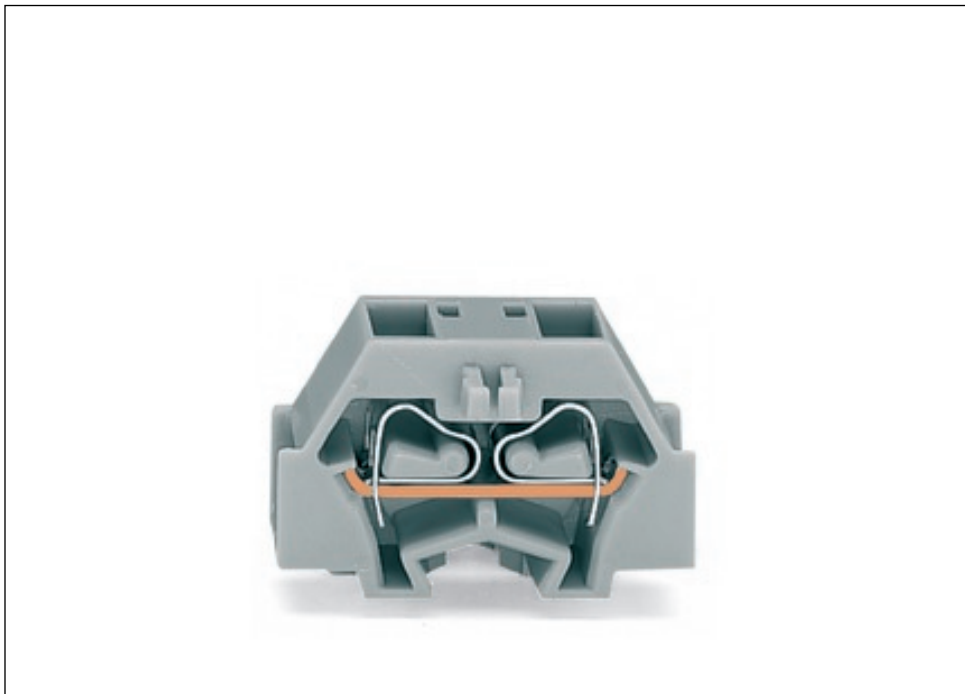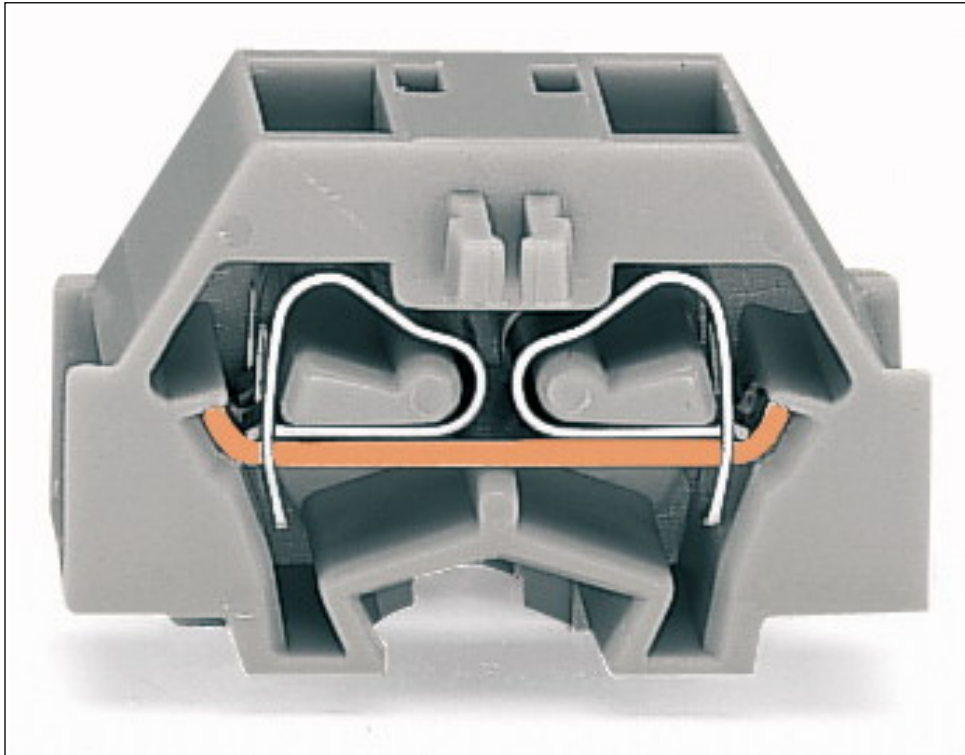

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.