

3-conductor LED terminal block; with red led; 24 VDC

Item No.: 2002-1321/1000-434



3-conductor LED terminal block; with red led; 24 VDC

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	2002-1321/1000-434
GTIN / EAN	4045454537685
Content	1
Order amount	100
Customer item number	

Notes

Safety information 1: Notice: This LED terminal block cannot be commoned with push-in type jumper bars!



Technical data

Miscellaneous

Total number of connection points	3
Total number of potentials	1
Color	gray
Ratings according to 1	IEC/EN 60947-7-1
Nominal current [A]	0.025 [A]
Nominal voltage [V]	24 [V]
Connection technology (1)	Push-in CAGE CLAMP®
Nominal cross section 1	2.5 mm ²
Solid sizes 1	0.25 ... 4 mm ² / 22 ... 12 AWG

Technical data	
<i>solid, directly pluggable 1</i>	<i>0.75 ... 4 mm² / 18 ... 12 AWG</i>
<i>Fine-stranded wires 1</i>	<i>0.25 ... 4 mm² / 22 ... 12 AWG</i>
<i>min. fine-stranded with insulated ferrule, push-in terminati</i>	<i>0.75 mm² / 18 AWG</i>
<i>Strip length 1</i>	<i>10 ... 12 mm / 0.39 ... 0.47 in</i>
<i>Type of wiring</i>	<i>Front-entry wiring</i>
<i>Design</i>	<i>horizontal</i>
<i>Marking level</i>	<i>Center/Side marking</i>
<i>Insulating material</i>	<i>Polyamide 66 (PA 66)</i>
<i>Weight [g]</i>	<i>6.2 [g]</i>
<i>Width</i>	<i>5.2 mm / 0.205 in</i>
<i>Height from upper-edge of DIN-rail [mm]</i>	<i>32.9 [mm]</i>
<i>Height from upper-edge of DIN-rail</i>	<i>32.9 mm / 1.295 in</i>
<i>Length</i>	<i>59.2 mm / 2.33 in</i>
<i>Type of mounting</i>	<i>DIN 35 rail</i>

Images & drawings

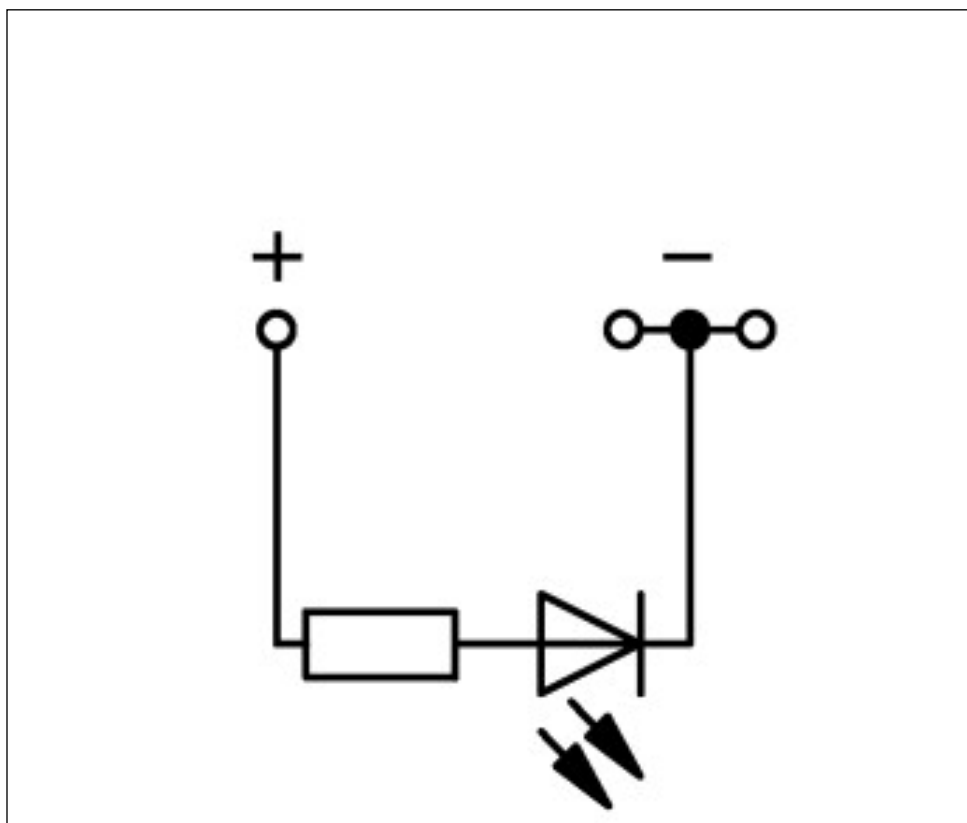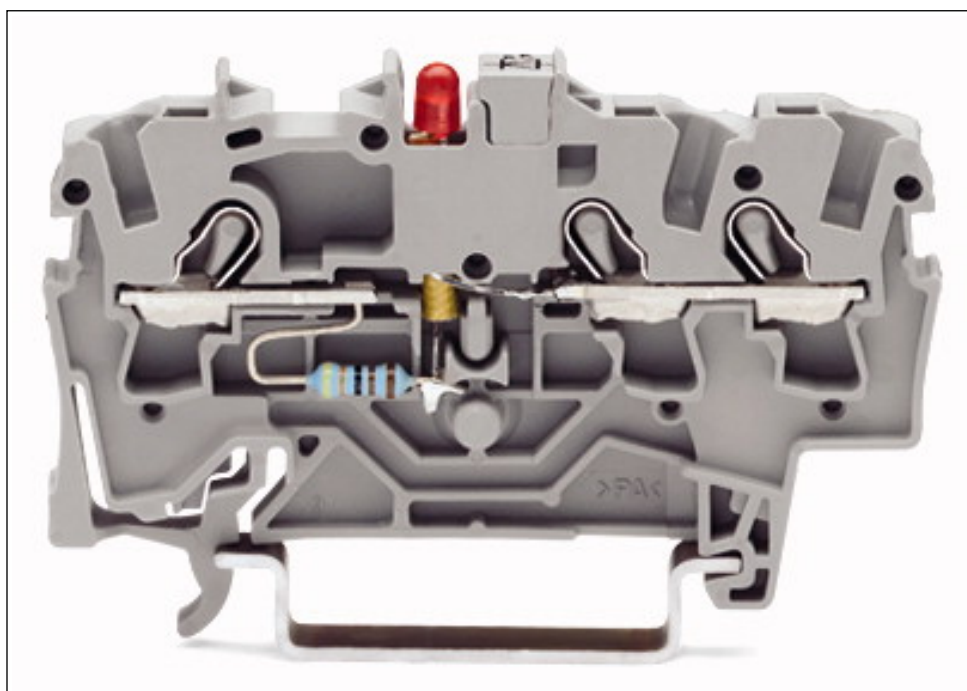

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.