

Printview: Female connector; 2-pole; pin spacing 5 mm / 0.197 in; 100% protected against mismatching; codable; one latch only - Item No.: 721-102/026-000

**WAGO**® online catalog / eShop

**Female connector; 2-pole; pin spacing 5 mm / 0.197 in; 100% protected against mismatching; codable; one latch only**

Item No.: 721-102/026-000



Female connector; 2-pole; pin spacing 5 mm / 0.197 in; 100% protected against mismatching; codable; one latch only

### Marking

RoHS ✓  
Compliant

### Business data

Supplier	WAGO
Item no.	721-102/026-000
GTIN / EAN	4044918352925
Content	1
Order amount	100
Customer item number	

### Notes

Universal connection for all conductor types Easy cable pre-assembly and on-unit wiring via vertical and horizontal CAGE CLAMP® actuation Integrated test ports 100% protected against mismatching Coding option available

### Technical data

#### Miscellaneous

No. of poles	2
Pin Spacing	5 mm / 0.197 in %
Total number of connection points	2
Total number of potentials	2
Color	light gray
Ratings according to 1	IEC/EN 60664-1
Overvoltage category EN 1	III
Pollution degree (1)	2

Printview: Female connector; 2-pole; pin spacing 5 mm / 0.197 in; 100% protected against mismatching; codable; one latch only - Item No.: 721-102/026-000

<b>Technical data</b>	
<i>Rated voltage EN (1) [V]</i>	320 [V]
<i>Rated surge voltage (1) [kV]</i>	4 [kV]
<i>Nominal current [A]</i>	16 [A]
<i>Overvoltage category EN 2</i>	II
<i>Degree of pollution (2)</i>	2
<i>Rated voltage EN (2) [V]</i>	630 [V]
<i>Rated surge voltage (2) [kV]</i>	4 [kV]
<i>Nominal current (2) [A]</i>	16 [A]
<i>Overvoltage category EN 3</i>	III
<i>Degree of pollution (3)</i>	3
<i>Rated voltage EN (3) [V]</i>	320 [V]
<i>Rated surge voltage (3) [kV]</i>	4 [kV]
<i>Nominal current (3) [A]</i>	16 [A]
<i>Number of individual connection objects at the product</i>	1
<i>Connection technology (1)</i>	CAGE CLAMP®
<i>Solid sizes 1</i>	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG
<i>Fine-stranded wires 1</i>	0.08 ... 2.5 mm <sup>2</sup> / 28 ... 12 AWG
<i>Fine-stranded wires with insulated ferrule 1</i>	0.25 ... 1.5 mm <sup>2</sup> / ...
<i>Fine-stranded wires with uninsulated ferrule 1</i>	0.25 ... 2.5 mm <sup>2</sup> / ...
<i>Strip length 1</i>	8 ... 9 mm / 0.31 ... 0.35 in
<i>Material group</i>	I
<i>Insulating material</i>	Polyamide 66 (PA 66)
<i>Flammability rating per UL 94</i>	V0
<i>Limit temperature range</i>	-60 C ... 85 C
<i>Clamping spring material</i>	Chrome-nickel spring steel (CrNi)
<i>Contact material</i>	Copper alloy
<i>Contact plating</i>	tin-plated
<i>Fire load [MJ]</i>	0.057 [MJ]
<i>Weight [g]</i>	3.87 [g]
<i>Width</i>	11.5 mm / 0.453 in
<i>Height</i>	14.3 mm / 0.563 in
<i>Length</i>	26.45 mm / 1.041 in


Printview: Female connector; 2-pole; pin spacing 5 mm / 0.197 in; 100% protected against mismatching; codable; one latch only - Item No.: 721-102/026-000

---

## Images & drawings



Printview: Female connector; 2-pole; pin spacing 5 mm / 0.197 in; 100% protected against mismatching;  
codable; one latch only - Item No.: 721-102/026-000

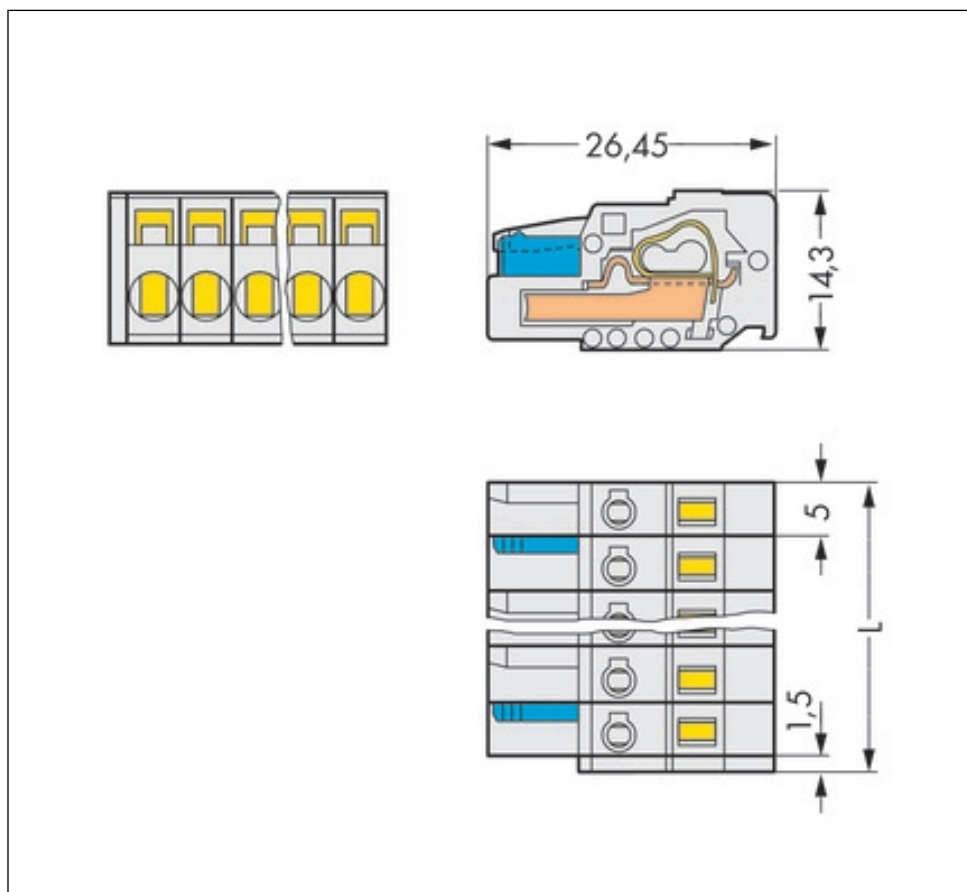

#### Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.