

Printview: Female connector; 16-pole; pin spacing 5 mm / 0.197 in; 100% protected against mismatching; codable; with 2 latches - Item No.: 721-116/026-000

WAGO® online catalog / eShop

Female connector; 16-pole; pin spacing 5 mm / 0.197 in; 100% protected against mismatching; codable; with 2 latches

Item No.: 721-116/026-000



Female connector; 16-pole; pin spacing 5 mm / 0.197 in; 100% protected against mismatching; codable; with 2 latches

Marking

RoHS ✓
Compliant

Business data

Supplier	WAGO
Item no.	721-116/026-000
GTIN / EAN	4044918355933
Content	1
Order amount	25
Customer item number	

Notes

Universal connection for all conductor types
Easy cable pre-assembly and on-unit wiring via vertical and horizontal
CAGE CLAMP® actuation
Integrated test ports
100% protected against mismatching
Coding option available

Technical data

Miscellaneous


No. of poles	16
Pin Spacing	5 mm / 0.197 in %
Total number of connection points	16
Total number of potentials	16
Color	light gray
Ratings according to 1	IEC/EN 60664-1
Overvoltage category EN 1	III
Pollution degree (1)	2

Printview: Female connector; 16-pole; pin spacing 5 mm / 0.197 in; 100% protected against mismatching; codable; with 2 latches - Item No.: 721-116/026-000


Technical data	
Rated voltage EN (1) [V]	320 [V]
Rated surge voltage (1) [kV]	4 [kV]
Nominal current [A]	16 [A]
Overvoltage category EN 2	II
Degree of pollution (2)	2
Rated voltage EN (2) [V]	630 [V]
Rated surge voltage (2) [kV]	4 [kV]
Nominal current (2) [A]	16 [A]
Overvoltage category EN 3	III
Degree of pollution (3)	3
Rated voltage EN (3) [V]	320 [V]
Rated surge voltage (3) [kV]	4 [kV]
Nominal current (3) [A]	16 [A]
Number of individual connection objects at the product	1
Connection technology (1)	CAGE CLAMP®
Solid sizes 1	0.08 ... 2.5 mm ² / 28 ... 12 AWG
Fine-stranded wires 1	0.08 ... 2.5 mm ² / 28 ... 12 AWG
Fine-stranded wires with insulated ferrule 1	0.25 ... 1.5 mm ² / ...
Fine-stranded wires with uninsulated ferrule 1	0.25 ... 2.5 mm ² / ...
Strip length 1	8 ... 9 mm / 0.31 ... 0.35 in
Material group	I
Insulating material	Polyamide 66 (PA 66)
Flammability rating per UL 94	V0
Limit temperature range	-60 C ... 85 C
Clamping spring material	Chrome-nickel spring steel (CrNi)
Contact material	Copper alloy
Contact plating	tin-plated
Fire load [MJ]	0.394 [MJ]
Weight [g]	28.275 [g]
Width	81.5 mm / 3.209 in
Height	14.3 mm / 0.563 in
Length	26.45 mm / 1.041 in

Printview: Female connector; 16-pole; pin spacing 5 mm / 0.197 in; 100% protected against mismatching; codable; with 2 latches - Item No.: 721-116/026-000

Images & drawings

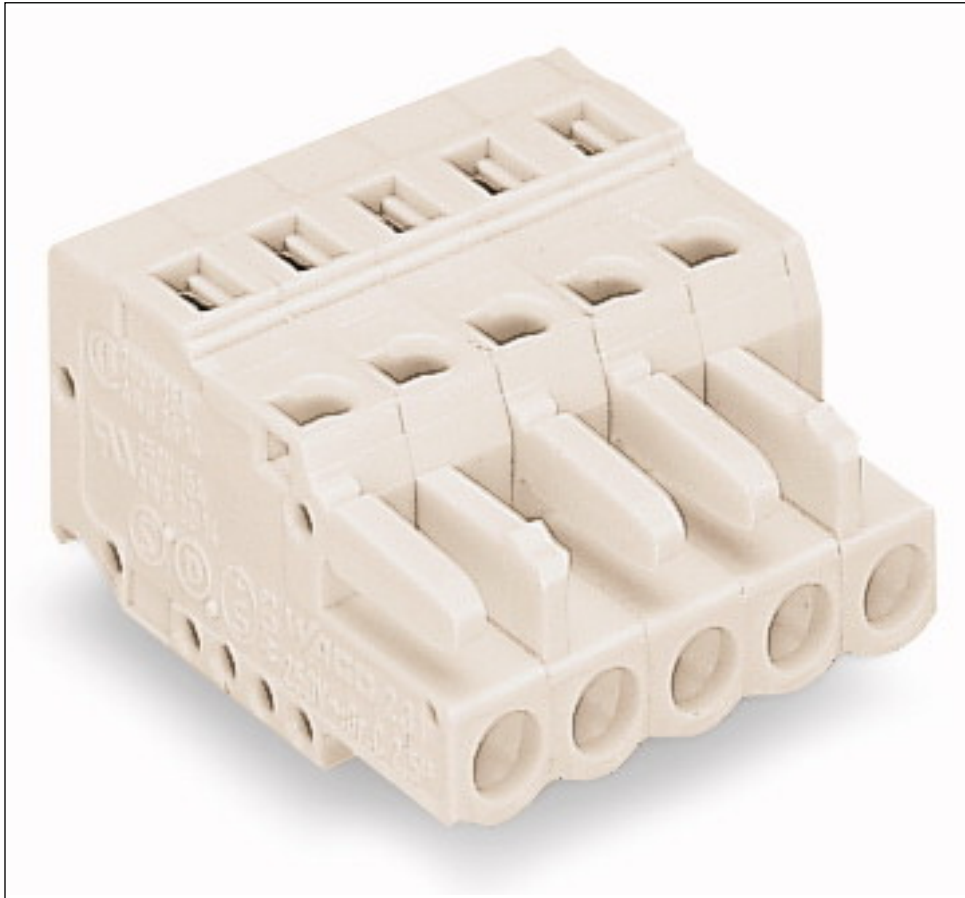

Printview: Female connector; 16-pole; pin spacing 5 mm / 0.197 in; 100% protected against mismatching;
codable; with 2 latches - Item No.: 721-116/026-000

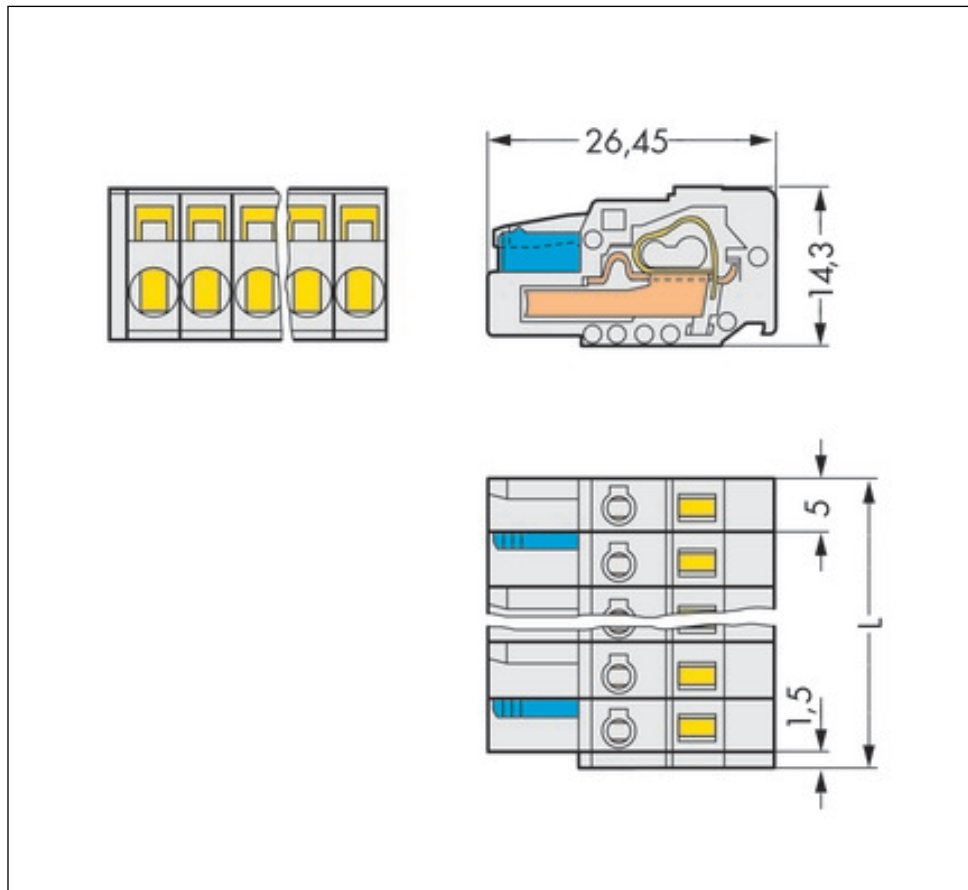

Address

WAGO Kontakttechnik GmbH & Co. KG

Hansastr. 27

32423 Minden

Telefon: 0571/887-0

Fax: 0571/887-169

<http://www.wago.com>

© WAGO Kontakttechnik GmbH & Co. KG

Technische Änderungen und Irrtümer vorbehalten.