

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0191540035](#)
Status: **Active**
Overview: [Splices](#)
Description: Step Down Butt Splice for 10-16 AWG Wire Yellow w/Blue Stripe

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR18689
 UL E32244

General

Product Family Splices
 Series [19154](#)
 Comments Step down: 10/12 to 14/16 AWG . Yellow with Blue Stripe
 Crimp Quality Equipment Yes
 Mil-Spec N/A
 Overview [Splices](#)
 Product Name Butt - Step Down
 UPC 800753108998

Physical

Barrel Type Closed - Brazed
 Color - Resin Yellow
 Flammability 94V-0
 Insulation PVC
 Material - Metal Copper
 Material - Plating Mating Tin
 Material - Plating Termination Tin
 Material - Resin PVC
 Net Weight 3.463/g
 Packaging Type Bag
 Temperature Range - Operating -40°C to +105°C
 Wire Insulation Diameter 6.35mm max.
 Wire Size AWG 10, 12, 14, 16

Electrical

Voltage - Maximum 600V

Solder Process Data


Lead-freeProcess Capability N/A

Material Info

Old Part Number CB-646X

Reference - Drawing Numbers

Product Specification PS-19902-011, PS-19902-013
 Sales Drawing SD-19154-007

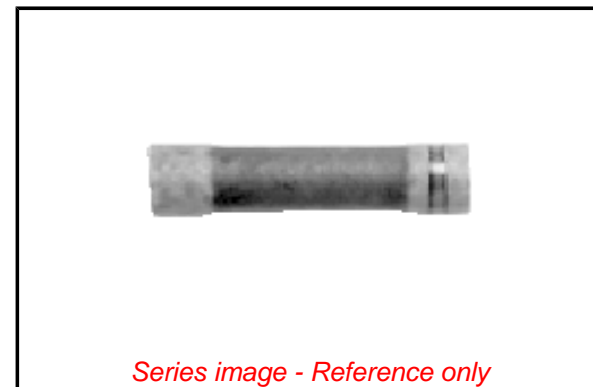

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
 ED/108/2014 (17 Dec
 2014)

Halogen-Free

Status

Not Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS

ELV

China RoHS

Green Image

Not Relevant

Search Parts in this Series

19154 Series

Application Tooling | FAQ

*Tooling specifications and manuals are
 found by selecting the products below.
 Crimp Height Specifications are then
 contained in the Application Tooling
 Specification document.*

Global

Description	Product #
PremiumGrade™ Hand Crimp Tool	0640010100
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050100