

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0010013046](#)
Status: **Active**
Overview: SPOX™ Wire-to-Board Connectors
Description: 5.08mm Pitch SPOX™ Crimp Terminal Housing, 4 Circuits

Documents:

[3D Model](#) [Product Specification PS-5197-005 \(PDF\)](#)
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-5197-001 \(PDF\)](#)

Agency Certification

CSA LR19980
 UL E29179

General

Product Family Crimp Housings
 Series 5197
 Application Signal, Wire-to-Board
 Overview SPOX™ Wire-to-Board Connectors
 Product Name SPOX™
 UPC 800754313131

Physical


Circuits (maximum) 4
 Color - Resin Natural
 Flammability 94V-2
 Gender Female
 Glow-Wire Compliant No
 Material - Resin Nylon
 Net Weight 1535.800/mg
 Number of Rows 1
 Packaging Type Bag
 Panel Mount No
 Pitch - Mating Interface 5.08mm
 Stackable No
 Temperature Range - Operating -40°C to +105°C

Material Info

Old Part Number 5197-04

Reference - Drawing Numbers

Product Specification PS-5197-001, PS-5197-005, RPS-5281-001
 Sales Drawing SD-5197-N

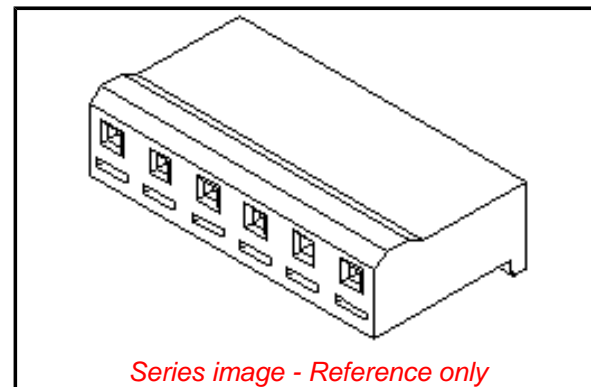

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per
 -ED/79/2015 (17
 December 2015)

Halogen-Free

Status

Low-Halogen

**Need more information on product
 environmental compliance?**

Email productcompliance@molex.com
 Please visit the [Contact Us](#) section for any
 non-product compliance questions.

China ROHS
 ELV

Green Image
 Not Relevant

Search Parts in this Series

[5197 Series](#)

Mates With

[5281](#) , [5282](#)

Use With

[5194](#) , [5225](#)