



**Ring Terminal**  
**T&B Catalog Number:**

RD10361

**UPC Number:**

78621083034

**Status:**

Active

**Description:**

Nylon Insulated Large Ring Terminal, Length 1.40 Inches, Width .41 Inches, Maximum Insulation .270, Bolt Hole #10, Wire Range 8AN, Color Red, Copper, Tin Plated

**WEB\_USE**

US Cutsheet PDF Catalog Link

<http://www-public.tnb.com/contractor/docs/stakon.pdf>

**Features**

Funneled Barrel Entry, Deep Internal Serrations, Brazed or overlapping seams.

**General**

Insulation Type	Insulated Nylon
Terminal Series	RD
Material	Copper
Finish	Electro -Tin Plated
Color	Red
Wire Range	8AN
Stud Size	#10

**Dimension Information**

Maximum Insulation (inches)	.270
Stock Thickness	.04
A (inches)	1.40
B (inches)	.41
C (inches)	.24
M (inches)	1.20

**Specifications**

Temperature Rating	105°C
Voltage Rating	600V
Flammability Rating	UL 94 V-2
MIL Specification	MS-25036-115

**Tooling**


Tool Charts	Available on Website
Application Tools	ERG4007
Recommended Tool	ERG4007

**Packaging**

T&B Order Multiple	200
T&B Inner Pack	200
Package in Units	2000
Package Type	Standard
T&B Sold in UOM	Each
T&B Weight Per UOM	1.06 lbs. per 100

**Application Support**

T&B Sales Drawings	wsd-000207
Overview	Available on Website
Wire Guide Tables	Available on Website

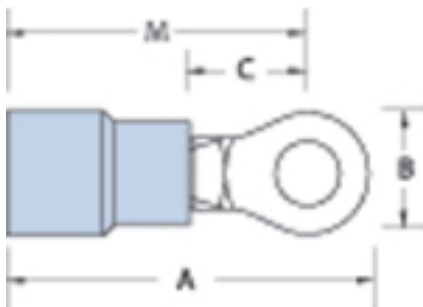

## Notes

Not available on Mylar Tape.

## Certifications

RoHS Compliance

Yes

## Certifications



File Nbr:

E9809

### For further technical assistance, please contact us...

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com