



## Saddle Support Base T&B Catalog Number:


**UPC Number:**  
**Status:**  
**Description:**

TC142X  
78620987440  
Active

Saddle Support Mounting Base, Heat Stabilized Black Polyamide (Nylon 6.6) for Temperatures up to 85 Degrees Celsius (185 F), Length of 23.42mm (0.922 Inches), Width of 14.29mm (0.563 Inches), Height of 10.72mm (0.422 Inches), Mount with #10 Screw, Bulk Pack

### Features

This mounting base provides a saddle for the wire run. Ty-Rap tie is threaded under bundle and tied in a usual manner.

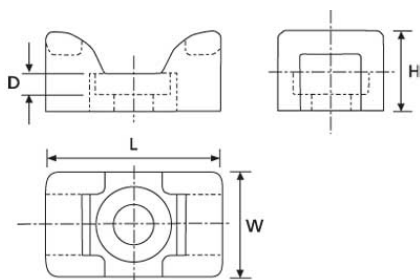

### General

Material	Nylon 6.6
Color	Black
Mounting Method	Screw
Stud Size	#10 Pan head
Max Tie Width Accepted	.301
For Cable Ties	Up to 120 lbs.

### Dimension Information

Length (inches)	.922
Width (inches)	.563

### Specifications

Temperature Rating	-40°F to 185°F
Flammability Rating	UL 94 V-2

### Packaging

T&B Order Multiple	500
T&B Inner Pack	500
Package in Units	5000
Package Type	Bulk
T&B Sold in UOM	Each
T&B Weight Per UOM	1.25 lbs. per 1000

### Application Support

Material Selection Guide	Available on Website
--------------------------	----------------------

### Certifications

RoHS Compliance	Yes
-----------------	-----

### Certifications



File Nbr:  
E49405

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
www.tnb.com

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email:techsupport@tnb.com