


Capacitor, film, Film-Foil Polypropylene, 16 uF, +/-5% Tol, 470 VAC, Motor Run

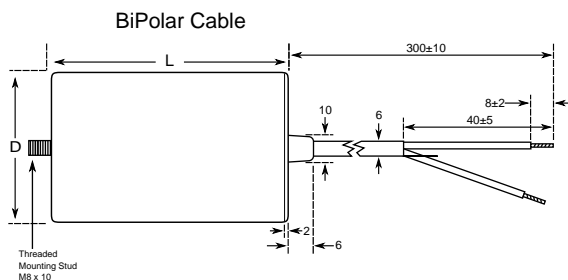

General Information	
Supplier:	KEMET
Dielectric:	Film-Foil Polypropylene
Application:	Motor Run
Style:	Round Can
Lead Type:	Bipolar Cable
Mounting Type:	Bolt: M8x10
Features:	Ultra Sonically Welded Seal, Safety Class P0, UL_94 V0 Disk
Approvals:	UL, VDE, UL (Construction Only), UL_94 V0 Disk
RoHS:	Yes

Dimensions (mm)		
Symbol	Dimension	Tolerance
D	35	+1
L	71.5	+/-2

Packaging Specifications	
Package Kind:	Bulk

Specifications	
Capacitance:	16 uF
Voltage AC:	470 VAC
Tolerance:	+/-5%
Temperature Range:	-25/+85C
Rated Temperature:	85C
Life:	10000 Hrs
Life:	30000 Hrs (85C, 420V)
Maximum dVdT:	15 v/us