

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0734152202](#)
Status: **Active**
Overview: Mini-BNC RF Connectors
Description: 75 Ohms, Mini-BNC Jack, Right-Angle, Bulkhead, Nickel, PCB

Documents:

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

| | |
|-----------------|-------------------------------|
| Product Family | RF/Coax Connectors |
| Series | 73415 |
| Overview | <u>Mini-BNC RF Connectors</u> |
| Product Name | mini-BNC |
| Style | PCB |
| UPC | 822350649414 |
| Wire/Cable Type | N/A |

Physical

| | |
|-----------------------------|--------------|
| Gender | Jack |
| Keying to Mating Part | Yes |
| Net Weight | 7.490/g |
| Orientation | Right Angle |
| PCB Mounting | Through Hole |
| PCB Thickness - Recommended | 2.79mm |
| Packaging Type | Tray |
| Panel Mount | No |
| Panel Mount Method | Bulkhead |
| Reverse Polar | No |

Electrical

| | |
|-----------|-----|
| Impedance | 75# |
|-----------|-----|


Solder Process Data

| | |
|--|----------|
| Duration at Max. Process Temperature (seconds) | 010 |
| Lead-free Process Capability | SMC&WAVE |
| Max. Cycles at Max. Process Temperature | 002 |
| Process Temperature max. C | 260 |

Material Info

Reference - Drawing Numbers

| | |
|---------------|--------------|
| Sales Drawing | SD-73415-220 |
|---------------|--------------|

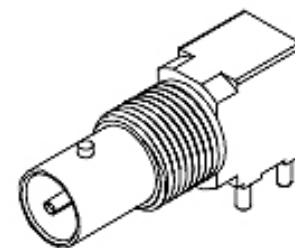

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Contained Per -ED/79/2015 (17 December 2015)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

50 Image

ELV

Not Relevant

Search Parts in this Series

[73415 Series](#)