

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0731000167](#)  
**Status:** **Active**  
**Overview:** [BNC RF Connectors](#)  
**Description:** 50 Ohms, BNC Right-Angle PCB Bulkhead Jack Receptacle with Board Locks, Black PBT Housing, Nut and Lock Washer not included, Tray

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR19980  
 UL E107635

**General**

Product Family RF/Coax Connectors  
 Series [73100](#)  
 Overview [BNC RF Connectors](#)  
 Product Name BNC  
 Style PCB  
 UPC 800753686113  
 Wire/Cable Type N/A

**Physical**

Gender Jack  
 Keying to Mating Part None  
 Net Weight 10.847/g  
 Orientation Right Angle  
 PCB Mounting Through Hole  
 PCB Thickness - Recommended 3.20mm  
 Packaging Type Tray  
 Panel Mount Yes  
 Panel Mount Method Bulkhead  
 Reverse Polar No

**Electrical**

Impedance 50#


**Solder Process Data**

Lead-freeProcess Capability WAVE  
 Max. Cycles at Max. Process Temperature 002  
 Process Temperature max. C 245

**Material Info**

**Reference - Drawing Numbers**

Sales Drawing SD-73100-0167

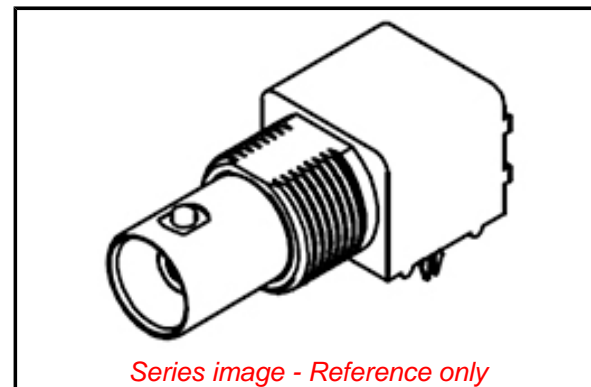

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
 -ED/79/2015 (17  
 December 2015)

**Halogen-Free**

**Status**

**Not Low-Halogen**

**Need more information on product  
 environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any  
 non-product compliance questions.

China ROHS

ELV

Green Image

Not Relevant

**Search Parts in this Series**

[73100 Series](#)