

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0192160004](#)  
**Status:** **Active**  
**Overview:** [Splices](#)  
**Description:** Multi-Lock Connector for 14-18 AWG Wire

**Documents:**

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Drawing \(PDF\)](#)

**Agency Certification**

UL E32244

**General**

Product Family Splices  
 Series [19216](#)  
 Comments Width 13.97mm (.550")  
 Crimp Quality Equipment Yes  
 Mil-Spec N/A  
 MolexKits Yes  
 Overview [Splices](#)  
 Product Name Multi-Lock  
 UPC 800753025943

**Physical**

Barrel Type Closed  
 Color - Resin White  
 Flammability 94V-0  
 Insulation Polypropylene  
 Material - Metal Copper  
 Material - Plating Mating Tin  
 Material - Plating Termination Tin  
 Net Weight 1.334/g  
 Packaging Type Bag  
 Wire Insulation Diameter 3.30mm & 3.56mm  
 Wire Size AWG 14, 16, 18  
 Wire Size mm<sup>2</sup> 0.96-2.60

**Electrical**

Voltage - Maximum 600V

**Solder Process Data**


Lead-freeProcess Capability N/A

**Material Info**

Old Part Number ML-1814

**Reference - Drawing Numbers**

Sales Drawing SD-19216-003

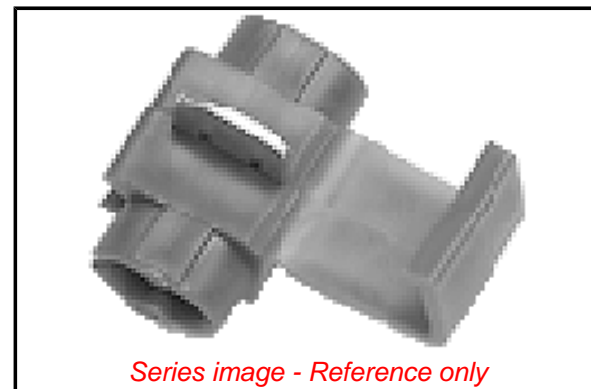

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per -  
 ED/21/2016 (20 June  
 2016)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product  
 environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 Please visit the [Contact Us](#) section for any  
 non-product compliance questions.

China ROHS

ELV

Green Image

Not Relevant

**Search Parts in this Series**

[19216 Series](#)