




Flexible Cable Support

- **Heladuct Flex**

Heladuct flexible cable supports are commonly used in switching cabinets. They are also used in the furniture industry, where cables need to be routed rapidly and attractively.

Features and Benefits

- Space-saving wiring system
- Highly flexible, can be installed at angles of 90° and higher
- Cable clearly open to view
- Rapid mounting with screws or adhesive strip with high-quality foam bonding layer

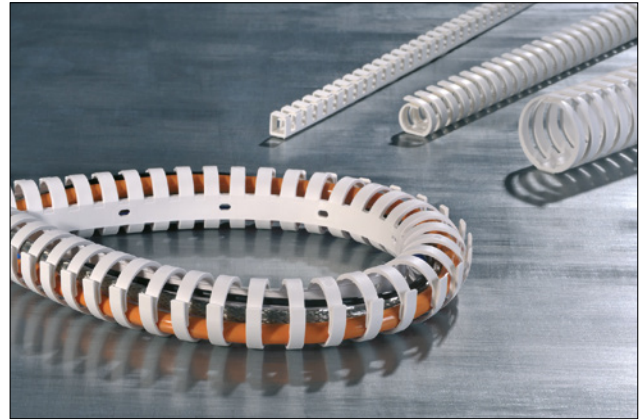

Heladuct Flex- clearly and space-saving arrangement of wiring, even at angles above 90°.

MATERIAL	Polypropylene (PP)
Operating Temperature	-20 °C to +70 °C
Adhesive	Synthetic rubber with base of polyethylene foam
Flammability	UL94 V0 (excluding adhesive)



TYPE	Nominal Ø	No. of Wires			Max. load on a length of 500 mm at 70 °C (g)	Colour	Length (L)	Article-No.
		9 x 0,75 mm ²	6 x 1,50 mm ²	4 x 2,50 mm ²				
Heladuct Flex10	10	9 x 0,75 mm ²	6 x 1,50 mm ²	4 x 2,50 mm ²	100	White (WH)	500	164-11008
Heladuct Flex20	20	32 x 0,75 mm ²	22 x 1,50 mm ²	14 x 2,50 mm ²	300	White (WH)	500	164-21008
Heladuct Flex30	30	67 x 0,75 mm ²	50 x 1,50 mm ²	34 x 2,50 mm ²	650	White (WH)	500	164-31008
Heladuct Flex40	40	-	81 x 1,50 mm ²	60 x 2,50 mm ²	1,100	White (WH)	500	164-41008

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.

TYPE	Nominal Ø	No. of Wires			Max. load on a length of 500 mm at 70 °C (g)	Colour	Length (L)	Article-No.
		9 x 0,75 mm ²	6 x 1,50 mm ²	4 x 2,50 mm ²				
Heladuct Flex10SK	10	9 x 0,75 mm ²	6 x 1,50 mm ²	4 x 2,50 mm ²	100	White (WH)	500	164-11108
Heladuct Flex20SK	20	32 x 0,75 mm ²	22 x 1,50 mm ²	14 x 2,50 mm ²	300	White (WH)	500	164-21108
Heladuct Flex30SK	30	67 x 0,75 mm ²	50 x 1,50 mm ²	34 x 2,50 mm ²	500	White (WH)	500	164-31108
Heladuct Flex40SK	40	-	81 x 1,50 mm ²	60 x 2,50 mm ²	400	White (WH)	500	164-41108

All dimensions in mm. Subject to technical changes.
Minimum Order Quantity (MOQ) may differ from package content.