

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: **0190160098**
Status: **Active**
Overview: Standard Quick-Disconnect Terminals
Description: Krimptite™ Quick Disconnect, Female, for 24-26 (0.20-0.12mm²) Wire, Box, Tab 4.75 x 0.51mm

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013-001 \(PDF\)](#)
[Product Specification PS-19902-011-001 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Quick Disconnects
Series	<u>19016</u>
Comments	Butted Seam
Crimp Quality Equipment	Yes
Insulated	No
Overview	<u>Standard Quick-Disconnect Terminals</u>
Product Name	Krimptite™
Type	Quick Disconnect
UPC	800755047585

Physical

Barrel Type	Closed
Gender	Female
Glow-Wire Compliant	No
Insulation	None
Lock to Mating Part	None
Material - Metal	Brass
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.360/g
Orientation	Straight
Packaging Type	Bag
Polarized to Mating Part	No
Tab Thickness	0.51mm
Tab Width	4.75mm
Temperature Range - Operating	Per Wire Specification
Wire Size AWG	24, 26

Electrical

Voltage - Maximum	Per Wire Specification
-------------------	------------------------

Solder Process Data


Lead-free Process Capability	N/A
------------------------------	-----

Material Info

Engineering Number	M-1136
--------------------	--------

Reference - Drawing Numbers

Product Specification	PS-19902-011-001, PS-19902-013-001
Sales Drawing	SD-19016-004

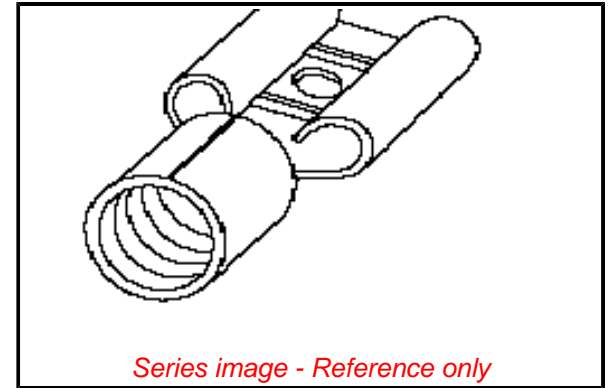

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/21/2016 (20 June
2016)

Halogen-Free

Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

19016 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
Hand Crimp Tool	<u>0640030400</u>
Crimp Head for the AT-200™ Pneumatic Hand Tool	<u>0640070400</u>