



SceneSwitch LED Lamps

LED Scene Switch 60W A60 B22 WW FR ND 1BC/4

Some situations call for cool light, others benefit from the ambiance of a warm cozy glow. With Philips SceneSwitch LED lamps, you can have different light settings from just one bulb, candle or spot. And you don't need a dimmer! Optimize your lighting for relaxing, hobbies, recreation or working. Simply at the flick of a switch. And that's your existing switch! No extra installation is required.

Product data

General Information	
Cap-Base	B22 [B22]
Bulb Shape	A60 [A 60mm]
Nominal Lifetime (Nom)	15000 h
Switching Cycle	100000X
Technical Type Setting(s)	8/5/2-60 W
Light Technical	
Color Code	827/825/822 [CCT of 2700K/2500K/2200K]
Luminous Flux Setting(s)	806/320/80 lm
Luminous Flux (Rated) Setting(s)	806/320/80 lm
Color Designation	Warm/Extra Warm/Very Warm
Correlated Color Temperature Setting(s)	2700/2500/2200 K
Luminous Efficacy (rated) (Nom)	100.75 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %

Operating and Electrical	
Input Frequency	50 to 60 Hz
Power (Rated) Setting(s)	8/5/2 W
Lamp Current (Nom)	100 mA
Wattage Equivalent	60 W
Starting Time (Nom)	0.5 s
Warm Up Time To 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.5
Voltage (Nom)	220-240 V
Controls and Dimming	
Dimmable	No
Mechanical and Housing	
Bulb Finish	Frosted
Approval and Application	
Energy Saving Product	Yes

SceneSwitch LED Lamps


Suitable For Accent Lighting	No
Energy Efficiency Label (EEL)	A+
Energy Consumption kWh/1000 h	8 kWh

Product Data

Full product code	871869658886400
Order product name	LED Scene Switch 60W A60 B22 WW FR ND 1BC/4
EAN/UPC - Product	8718696588864

Order code	929001236601
Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4
Material Nr. (12NC)	929001236601
Net Weight (Piece)	0.065 kg

Dimensional drawing

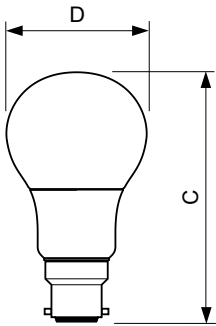

SS Bulb 9.5W-60W 150D 2700-2200K B22 ND

Product	D	C
LED Scene Switch 60W A60 B22 WW FR ND 1BC/4	61 mm	111 mm

Photometric data

General Uniform Lighting

