 



KEMET Part Number: SS35H-20170
(UAL35H20170000)

Commercial Grade, SS35V/35H, 0.017 H

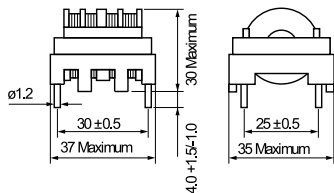

Dimensions

L	37mm MAX
T	35mm MAX
H	30mm MAX
S	25mm +/-0.5mm
S1	30mm +/-0.5mm
LL	4mm -1.5mm
F	1.2mm NOM

Packaging Specifications

Weight:	58 g
----------------	------

General Information

Style:	Through-Hole Choke
Series:	SS35V/35H
Description:	Common Mode Filter
RoHS:	Yes
Miscellaneous:	Inductance Measurement Condition: 1kHz 1V KC530

Specifications

Inductance:	17000 uH
Rated Temperature:	120C
Current:	2 mAmps (Irms, 45C Rise By Self Heating)
Voltage AC:	250 VAC
DC Resistance:	280 mOhms
Insulation Resistance:	100 MOhms