


KEMET Part Number: SC-02-20G
(UALSC0220G0000)

Choke, SC-G/GS, 2000 uH

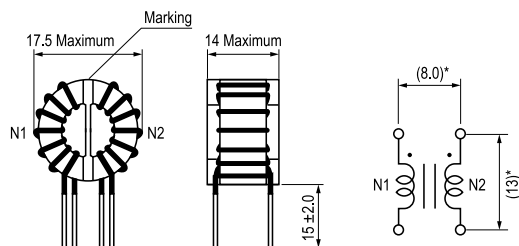

*Pin pitch values are for reference only. Values are not guaranteed.

Dimensions

L	17.5mm MAX
T	14mm MAX
H	17.5mm MAX
S	13mm MAX
S1	8mm NOM
LL	15mm +/-2mm
Wire Size	0.5mm

Packaging Specifications

Weight:	8 g
----------------	-----

General Information

Style:	Through-Hole Toroid
Series:	SC-G/GS
Description:	Miniature Common Mode Filter
RoHS:	Yes
Miscellaneous:	Inductance Measurement Condition: 100kHz 1mA KC547 (*=1mA KC547)
Notes:	Lead Spacing (S/S1) Are For Reference Only.

Specifications

Inductance:	2000 uH
Rated Temperature:	120C
Current:	2 mAmps (Irms, 40C Rise By Self Heating)
Voltage AC:	250 VAC
DC Resistance:	70 mOhms
Insulation Resistance:	100 MOhms