


KEMET Part Number: SU10VFC-R13025
(UALSU10VR13025)

Commercial Grade, SU-10VFC-R, 2500 uH

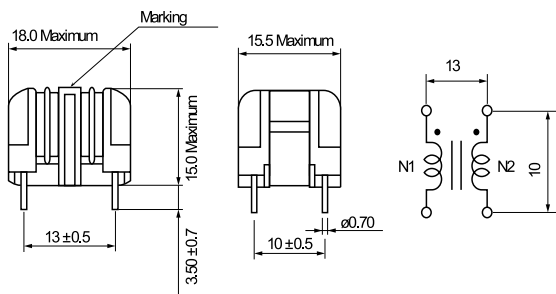

Dimensions

L	18mm MAX
T	15.5mm MAX
H	15mm MAX
S	10mm +/-0.5mm
S1	13mm +/-0.5mm
LL	3.5mm +/-0.7mm
F	0.7mm NOM

Packaging Specifications

Weight:	6.6 g
----------------	-------

General Information

Style:	Through-Hole Choke
Series:	SU-10VFC-R
Description:	Common Mode Filter, Height: 15mm MAX
RoHS:	Yes
Miscellaneous:	Inductance Measurement Condition: 1kHz 1V KC530

Specifications

Inductance:	2500 uH
Rated Temperature:	120C
Current:	1.3 mAmps (I _{rms} , 50C Rise By Self Heating)
Voltage AC:	250 VAC
DC Resistance:	300 mOhms
Insulation Resistance:	100 MOhms