

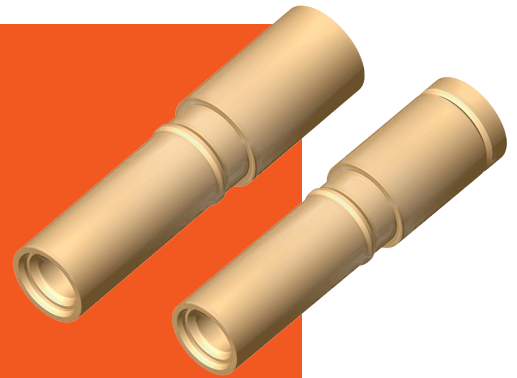
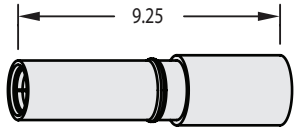


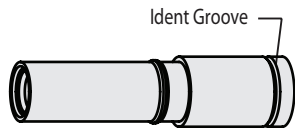


M300 Connectors

Female Cable Connector Contacts

- ❏ 4-finger Beryllium Copper contact.
- ❏ Crimp barrel meets all crimp guidelines and standards.
- ❏ 10A current capacity, resists high vibration and shock.
- ❏ Withstands extremes of temperature: -65°C to +175°C.

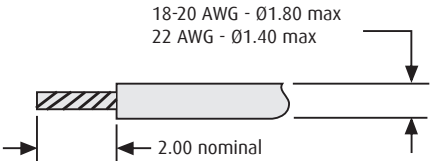

CONTACTS	WIRE STRIPPING DETAILS									
<p>18-20 AWG</p>  <p>22 AWG</p> 	 <p>18-20 AWG - Ø1.80 max 22 AWG - Ø1.40 max</p> <p>2.00 nominal</p>									
TOOLS										
<p>Recommended Crimp Tool - M22520/2-01 Positioner - Z80-058</p>	<p>Contact Insertion/Removal Tool - Z300-902 See page 12j ❏ Instruction sheets available at www.harwin.com/instructions</p>									
HOW TO ORDER										
<p>SERIES CODE</p> <p>M300 - 00X 00 45</p> <table border="1" data-bbox="186 1669 511 1795"> <thead> <tr> <th colspan="2">TYPE</th> </tr> </thead> <tbody> <tr> <td>001</td> <td>18-20 AWG crimp contact</td> </tr> <tr> <td>002</td> <td>22 AWG crimp contact</td> </tr> </tbody> </table>	TYPE		001	18-20 AWG crimp contact	002	22 AWG crimp contact	<p>FINISH</p> <table border="1" data-bbox="1096 1711 1437 1795"> <tbody> <tr> <td>45</td> <td>Gold</td> <td></td> </tr> </tbody> </table>	45	Gold	
TYPE										
001	18-20 AWG crimp contact									
002	22 AWG crimp contact									
45	Gold									

All dimensions in mm.