

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0845060012](#)  
**Status:** **Active**  
**Overview:** XRC™ (Extra Rugged Circular) Sealed Plugs and Receptacles  
**Description:** XRC™ Panel Mount Hex Nut for Shell Size 24 Receptacles

**Documents:**

[3D Model](#) [Packaging Specification PK-84506-001 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Accessories
Series	84506
Component Type	Hex Nut
More Detailed Tech Information	For Use On XRC™ Shell Size 24 Receptacles
Overview	<a href="#">XRC™ (Extra Rugged Circular) Sealed Plugs and Receptacles</a>
Product Name	XRC™
UPC	883906594695


**Physical**

Circuits (Loaded)	N/A
Gender	N/A
Lock to Mating Part	No
Net Weight	5.080/g
Number of Rows	0
Packaging Type	Bag
Temperature Range - Operating	-40°C to +130°C

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification	PK-84506-001
Sales Drawing	SD-84506-012

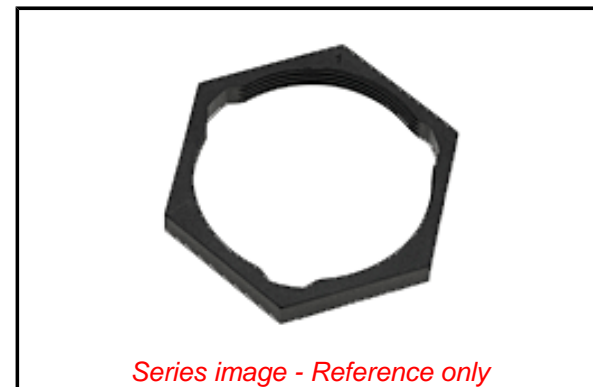

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per  
-ED/79/2015 (17  
December 2015)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS  
ELV

**China RoHS**

Green Image  
Not Relevant

**Search Parts in this Series**

[84506 Series](#)

**Use With**

[84506 XRC™ Receptacles, Shell Size 24](#),  
[84511 XRC™ Receptacles, Shell Size 24](#)