

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5023510600](#)
Status: **Active**
Overview: [DuraClik™ Connector System](#)
Description: [DuraClik™ Wire-to-Board Receptacle Housing, Single Row, 6 Circuits, Natural](#)

Documents:

[3D Model](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Drawing \(PDF\)](#)

General

| | |
|----------------|-----------------------------------------------------------------------------------------------------------------|
| Product Family | Crimp Housings |
| Series | 502351 |
| Application | Signal, Wire-to-Board |
| Comments | Molex part has an inner-locking system versus an outer-locking system. Molex part with tail protection feature. |
| Overview | DuraClik™ Connector System |
| Product Name | DuraClik™ |
| UPC | 800756666860 |

Physical

| | |
|-------------------------------|-----------------|
| Circuits (maximum) | 6 |
| Color - Resin | Natural |
| Gender | Receptacle |
| Glow-Wire Compliant | No |
| Keying to Mating Part | Yes |
| Lock to Mating Part | Yes |
| Net Weight | 267.000/mg |
| Number of Rows | 1 |
| Packaging Type | Bag |
| Panel Mount | No |
| Pitch - Mating Interface | 2.00mm |
| Polarized to Mating Part | Yes |
| Temperature Range - Operating | -40°C to +105°C |

Electrical

| | |
|-------------------------------|------|
| Current - Maximum per Contact | 3.0A |
|-------------------------------|------|


Solder Process Data

| | |
|-----------------------------|-----|
| Lead-freeProcess Capability | N/A |
|-----------------------------|-----|

Material Info

Reference - Drawing Numbers

| | |
|-----------------------|-------------------|
| Product Specification | RPS-502351-010-JP |
| Sales Drawing | SD-502351-001 |

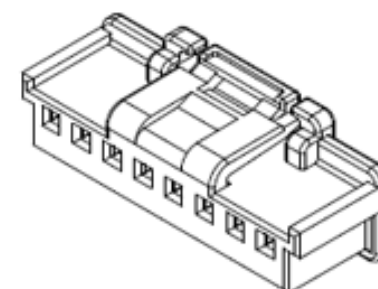

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
ED/21/2016 (20 June
2016)

Halogen-Free

Status

Not Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

China RoHS

Green Image

Compliant

Search Parts in this Series

[502351](#) Series

Mates With

[560020](#) , [502352](#) 2.00mm Pitch DuraClik™ Wire-to-Board Header

Use With

[560085](#) DuraClik™ Crimp Terminal AWG 22-26, [50212](#) 2.00mm Pitch Crimp Terminal AWG 24-30, [56161](#) 2.00mm Pitch Crimp Terminal AWG 22-26