


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [5040511001](#)
Status: **Active**
Overview: Pico-Lock™ Connector System
Description: 1.50mm Pitch Pico-Lock™ Crimp Housing, 2.00mm Mated Height, Positive Side Locks, 10 Circuits

Documents:

3D Model	Application Specification AS-504051-001 (PDF)
Drawing (PDF)	Application Specification AS-504051-002 (PDF)
Product Specification PS-504051-001 (PDF)	Packaging Specification SPK-504051-001 (PDF)
Product Specification PS-504051-002 (PDF)	RoHS Certificate of Compliance (PDF)

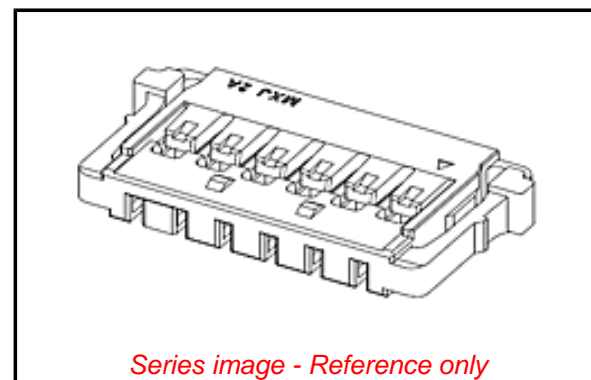

Agency Certification

UL E29179

General

Product Family	Crimp Housings
Series	504051
Application	Wire-to-Board
Overview	Pico-Lock™ Connector System
Product Name	Pico-Lock™
UPC	884982939929

Physical

Circuits (maximum)	10
Color - Resin	Black
Gender	Female
Glow-Wire Compliant	No
Keying to Mating Part	N/A
Lock to Mating Part	Yes
Material - Resin	High Temperature Thermoplastic
Net Weight	109.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.50mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40°C to +105°C

Electrical

Current - Maximum per Contact 2.0A

Material Info

Reference - Drawing Numbers

Application Specification	AS-504051-001, AS-504051-002
Packaging Specification	SPK-504051-001
Product Specification	PS-504051-001, PS-504051-002, RPS-504051-001, RPS-504051-002, RPS-504051-003, RPS-504051-004, RPS-504051-005, RPS-504051-006
Sales Drawing	SD-504051-001

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per - ED/21/2016 (20 June 2016)

Halogen-Free Status

Low-Halogen

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS ELV

Green Image Not Relevant

Search Parts in this Series

[504051 Series](#)

Mates With

[504050 Pico-Lock™ SMT Wire-to-Board Header](#)

Use With

[504052 Pico-Lock™ Crimp Terminal](#)