

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0397000104](#)  
**Status:** **Active**  
**Overview:** Eurostyle™ Terminal Blocks  
**Description:** 5.08mm Pitch, Eurostyle™ Fixed-Mount Push-Button Terminal Block, 45° Modular, 18A, 26-14 AWG, Green, 4 Circuits

**Documents:**

[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**General**

Product Family	Terminal Blocks
Series	39700
Application	Wire-to-Board
Component Type	Push-Button
Overview	<a href="#">Eurostyle™ Terminal Blocks</a>
Product Name	ESE, Eurostyle™ Fixed Mount
Type	Euro Block
UPC	78172542426

**Physical**

Circuits (Loaded)	4
Circuits (maximum)	4
Color - Resin	Green
Entry Angle	45° Angle
Lock to Mating Part	No
Material - Plating Termination	Tin
Material - Resin	Nylon
Number of Rows	1
Orientation	45° Angle
Panel Mount	Yes
Pitch - Mating Interface	5.08mm
Polarized to Mating Part	No
Stackable	No
Temperature Range - Operating	-40°C to +105°C
Wire Size AWG	14, 16, 18, 20, 22, 24, 26

**Electrical**

Current - Maximum per Contact	18.0A
Voltage - Maximum	300V

**Solder Process Data**


Lead-freeProcess Capability	N/A
-----------------------------	-----

**Material Info**

Old Part Number	M508-00-04-3
-----------------	--------------

**Reference - Drawing Numbers**

Sales Drawing	SD-39700-006
---------------	--------------

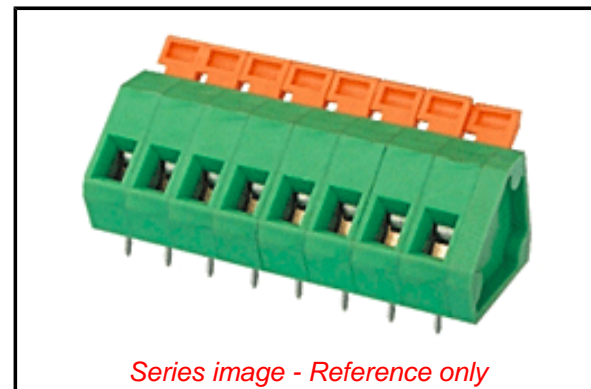

*Series image - Reference only*

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained Per - ED/108/2014 (17 Dec 2014)

**Halogen-Free**

**Status**

**Low-Halogen**

**Need more information on product environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

ELV

**China RoHS**

Green Image

Not Relevant

**Search Parts in this Series**

[39700 Series](#)