

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [0738380007](#)  
**Status:** **Active**  
**Overview:** [SL™ Modular Connectors](#)  
**Description:** 2.54mm SL™ Crimp Housing, Single Row, Version N, TPA™ with Positive Latch, 7 Circuits

**Documents:**

[3D Model](#) [Packaging Specification PK-70873-0540 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)  
[Product Specification PS-73838-005 \(PDF\)](#)

**General**

Product Family Crimp Housings  
Series [73838](#)  
Application Signal, Wire-to-Board, Wire-to-Wire  
Comments Terminal Position Assurance (TPA™) Piece  
Overview [SL™ Modular Connectors](#)  
Product Name SL™  
UPC 800754789509

**Physical**

Circuits (maximum) 7  
Color - Resin Natural  
Gender Female  
Glow-Wire Compliant No  
Material - Resin Polyester Alloy  
Net Weight 0.158/g  
Number of Rows 1  
Packaging Type Bag  
Panel Mount No  
Pitch - Mating Interface 2.54mm  
Stackable No  
Temperature Range - Operating -40°C to +105°C


**Solder Process Data**

Lead-free Process Capability N/A

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification [PK-70873-0540](#)  
Product Specification [PS-73838-005](#)  
Sales Drawing [SD-73838-004](#)

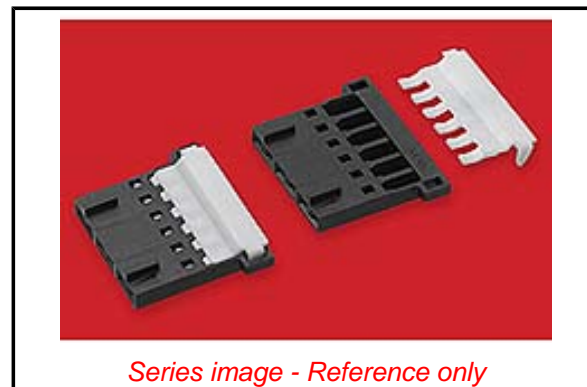

Series image - Reference only

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**China RoHS**

**REACH SVHC**

Not Contained Per -  
ED/39/2015 (15 June  
2015)

**Halogen-Free**

**Status**

**Not Low-Halogen**

**Need more information on product  
environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
Please visit the [Contact Us](#) section for any  
non-product compliance questions.

China ROHS  
ELV

Green Image  
Not Relevant

**Search Parts in this Series**

[73838](#) Series

**Mates With**

[70018](#) , [70543](#) , [70545](#) , [70553](#) , [70555](#) ,  
[70107](#) Version A, [70107](#) Version B

**Use With**

[70058](#) , [71851](#) , [73838](#)