

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0936010710](#)
Status: **Active**
Overview: [GWconnect® Heavy Duty Connectors \(HDC\)](#)
Description: [GWconnect® STD - Standard, Cover for Male Inserts, Die-cast Aluminum, with 2 Pegs, without Gasket, Size 3A «21x21», Grey](#)

Documents:

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Industrial Connectors / Enclosures
Series	93601
Comments	With nylon wire tether line.
Component Size	3A «21x21»
Component Type	Cover
IP Rating	IP66, IP67
Overview	GWconnect® Heavy Duty Connectors (HDC)
Product Category	Heavy Duty Connectors
Product Name	GWconnect®
Standard	ANSI/UL 50, ANSI/UL 50 E, CSA C22.2 No.94-1-2, EN 61984
Type	STD
UPC	887191844176
Use With	Size 3A «21x21» Housings and Male Inserts

Physical

Cover Coating	Polyester Powder
Cover Color	Grey RAL 7037
Lock to Mating Part	Yes
Material - Cover	Die-cast Aluminum
Material - Peg	Die-cast Aluminum
Number of Pegs	2
Packaging Type	Bag
Thread Size	N/A
Thread Type	N/A


Electrical

Voltage - Maximum	230V / 400V
-------------------	-------------

Material Info

Old Part Number	7803.6804.0
-----------------	-------------

GWconnect® is a registered trademark of Molex Incorporated in Italy and may be registered in other jurisdictions.

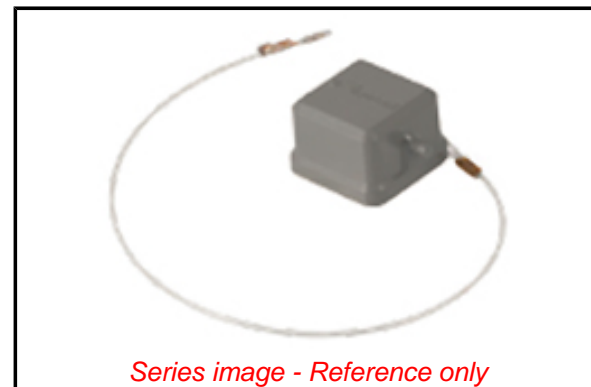

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

Not Reviewed

REACH SVHC

Not Reviewed

Halogen-Free

Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
Please visit the [Contact Us](#) section for any non-product compliance questions.

China ROHS

Not Reviewed

ELV

Not Reviewed

Search Parts in this Series

[93601](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION